



Southwire™

LIQUIDTIGHT CORD GRIPS

NPT HUBS - 6/6 NYLON

FEATURES

- Liquidtight at up to 70 P.S.I. water pressure
- Acme threads on body prevent skipping and speed installation
- Multiple sizes for cable diameters
- Suitable for NEMA type 6 enclosures
- IP68 Rating
- Locknuts sold separately

APPLICATION

- Indoor or outdoor use
- Prevents cable pullout and controls arc of bend

STANDARD MATERIAL


- 6/6 nylon

CERTIFICATIONS

- UL



LTF12

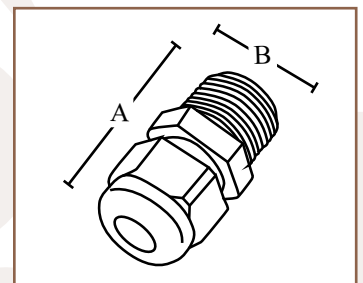

PART #	SIZE	CABLE DIAMETER		SUGGESTED CLEARANCE HOLE DIAMETER	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
		MIN.	MAX.						
LTF12	1/2"	.17"	.450"	.875"	25	100	3	1.53"	.93"
LTF34	3/4"	.45"	.709"	1.04"	10	100	5	1.97"	1.30"
LTF1	1"	.59"	1"	1.326"	10	100	6	2.42"	1.65"

Rev. 0, 02/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.