



# LED LINEAR WRAP

## MODERN

### SUGGESTED APPLICATIONS

- Commercial, residential
- New construction or remodel
- Offices, schools, retail, general task lighting
- Suitable for use in closets: Compliant with NFPA 70 NEC section 410.16 (A)(3) and 410.16 (C)(5)

### FEATURES

- CCT Selectable switch 3500K/4000K/5000K available on select models
- Efficient replacement for traditional fluorescent fixtures
- Side ½" knockouts allow easy access connection for wire and conduit
- Smooth 0-10V dimming, down to 10%
- Sleek modern white steel housing with frosted polycarbonate lens
- Surface mount hardware included
- Emergency battery backup models available



**INPUT VOLTAGE: 120-277V**

**FREQUENCY: 50/60HZ**

**POWER FACTOR, THD %:**  
**>0.9;<20%**

 
**DIMMABLE: 0-10V,**  
**DOWN TO 10%**

**EFFICACY: UP TO 115 LPW**

**CRI: 80**

**BEAM ANGLE: 105°**

**LIFETIME (L70): 50,000 HOURS**



**BUILT FOR DURABILITY.**  
**BUILT FOR RELIABILITY.**  
**BUILT FOR WORK.™**

800-666-2852 | TOPAZ-USA.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.

Job Name/Title: \_\_\_\_\_

Model #: \_\_\_\_\_

Contractor: \_\_\_\_\_



# TOPAZ®



A Southwire Company

## LED LINEAR WRAP MODERN

### ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	SIZE (TRADE)	LUMENS	WATTAGE	INPUT CURRENT @120V/277V	CCT	DLC ID
LWRAP2-25-40K-D	74422	032886304729	2FT	2,875	25W	0.20/0.11A	4000K	S-394SPW
LWRAP2-25-50K-D	74423	032886304736	2FT	2,875	25W	0.20/0.11A	5000K	S-8IU4SZ
LWRAP4-48-40K-D	74424	032886304743	4FT	5,520	48W	0.40/0.19A	4000K	S-UPKL02
LWRAP4-48-50K-D	74425	032886304750	4FT	5,520	48W	0.40/0.19A	5000K	S-215VYR
LWRAP4-48-CS-D	74426	032886304774	4FT	5,500 5,520 5,500	48W	0.40/0.19A	3500K 4000K* 5000K	S-GDCNOF
LWRAP4EM-48-CS-D	74427	032886304767	4FT	4,900 5,000 4,900	48W	0.40/0.19A	3500K 4000K* 5000K	---

\*DEFAULT CCT SELECT SETTING

### NOMENCLATURE

Example: LWRAP4EM-48-CS-D

PRODUCT	SIZE	WATTAGE	CCT	OPTIONS
LWRAP = LINEAR WRAP	2FT 4FT	25W 48W	4000K 5000K CS = COLOR SELECTABLE	EM = EMERGENCY BATTERY BACKUP D = DIMMABLE

### ACCESSORIES (SOLD SEPARATELY)

MODEL #	ORDER CODE	UPC	DESCRIPTION
BEL4W-UNV	72764	---	LED Emergency Driver
WD-OS	72700	751338004931	Occupancy Sensor

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

800-666-2852 | TOPAZ-USA.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.




# LED LINEAR WRAP MODERN

## ENERGY SAVINGS *Based on 12 hours/day and \$0.11/kWh*

MODEL #	LED WATTAGE	FLUORESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
LWRAP2-25-xxK-D	25W	2x 17W T8	5W	\$2	\$12
LWRAP4-48-xxK-D	48W	2x 32W T8	12W	\$6	\$29

## DIMENSIONS | WEIGHT

MODEL #	A (IN)	B (IN)	C (IN)	WEIGHT (LBS)
LWRAP2-25-xxK-D	21.25	5.31	2.16	1.54
LWRAP4-48-xxK-D	47.2	5.31	2.16	2.75
LWRAP4-48-CS-D	47.2	5.31	2.16	2.75
LWRAP4EM-48-CS-D	47.2	5.31	2.16	5.63

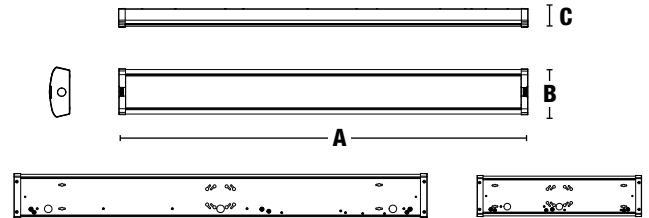

## NOTES

DLC Primary Use - Direct Linear Ambient Luminaires

Dimming with standard 0-10V control system or wall dimmers. Dimming complies with IEC60929 Annex E. Fixture may not be compatible with all dimmers. Dimming performance may vary based on selected dimmer.

Visit [www.topaz-usa.com/led-dimmer-compatibility](http://www.topaz-usa.com/led-dimmer-compatibility) for up-to-date dimmer compatibility information.

FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC. For details visit: <https://southwire.com/resources/warranties>

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

Specifications are subject to change without prior notice. Replacement wattage shown depends on application and fixture.

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

800-666-2852 | TOPAZ-USA.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.