



TRAY ROLLERS

Southwire now offers Tray Rollers and Tray Roller accessories, made with industrial grade quality and intended for reliability and long life that professionals expect. Some models are equipped with two load rollers on both the top and bottom to reduce point load on cables and to prevent tape shield wrinkling on MV Cables. All tray rollers use ball bearings and cast aluminum frames for weight reduction and durability.



HB1A-6 CABLE TRAY ROLLER

STOCK #: 65094901

- 6" zinc plated or stainless steel rollers
- "T"-handle clamp with swivel base
- 3/8" locking pin for locking and unlocking unit
- Adjustable angle for various cable-tray sizes
- Cable space between rollers is approx. 4"x 4"
- Ball-bearing rollers for reduced pulling tension



HB1A-9 UNIVERSAL SPLIT BOX ROLLER

STOCK #: 65095101

- Working load – 600 lbs.
- Can be extended above the cable tray by using the optional HBFB extension with the standard cross-bar
- Using the optional 90 degree bracket with the cross-bar, the HB1A-9 can be mounted with the force rollers on the sides above or below the cable tray
- Includes ball-bearing rollers for reduced pulling tension
- Can be mounted above or inside the cable tray by using a standard cross-bar and end-tray clamps
- Cable space between rollers is approx. 4-5/8"x 4-3/4"
- One-piece cast aluminum housing
- Open top for easy access



HB1A-9STC UNIVERSAL SPLIT BOX ROLLER WITH SIDE TRAY CLAMP

STOCK #: 65103301

- Working load: 600 lbs.
- Ball-bearing rollers for reduced pulling tension
- Cable space between rollers is approx. 4-5/8"x 4-3/4"
- One-piece cast aluminum housing
- Open top for easy access



HB1A-9X48 EXTENDED OUTSIDE VERTICAL RISER AND STRAIGHT SECTION ROLLER W/ 48" CROSSBAR AND CLAMPS

STOCK #: 65103501

- Working load – 600 lbs.
- Extended outside vertical riser and straight section roller
- Comes with cross bar and tray clamps
- Includes ball-bearing rollers for reduced pulling tension
- Cable space between rollers is approx. 4-5/8" x 4-3/4"
- One-piece cast aluminum housing
- Open top for easy access



HBFB-EXT TRAY CLAMP EXTENDED

STOCK #: 65095301

- Working load – 600 lbs.
- Used in place of HBFB side tray clamps to suspend HB1A-9 below 48" cross-bar
- Attaches to 6" - 12" cable tray
- Open top for easy access



HB3AX48 CROSSBAR W/ TRAY CLAMPS

STOCK #: 65095401

- Working load: 600 lbs.
- 48" crossbar w/ HBFB tray clamps for use with cable tray rollers
- Attaches to 4" to 6" cable tray



HBFB TRAY CLAMP

STOCK #: 65095501

- Working load: 600 lbs.
- Replacement tray clamp for HB3AX48
- Attaches to 4" to 6" cable tray






HB-90 90 DEGREE BRACKET

STOCK #: 65095601

- 90 Degree Bracket
- For adjustable 90 degree mounting of the HB1A-9 tray roller

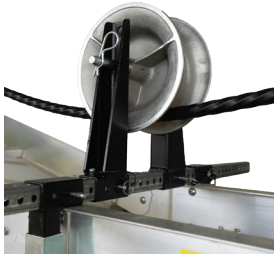

HB4A-12X5 - INSIDE VERTICAL RISER ROLLER, 12" W/ 48" CROSSBAR AND CLAMPS

STOCK #: 65103701

- Adjustable cable tray clamps for multiple setup configurations
- 48" base is usable with multiple tray roller configurations
- Standard 12" Dia x 5" Wide alloy aluminum sheave and horizontal sheave bracket with 3/4" Dia axle.
- Designed for Guiding Cable into Inside Vertical Risers in Cable Tray
- Ball-Bearing Rollers for reduced pulling tension



HB5A-12X5 - HORIZONTAL ELBOW ROLLER 12" W/ 48" CROSSBAR AND CLAMPS

STOCK #: 65103801

- Adjustable cable tray clamps for multiple setup configurations
- 48" base is usable with multiple tray roller configurations
- Standard 12" Dia x 5" Wide alloy aluminum sheave and vertical bracket with 3/4" Dia axle.
- Designed for Guiding Cable around turns in Cable Tray
- Ball-Bearing Rollers for reduced pulling tension



HB9AX48 - OUTSIDE VERTICAL RISER AND STRAIGHT SECTION ROLLER W/ 48" CROSSBAR AND CLAMPS

STOCK #: 65104001

- 48" base is usable with multiple tray roller configurations
- Ball-Bearing Rollers for reduced pulling tension
- Rollers create a minimum bend radius
- For use guiding cables around Outside Vertical Risers & through Straight-Sections in cable tray
- Fits cable tray sidewalls from 4"-6". Optional 6"-8" available
- Single point securing to crossbar



STC - SIDE TRAY CLAMP

STOCK #: 65183740

- Side Tray Clamp for mounting to side of cable tray
- Usable with HB9A/ HB1A-9 Rollers



HB4A - INSIDE VERTICAL RISER ROLLER, 12"

STOCK #: 65183840

- Standard 12" Dia x 5" Wide alloy aluminum sheave and horizontal sheave bracket with 3/4" Dia axle
- Designed for Guiding Cable into Inside Vertical Risers in Cable Tray
- Ball-Bearing Rollers for reduced pulling tension



HB5A - HORIZONTAL ELBOW ROLLER 12"

STOCK #: 65183940

- Standard 12" Dia x 5" Wide alloy aluminum sheave and horizontal sheave bracket with 3/4" Dia axle
- Designed for Guiding Cable into Inside Vertical Risers in Cable Tray
- Ball-Bearing Rollers for reduced pulling tension



HB9A - OUTSIDE VERTICAL RISER AND STRAIGHT SECTION ROLLER

STOCK #: 65184040

- Ball-Bearing Rollers for reduced pulling tension
- Rollers create a minimum bend radius
- For use guiding cables around Outside Vertical Risers & through Straight-Sections in cable tray
- One-piece cast aluminum housing
- Open top for easy access
- Single point for securing to crossbar



MODEL NUMBER	UPC	STOCK	DESCRIPTION	WORKING LOAD LBS.	HEIGHT IN	HEIGHT CM	WIDTH IN	WIDTH CM	LENGTH IN	LENGTH CM	WEIGHT LB	WEIGHT KG
HB1A-6	0-32886-70795-7	65094901	Cable Tray Roller	300	11.50	29.21	5.00	12.70	12.00	30.48	9.00	4.05
HB1A-9	0-32886-70797-1	65095101	Universal Split Box Roller	600	11.50	29.21	6.85	17.40	12.55	31.88	14.10	6.345
HB1A-9STC	0-32886-70939-5	65103301	Universal Split Box Roller with Side Tray Clamp	600	15.30	38.86	6.80	17.27	18.80	47.75	22.00	9.9
HB1A-9X48	0-32886-70940-1	65103501	Extended Outside Vertical Riser and Straight Section Roller w/ 48" Crossbar and Clamps	600	16.00	40.64	3.20	8.13	48.00	121.92	27.10	12.195
HBFB-EXT	0-32886-70798-8	65095301	Tray Clamp Extended	600	6.00	15.24	1.75	4.45	17.75	45.09	6.90	3.105
HB3Ax48	0-32886-70799-5	65095401	Crossbar w/ Tray Clamps	600	18.25	46.36	2.00	5.08	48.00	121.92	12.90	5.805
HBFB	0-32886-70800-8	65095501	Tray Clamp	600	7.00	17.78	2.00	5.08	3.75	9.53	3.00	1.35
HB-90	0-32886-70801-5	65095601	90 Degree Bracket	300	9.75	24.77	1.75	4.45	3.75	9.53	2.00	0.9
HB4A-12x5	0-32886-70942-5	65103701	Inside Vertical Riser Roller, 12" w/ 48" Crossbar and Clamps	N/A	23.50	59.69	12.00	30.48	48.00	121.92	33.15	14.92
HB5A-12x5	0-32886-70943-2	65103801	Horizontal Elbow Roller 12" w/ 48" Crossbar and Clamps	N/A	23.50	59.69	12.00	30.48	48.00	121.92	26.00	11.7
HB9Ax48	0-32886-70945-6	65104001	Outside Vertical Riser and Straight Section Roller w/ 48" Crossbar and Clamps	300	17.15	43.56	6.68	16.97	48.00	121.92	23.00	10.35
STC	0-32886-79238-0	65183740	Side Tray Clamp	600	10.5	26.67	1.5	3.81	19	48.26	6.9	3.13
HB4A	0-32886-79239-7	65183840	Inside Vertical Riser Roller, 12"	600	8	20.32	14	35.56	14	35.56	19	8.62
HB5A	0-32886-79240-3	65183940	Horizontal Elbow Roller 12"	600	8	20.32	14	35.56	14	35.56	18	8.16
HB9A	0-32886-79241-0	65184040	Outside Vertical Riser and Straight Section Roller	300	8	20.32	14	35.56	14	35.56	13	5.9