



# Southwire™

## RIGID BUSHINGS

### INSULATED - 105°C THERMOPLASTIC LINER - ZINC

#### FEATURES

- Liner is rated flame retardant to 105°C

#### APPLICATION

- Indoor or outdoor use
- Use with locknut to terminate Rigid or IMC conduit to an outlet box
- Plastic liner prevents damage to wire insulation

#### STANDARD MATERIAL

- Zinc
- Plastic insulator

#### CERTIFICATIONS


- UL Standard: UL 514B
- Fed. Spec: W-F-406E, W-F-406D
- NEMA: FB1-2014



311



| PART # | SIZE   | INNER QTY. | MASTER QTY. | WEIGHT/ CASE (LBS.) | A      | B     |
|--------|--------|------------|-------------|---------------------|--------|-------|
| 311    | 1/2"   | 100        | 1000        | 30                  | 1.053" | .394" |
| 312    | 3/4"   | 50         | 500         | 20                  | 1.327" | .394" |
| 313    | 1"     | 50         | 500         | 40                  | 1.584" | .477" |
| 314    | 1-1/4" | 25         | 250         | 25                  | 1.952" | .503" |
| 315    | 1-1/2" | 25         | 250         | 27                  | 2.201" | .522" |
| 316    | 2"     | 10         | 100         | 17                  | 2.693" | .564" |
| 317    | 2-1/2" | ---        | 50          | 20                  | 3.235" | .866" |
| 318    | 3"     | ---        | 25          | 12                  | 3.855" | .866" |
| 319    | 3-1/2" | ---        | 25          | 14                  | 4.359" | .866" |
| 320    | 4"     | ---        | 10          | 6                   | 5.011" | .866" |

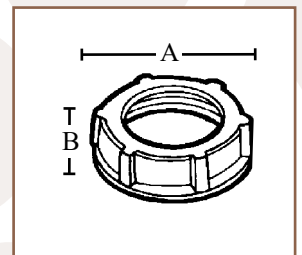

Rev. 0, 05/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.