

WELDING CYLINDER CARTS

SUMNER

Sumner Manufacturing Co, Inc.



- Small Single Cylinder Cart**
- Heavy Duty Single Cylinder Carts**
- Small-Medium High Rail Cylinder Carts**
- Medium Range High Rail Cylinder Carts**
- Full Range High Rail Cylinder Carts**

Small Single Cylinder Cart (Model #108)		
	Part No.	782375
	Model #	108-8S
	Cylinders	40 cf. Acetylene OR 50 to 80 cf Oxygen
	Wheel PN	779024
	Wheel Type	8" semi-pneumatic
	Chain/Bar	Chain
	Lifting Eye	No
	Firewall	No
	Height	40.0" (101.6 cm)
	Depth	12.3" (31.2 cm)
	Width	12.1" (30.7 cm)
	lbs	11.0
kg	5.0	

HD Single Cylinder Cart (Model #112)			
	Part No.	782386	782385
	Model #	112-10P	112-10S
	Cylinders	75 cf. Acetylene OR 80 to 150 cf Oxygen	
	Wheel PN	779027	779011
	Wheel Type	12" pneumatic	12" semi-pneu.
	Chain/Bar	Chain	
	Lifting Eye	No	
	Firewall	No	
	Height	49.4" (125.5 cm)	
	Depth	18.1" (46.0 cm)	18" (45.7 cm)
	Width	20.8" (52.8 cm)	19.1" (48.6 cm)
	lbs	30.0	36.0
kg	13.6	16.4	

Base Plate: 7" x 14" (178 x 356 mm) Load Capacity: 500 lbs (225 kg)

Small-Med High Rail Cylinder Carts (Model #207)			
	Part No.	782359	782360
	Model #	207-10S	207-8S
	Cylinders	40 cf. Acetylene & 50 to 80 cf Oxygen	
	Wheel PN	779011	779031
	Wheel Type	10" semi-pneu.	8" semi-pneu.
	Chain/Bar	Chain	
	Lifting Eye	No	
	Firewall	No	
	Height	41.0" (104.1 cm)	
	Depth	22.8" (57.8 cm)	21.8" (55.2 cm)
	Width	13.8" (34.9 cm)	12.8" (32.3 cm)
	lbs	30.0	30.0
kg	13.6	13.6	

Base Plate: 7.5" x 15.5" (190 x 394 mm)

Small-Med High Rail Cylinder Carts (Model #208)			
	Part No.	782380	782379
	Model #	208-10S	208-8S
	Cylinders	75 cf. Acetylene & 80 to 150 cf Oxygen	
	Wheel PN	779011	779031
	Wheel Type	10" semi-pneu.	8" semi-pneu.
	Chain/Bar	Chain	
	Lifting Eye	No	
	Firewall	No	
	Height	49.5" (125.7 cm)	
	Depth	23" (58.4 cm)	22" (55.9 cm)
	Width	18.3" (46.4 cm)	
	lbs	40.0	40
kg	18.1	18.1	

Base Plate: 8" x 17" (203 x 432 mm)

Medium Range, High Rail Cylinder Cart w/ Chain (Model #209)



782424
209-14S

Part No.	782424	782420	782422	782426	782428
Model #	209-14S	209-10S	209-10P	209-16P	209-16F
Cylinders	244 to 330 cf Oxygen & 145 cf Acetylene				
Wheel PN	779028	779011	779027	779107	779104
Wheel Type	14" semi-pneu.	10" semi-pneu.	10" pneumatic	16" pneumatic	16" flat free
Chain/Bar	Chain				
Lifting Eye	No				
Firewall	No				
Height	43.6" (110.7 cm)				
Depth	16.9" (42.9 cm)			18.27" (46.4 cm)	
Width	28" (71 cm)			32.5" (82.6 cm)	
lbs	47	48	40	53	54
kg	21.4	21.8	18.2	24.1	24.5

Base Plate: 9" x 18" (229 x 457 mm)

Medium Range, High Rail Cylinder Cart w/ Bar (Model #209)



782420
209-10S



782422
209-10P



782425
209-14SB

Part No.	782425	782421	782427
Model #	209-14SB	209-10SB	209-16PB
Cylinders	244 to 330 cf Oxygen & 145 cf Acetylene		
Wheel PN	779028	779011	779107
Wheel Type	14" semi-pneu.	10" semi-pneu.	16" pneumatic
Chain/Bar	Bar		
Lifting Eye	No		
Firewall	No		
Height	43.6" (110.7 cm)		
Depth	16.9" (42.9 cm)		18.27" (46.4 cm)
Width	28" (71 cm)		32.5" (82.6 cm)
lbs	48	49	54
kg	21.8	23.3	24.5

Base Plate: 9" x 18" (229 x 457 mm)



782421
209-10SB



782427
209-16PB

Medium Range, High Rail Cylinder Cart w/ Lifting Eye & Firewall (Model #209)



782426
209-16P



782428
209-16F



782443
209-16PB-LF

Part No.	782443	782444	782439
Model #	209-16PB-LF	209-16FB-LF	209-14SB-LF
Cylinders	244 to 330 cf Oxygen & 145 cf Acetylene		
Wheel PN	779107	779104	779028
Wheel Type	16" pneumatic	16" flat free	14" semi-pneu.
Chain/Bar	Bar		
Lifting Eye	Yes		
Firewall	Yes		
Height	66" (167.6 cm)		
Depth	18.4" (46.7 cm)		17" (43.2 cm)
Width	32.4" (82.3 cm)		27.5" (69.9 cm)
lbs	75.5	74	81
kg	34.2	33.6	36.7


Base Plate: 9" x 18" (229 x 457 mm)



782444
209-16FB-LF



782439
209-14SB-LF

Full Range, High Rail Cylinder Cart w/ Chain (Model #213)				
	Part No.	782480	782475	782482
	Model #	213-14S	213-25W	213-16P
	Cylinders	244 to 330 cf Oxygen & 210 to 420 cf Acetylene		
	Wheel PN	779028	782575	779107
	Wheel Type	14" semi-pneu.	25" steel	16" pneumatic
	Chain/Bar	Chain		
	Lifting Eye	No		
	Firewall	No		
	Height	44.6" (113.3 cm)		
	Depth	20.3" (51.6 cm)	26.75" (67.9 cm)	22.1" (56.1 cm)
	Width	31.8" (80.8 cm)	33.6" (85.4 cm)	36.5" (92.7 cm)
	lbs	53	69	59
	kg	24	31.3	26.8

782480
213-14S




782475
213-25W




782482
213-16P

Base Plate: 13" x 25" (330 x 630 mm)

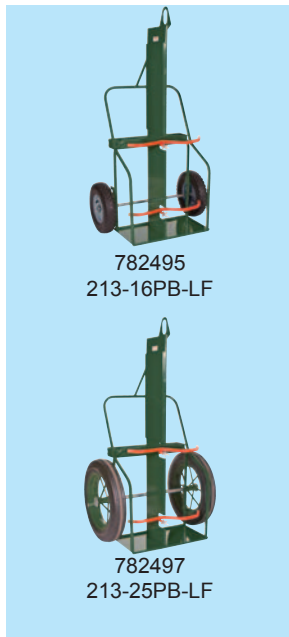

782495
213-16PB-LF

782497
213-25PB-LF

Full Range, High Rail Cylinder Cart w/ Bar (Model #213)																											
	<table border="1"> <tr> <td>Part No.</td> <td>782483</td> </tr> <tr> <td>Model #</td> <td>213-16PB</td> </tr> <tr> <td>Cylinders</td> <td>244 to 330 cf Oxygen & 210 to 420 cf Acetylene</td> </tr> <tr> <td>Wheel PN</td> <td>779107</td> </tr> <tr> <td>Wheel Type</td> <td>16" pneumatic</td> </tr> <tr> <td>Chain/Bar</td> <td>Bar</td> </tr> <tr> <td>Lifting Eye</td> <td>No</td> </tr> <tr> <td>Firewall</td> <td>No</td> </tr> <tr> <td>Height</td> <td>44.6" (113.3 cm)</td> </tr> <tr> <td>Depth</td> <td>22.1" (56.1 cm)</td> </tr> <tr> <td>Width</td> <td>36.5" (92.7 cm)</td> </tr> <tr> <td>lbs</td> <td>61</td> </tr> <tr> <td>kg</td> <td>27.7</td> </tr> </table>	Part No.	782483	Model #	213-16PB	Cylinders	244 to 330 cf Oxygen & 210 to 420 cf Acetylene	Wheel PN	779107	Wheel Type	16" pneumatic	Chain/Bar	Bar	Lifting Eye	No	Firewall	No	Height	44.6" (113.3 cm)	Depth	22.1" (56.1 cm)	Width	36.5" (92.7 cm)	lbs	61	kg	27.7
Part No.	782483																										
Model #	213-16PB																										
Cylinders	244 to 330 cf Oxygen & 210 to 420 cf Acetylene																										
Wheel PN	779107																										
Wheel Type	16" pneumatic																										
Chain/Bar	Bar																										
Lifting Eye	No																										
Firewall	No																										
Height	44.6" (113.3 cm)																										
Depth	22.1" (56.1 cm)																										
Width	36.5" (92.7 cm)																										
lbs	61																										
kg	27.7																										


782483
213-16PB

Base Plate: 13" x 25" (330 x 630 mm)



782476
213-25WB-LF

782491
213-14SB-LF


Full Range, High Rail Cylinder Cart w/ Lifting Eye & Firewall (Model #213)						
	Part No.	782496	782495	782497	782476	782491
	Model #	213-16FB-LF	213-16PB-LF	213-25PB-LF	213-25WB-LF	213-14SB-LF
	Cylinders	244 to 330 cf Oxygen & 210 to 420 cf Acetylene				
	Wheel PN	779104	779107	780521	782575	779028
	Wheel Type	16" flat free	16" pneumatic	25" pneumatic	25" steel	14" semi-pneu.
	Chain/Bar	Bar				
	Lifting Eye	Yes				
	Firewall	Yes				
	Height	66.5" (168.9 cm)				
	Depth	22.1" (56.1 cm)		27.1" (68.8 cm)	26.75" (67.9 cm)	20.5" (52.1 cm)
	Width	36.8" (93.5 cm)			33.6" (85.4 cm)	31.8" (80.8 cm)
	lbs	109	109	152	115	103
	kg	49.4	49.4	69.1	52.2	46.7

782496
213-16FB-LF

Base Plate: 13" x 25" (330 x 630 mm)

How To Read Sumner Cylinder Cart Product Descriptions


X X X - X X X X - X X

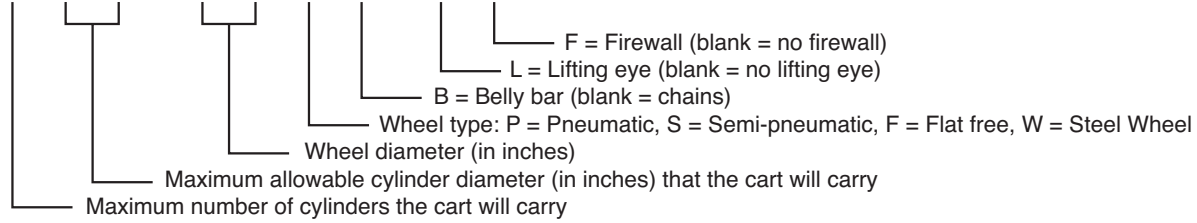

EXAMPLE: cart part number 782496, 213-16FB-LF

- 2 = carries two cylinders
- 13 = 13 inch maximum cylinder diameter
- 16 = 16 inch wheel size
- F = Flat free tire
- B = Belly bar
- L = Lifting eye
- F = Firewall

Wheel					
Part No.	779024	779031	779011	779027	779028
Diameter	8" (200 mm)	8" (200 mm)	10" (250 mm)	10" (250 mm)	14" (355 mm)
Width	1.75" (44 mm)	2" (50 mm)	2.75" (70 mm)	3.5" (89 mm)	1.75" (44 mm)
Bore	0.5" (13 mm)	0.5" (13 mm)	5/8" (16 mm)	5/8" (16 mm)	5/8" (16 mm)
Bearing	Powder metal bushing	Steel bushing	Bronze bushing	Bronze bushing	Bronze bushing
Description	Semi-pneumatic	Semi-pneumatic	Semi-pneumatic	Pneumatic	Semi-pneumatic
Load Capacity	80 lbs (36.2 kg)	400 lbs (180 kg)	400 lbs (180 kg)	350 lbs (150 kg)	150 lbs (65 kg)
Fits Sumner Cart(s)	108, 207, 208	207, 208	112, 207, 208, 209	112, 209	209, 213

Wheel				
Part No.	779104	779107	780521	782575
Diameter	16" (400 mm)	16" (400 mm)	25" (635 mm)	25" (635 mm)
Width	4.8" (120 mm)	4.8" (120 mm)	4" (100 mm)	2" (50 mm)
Bore	1" (25 mm)	1" (25 mm)	1.25" (32 mm)	1.25" (32 mm)
Bearing	Powder metal bushing	Powder metal bushing	Bronze bushing	Bronze bushing
Description	Flat free	Pneumatic	Pneumatic	Steel
Load Capacity	380 lbs (170 kg)	380 lbs (170 kg)	800 lbs (360 kg)	800 lbs (360 kg)
Fits Sumner Cart(s)	209, 213	209, 213	213	213

DISTRIBUTED BY:

SUMNER

Sumner Manufacturing Co, Inc.

www.sumner.com

Sumner - U.S. 7514 Alabonson Road • Houston, TX 77088 • Ph: 281-999-6900 • Fax: 281-999-6966

Sumner - Canada 75 Saltsman Drive, Unit 5 • Cambridge, Ontario N3H 4R7 • Ph: 519-653-5300 • Fax: 519-653-5305

Sumner - Netherlands Midden Engweg 21 • NL-3882TS Putten • The Netherlands • Ph: +31 (0) 85 489 0284 • europeansales@sumner.com

Sumner - U.K. Unit 3 Kempton Road • Keytec 7 Business Park • Pershore, Worcestershire WR10 2TA • Ph: (44) 01386 556278 • Fax: (44) 01386 556776