



Southwire™

TOOLS & EQUIPMENT

SOUTHWIRE'S NEW LINE OF NON-CONTACT AC VOLTAGE DETECTORS MAKE IT EVEN EASIER TO CHECK FOR THE PRESENCE OF LIVE VOLTAGE ON OUTLETS, WIRING, CIRCUIT BREAKERS, LIGHTING FIXTURES AND SWITCHES. ALL COME WITH A STANDARD ON/OFF SWITCH AND REAR FACING FLASHLIGHT WHICH IS NOW TWICE AS BRIGHT.



40116N

40126N

40136N

40150N

NCV'S

Rear facing flashlight now 2X brighter

Available front facing flashlight

Thinner probe tip for working with wall outlets

Standard on/off switch

Green "power on" LED

Available dual sensitivity mode

Available silent mode

Low battery self test

Waterproof model available



COMMON FEATURES

- Audible and visual indication of AC voltage without contact
- New more powerful rear facing flashlight
- Standard on/off switch
- Bright green LED indicates unit is on and ready for use
- Flashing red LED and pulsing beeper indicate presence of AC Voltage
- Pocket clip for easy storage
- Thinner probe tip for easy testing of wall receptacles
- Low battery self-test

ADDED FEATURES

40126N


- Dual sensitivity allows detection of voltage in low voltage circuits down to 24V AC as well as higher voltage up to 600V AC
- Yellow LED indicates low voltage mode

40136N

- Silent mode
- Flash and Beep rate increase as the detector gets closer to the voltage source helping the user pinpoint live circuits

40150N

- Dual sensitivity allows detection of voltage in low voltage circuits down to 24V AC as well as higher voltage up to 600V AC
- Yellow LED indicates low voltage mode
- Silent mode
- Flash and Beep rate increase as the detector gets closer to the voltage source helping the user pinpoint live circuits
- IP-67 Waterproof

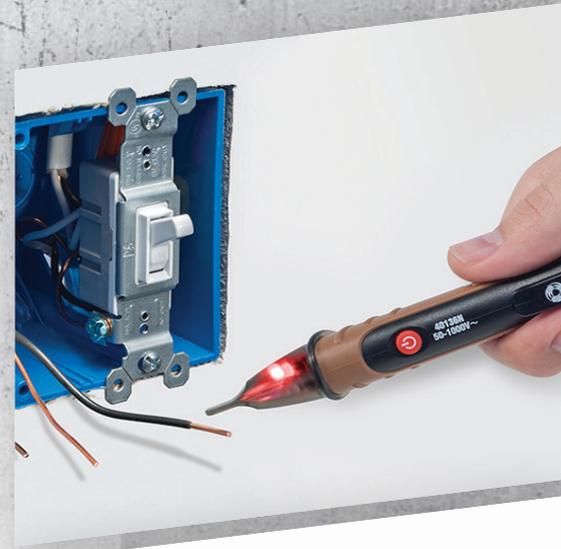

SPECIFICATIONS

Model #	AC Detection Range
40116N	100-600V AC
40126N	24-600V AC
	100-600V AC
40136N	50-600V AC
40150N	12-1000V AC
	100-1000V AC

GENERAL SPECIFICATIONS

Safety Rating	CAT IV 600V
Frequency Range	50/60Hz
Batteries	Two AAA
Operating Temperature	32oF to 104oF (0oC to 40oC)
Storage Temperature	14oF to 140oF (-10oC to 60oC)
Dimensions	6.23 x 0.83 x 0.99 in (158 x 21 x 25 mm)
Humidity	80% max

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-SWTOOLS | 1-855-798-6657 | SOUTHWIRETOOLS.COM