


# ULTRA FIT\* PARTS

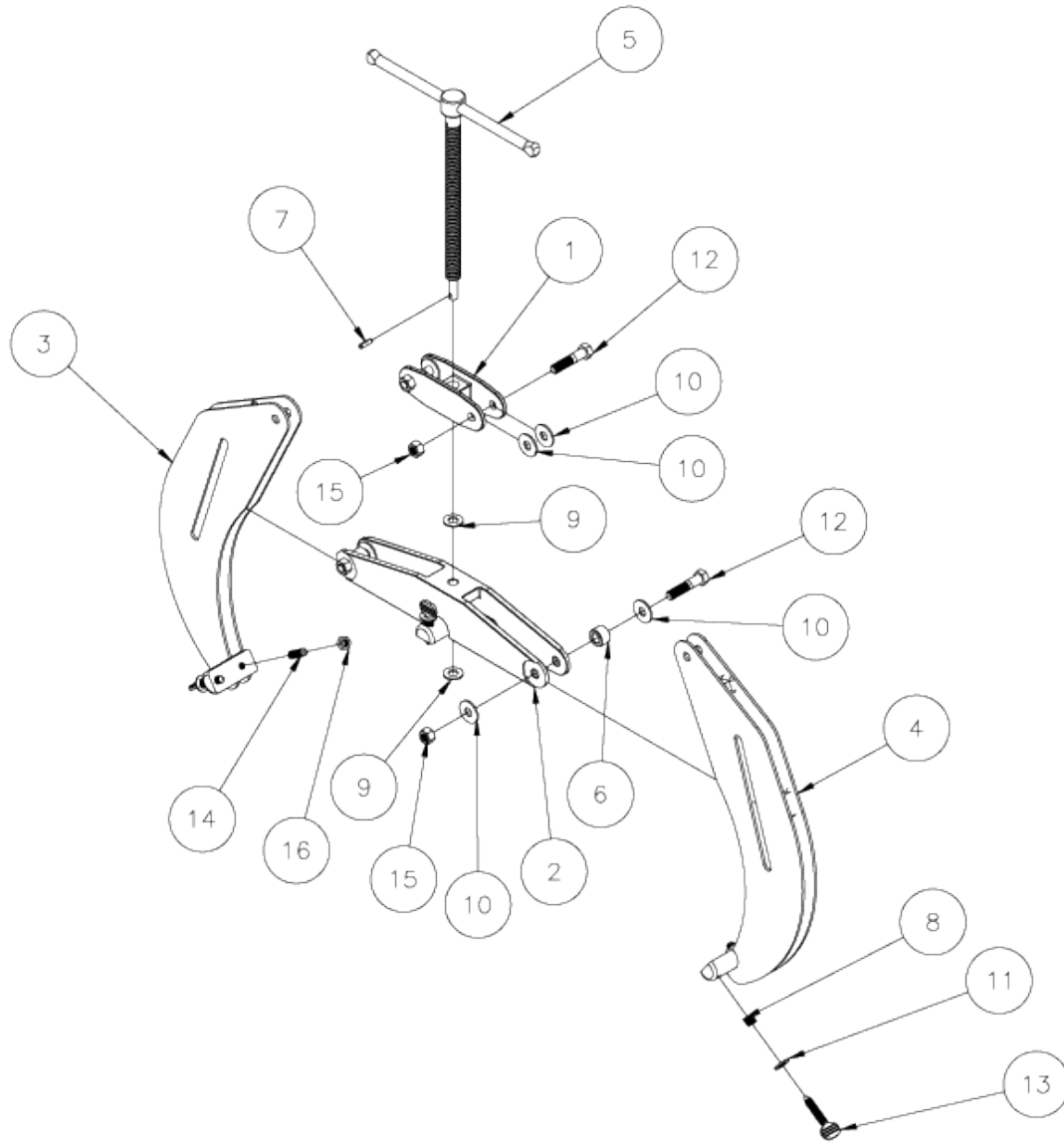

Item	Part No.	Description	Qty
1	783002	HEADER 2-1/2"	1
1	783004	HEADER 2-6"	1
1	781293	HEADER PLATE, 5-12"	1
2	781267	RAM ASSEMBLY 1" - 2-1/2"	1
2	781276	RAM ASSEMBLY 6"	1
2	781286	RAM ASSEMBLY 12"	1
3	781269	CLAW WELDMENT, LEFT 2-1/2"	1
3	781279	CLAW WELDMENT, LEFT 6"	1
3	781289	CLAW WELDMENT, LEFT 12"	1
4	781268	CLAW WELDMENT, RIGHT 2-1/2"	1
4	781280	CLAW WELDMENT, RIGHT 6"	1
4	781288	CLAW WELDMENT, RIGHT 12"	1
5	781131	TEE HANDLE ASSY. 2-1/2"UC	1
5	781151	T-HANDLE ASSY. 6"UC	1
5	781171	T-HANDLE ASSY. 12"	1
6	781281	ROLLER, ULTRA CLAMP, 6", 12"	2
7	774092	PIN, ROLL 1/8 X 5/8" for 2-1/2"	1
7	774096	PIN, ROLL 3/16 X 5/8" for 6" and 12"	1
8	776066	SPRING "SS" FOR UC 2-1/2"	3
9	773022	WASHER FL HARD .38 for 6" and 12"	2
9	773021	WASHER FL HARD 1/4 for 2-1/2"	2
10	773024	WASHER FL BRASS .38 (3/8L) for 2-1/2"	8
10	773023	WASHER FL BRASS .25 (16L) for 6"	8
11	773016	WASHER, FLAT 5/16 TYPE B NARROW	3
12	771100	SCREW, HHC 3/8-16 X 1-3/4" for 6"	4
12	771029	SCREW, HHC 1/4-20 X 1-3/4"	4
13	771148	THUMB SCREW, SS 5/16 - 18 X 1.5"	3
14	771433	SET SCREW, SS 5/16 - 18	2
15	772076	NUT, INSERT LOCK 1/4-20 for 2-1/2"	4
15	772350	NUT, INSERT JAM 3/8-16 for 12"	4
16	772506	NUT, JAM 5/16 - 18	2