

## LED Traditional Wall Pack

### POWER & CCT SELECTABLE



### Advanced Technology Wrapped in a Traditional Fixture

Topaz's LED Traditional Wall Packs are an easy upgrade to energy efficient lighting, designed to cover the existing footprint of legacy HID fixtures. The integrated dusk-to-dawn photocell and 0-10V dimming driver provide light adjustability for substantial energy savings. Selectable 3 CCT color and power settings allow up to nine different configurations for added customization while also significantly reducing SKU count.

### FEATURES

- Choose from three wattage and three CCT choices for up to nine possible configurations
- Durable aluminum housing with hinged lens frame, captive screws and ½" knockouts on each side
- IK06 impact resistant glass lens
- Semi-cut off light distribution designed to eliminate glare providing smooth, uniform light
- Integrated dusk-to-dawn photocell

### SUGGESTED APPLICATIONS

- Commercial and residential
- Security lighting
- Perimeter lighting
- Warehouses
- Condos / apartments
- Hotels





Job Name/Title: \_\_\_\_\_ Catalog Number \_\_\_\_\_

Contractor: \_\_\_\_\_ Notes: \_\_\_\_\_

## LED Traditional Wall Pack POWER & CCT SELECTABLE

### GENERAL SPECIFICATIONS

**Input Voltage, Frequency:** 120-277V, 50/60Hz  
**Power Factor, THD %:** >0.9, <25%  
**Dimmable:** 0-10V down to 15%<sup>1</sup>  
**Efficacy:** Up to 140 LPW  
**Beam Angle:** 90°  
**Minimum CRI:** 82  
**IES Distribution:** Type IV

**Functional Life (L70):** 50,000 Hours  
**Location Rating:** Wet  
**IP Rating:** IP65  
**Ambient Operating Temperature:** -40°F to 122°F  
**Mounting:** Wall Mount, typical for mounting heights up to 30'



**Integrated dusk-to-dawn photocell\***

### ITEM SPECIFICATIONS / ORDER INFO

Catalog Number	Order Code	UPC	Lumens	Wattage	Input Current @120/277V	CCT	DLC ID <sup>†</sup>
WP/40W/PCTS/BZ/PC	72983	751338039360	3,920	28W	0.25/0.11A	3000K	PQZYFURT
			5,600	40W	0.35/0.16A	4000K 5000K	
WP/80W/PCTS/BZ/PC	72984	751338039377	5,600	40W	0.35/0.16A	3000K	PNQ1KT7N
			8,400	60W	0.51/0.24A	4000K	
			11,200	80W	0.70/0.32A	5000K	
WP/120W/PCTS/BZ/PC	72985	751338039384	11,200	80W	0.70/0.32A	3000K	PN5ZFW39
			14,000	100W	0.85/0.40A	4000K	
			16,800	120W	1.05/0.48A	5000K	

### NOMENCLATURE

**WP** = Wall Pack / **40W** = 28W|40W / **P** = Power Select **CTS** = Color Temperature Select 3000K|4000K|5000K / **BZ** = Bronze / **PC** = Photocell Included  
**80W** = 40W|60W|80W  
**120W** = 80W|100W|120W

### ACCESSORIES (SOLD SEPARATELY)


Catalog Number	Order Code	UPC	Description
<b>F-WP/HE/GUARD/S-95</b>	70272	751338035492	Small wire guard for use with WP/40W/PCTS/BZ/PC
<b>F-WP/HE/GUARD/L-95</b>	70273	751338035508	Large wire guard for use with WP/80W/PCTS/BZ/PC, WP/120W/PCTS/BZ/PC
<b>F-WP/HE/SHIELD/S-95</b>	70274	751338035515	Small shield for use with WP/40W/PCTS/BZ/PC
<b>F-WP/HE/SHIELD/L-95</b>	70275	751338035546	Large shield for use with WP/80W/PCTS/BZ/PC, WP/120W/PCTS/BZ/PC

### ENERGY SAVINGS

Catalog Number	LED Wattage	HID Replacement Wattage	Watts Saved	Yearly Savings	5 Year Savings
<b>Based on 12 hours/day and \$0.11/kWh</b>					
<b>WP/40W/PCTS/BZ/PC</b>	28W 40W	100W-150W	110W	\$53	\$265
<b>WP/80W/PCTS/BZ/PC</b>	40W 60W 80W	150W-275W	195W	\$94	\$470
<b>WP/120W/PCTS/BZ/PC</b>	80W 100W 120W	320W-400W	280W	\$135	\$675

### DIMENSIONS / WEIGHTS

Catalog Number	(A)	(B)	(C)	Weight
<b>WP/40W/PCTS/BZ/PC</b>	10.62"	7.59"	6.61"	4.0 Lbs.
<b>WP/80W/PCTS/BZ/PC</b>	14.60"	9.68"	7.72"	8.4 Lbs.
<b>WP/120W/PCTS/BZ/PC</b>	14.60"	9.68"	7.72"	8.4 Lbs.

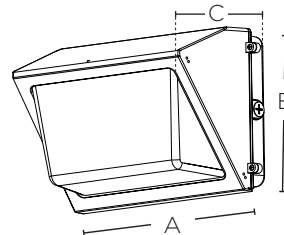

#### NOTES:

\*Photocell can easily be disabled (bypassed) by user. Refer to product installation instructions for details.

<sup>†</sup>DLC Primary Use: Outdoor Non-Cutoff and Semi-Cutoff Wall-Mounted Area Luminaires

<sup>‡</sup>Dimming with standard 0-10V control system or wall dimmers. Dimming complies with IEC60929 Annex E. Fixture may not be compatible with all dimmers. Dimming performance may vary based on selected dimmer. Visit [www.topaz-usa.com/led-dimmer-compatibility](http://www.topaz-usa.com/led-dimmer-compatibility) for up-to-date dimmer compatibility information.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

Specifications subject to change without prior notice. Replacement wattage shown depends on application and fixture.

**WARNING:** Some products included in this specification sheet may be subject to the warning requirements of California's Proposition 65. Please refer to your product packaging for more information.

Revised August 2021