




Southwire[®]

SDSH1/4, SDSH2P6

SCREWHOLDING SCREWDRIVERS

These specialty screwdrivers are designed for the professional with durability, quality and comfort in mind.

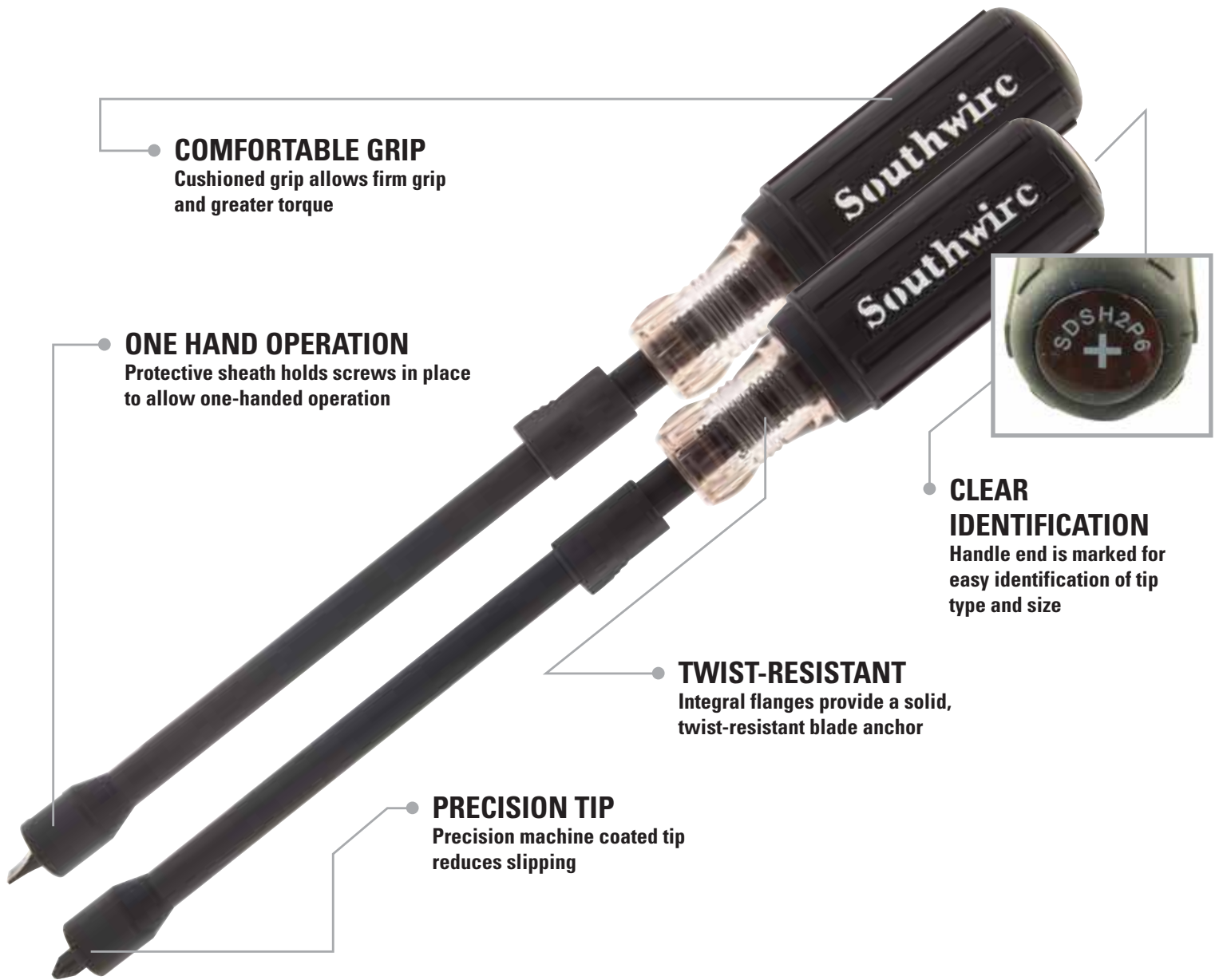

COMFORTABLE GRIP
Cushioned grip allows firm grip and greater torque

ONE HAND OPERATION
Protective sheath holds screws in place to allow one-handed operation

PRECISION TIP
Precision machine coated tip reduces slipping

TWIST-RESISTANT
Integral flanges provide a solid, twist-resistant blade anchor

CLEAR IDENTIFICATION
Handle end is marked for easy identification of tip type and size



Southwire[™]

TOOLS & EQUIPMENT

[BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.]

1-855-SWTOOLS
(855-798-6657)



Southwiretools.com



Features & Benefits

- Protective sheath holds screws in place to allow one-handed operation
- Precision-machined, black phosphate coated tip reduces slipping
- Comfortable cushioned grip allows firm grip and greater torque
- Integral flanges provide a solid, twist-resistant blade anchor
- Handle end is marked for easy identification of tip type and size
- Meets or exceeds the applicable ASME / ANSI specifications

Specifications

MODEL #	SDSH1/4	SDSH2P6
STOCK #	582840	582839
DESCRIPTION	1/4" Slotted Screwholding Screwdriver	#2 Phillips Screwholding Screwdriver 6" Shank
HEIGHT	11.25"	11.25"
WIDTH	1.25"	1.25"
DEPTH	1.25"	1.25"
WEIGHT	4.9 oz	4.9 oz
TIP TYPE	Slotted	Phillips
TIP SIZE	1/4"	#2
SHANK TYPE	Screwholding	Screwholding
SHANK LENGTH	6"	6"
HANDLE FINISH	Comfort Grip	Comfort Grip

