



Southwire™

INSULATED METALLIC GROUNDING BUSHINGS WITH ALUMINUM LUG - 105°C THERMOPLASTIC LINER - ZINC

FEATURES

- Liner is rated flame retardant to 105°C
- UL listed for use with copper or aluminum grounding conductor

APPLICATIONS

- Indoor or outdoor use
- Use with locknut to terminate service conduit to a cabinet
- Lug provided for bonding jumper to a neutral bus bar
- Round surface of bushing prevents damage to wire insulation
- Plastic liner prevents damage to wire insulation

STANDARD MATERIAL


- Body - Zinc/plastic insulator
- Lug - Aluminum
- Clamping screw - Steel
- Set screws - Steel



321



PART #	SIZE	GROUNDING LUG WIRE SIZE		INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
		MIN.	MAX.					
321	1/2"	14	4	50	500	25	1.25"	.50"
322TZ	3/4"	14	4	50	500	35	1.50"	.50"
323	1"	14	4	25	250	30	1.75"	.56"
324TZ	1-1/4"	14	4	20	200	34	2.12"	.62"
325	1-1/2"	14	2	10	100	20	2.37"	.75"
326	2"	14	2	10	100	35	2.81"	.75"
327	2-1/2"	14	1/0	--	50	25	3.62"	.93"
328TZ	3"	14	1/0	---	10	6	4.18"	.93"
329	3-1/2"	14	2/0	---	10	7	4.68"	.93"
330	4"	6	250MCM	---	10	8	5.25"	.93"

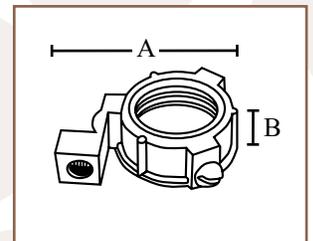

Rev. 0, 05/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.