



# LED INDOOR REFLECTOR SERIES

## SUGGESTED APPLICATIONS

- Recessed downlighting, track lights, task lighting
- Residential, hospitality, retail, restaurants, commercial

## FEATURES

- Approximately 80% energy savings over halogen reflectors
- Dimmable down to 10% of total light output\*
- Lasts up to 10X longer than traditional incandescent lamps
- Available in a wide variety of color temperatures
- Contains NO mercury

**INPUT VOLTAGE: 120V**

**FREQUENCY: 50/60Hz**

**BASE: E26**


**LIFETIME (L70):  
UP TO 25,000 HOURS**



R20

BR30

 BR40



**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

**800-666-2852 | SOUTHWIRE.COM**

©2025 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.



# LED INDOOR REFLECTOR SERIES

## ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	LUMENS	WATTAGE	RATED LUMENS	BEAM SPREAD	CCT	CRI	CBCP (CD)	MOL (IN)
R20										
LR20/6/827/D-46	73425	751338001459	525	6.5W	525	107°	2700K	80	180	3.9"
LR20/6/830/D-46	73426	751338002036	525	6.5W	525	107°	3000K	80	180	3.9"
LR20/6/840/D-46	73427	751338002043	525	6.5W	525	107°	4000K	80	180	3.9"
LR20/6/850/D-46	73428	751338002050	525	6.5W	525	107°	5000K	80	180	3.9"
BR30										
LBR30/9/827/D-46	78930	751338002203	750	9.5W	750	105°	2700K	80	260	5.2"
LBR30/9/830/D-46	73413	751338001442	750	9.5W	750	105°	3000K	80	260	5.2"
LBR30/9/840/D-46	73414	751338001657	750	9.5W	750	105°	4000K	80	260	5.2"
LBR30/9/850/D-46	78931	751338002210	750	9.5W	750	105°	5000K	80	260	5.2"
BR40										
LBR40/16/827/D-46	73407	751338001428	1,200	16.5W	1,200	103°	2700K	80	445	6.5"
LBR40/16/830/D-46	73408	751338002111	1,200	16.5W	1,200	103°	3000K	80	445	6.5"
LBR40/16/840/D-46	73409	751338001435	1,200	16.5W	1,200	103°	4000K	80	445	6.5"
LBR40/16/850/D-46	73410	751338002166	1,200	16.5W	1,200	103°	5000K	80	445	6.5"

## ORDERING GUIDE

Example: LR20/6/827/D

PRODUCT	WATTAGE	CRI	OPTIONS
LR20 = LED R20 Shape LBR30 = LED BR30 Shape LBR40 = LED BR40 Shape	6W = 6 Watts 8W = 8 Watts 9W = 9 Watts 11W = 11 Watts 16W = 16 Watts	827 = 80 CRI and 2700K 830 = 80 CRI and 3000K 840 = 80 CRI and 4000K 850 = 80 CRI and 5000K 927 = 90 CRI and 2700K 930 = 90 CRI and 3000K	D = Dimmable



800-666-2852 | SOUTHWIRE.COM

©2025 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.




# LED INDOOR REFLECTOR SERIES

**ENERGY SAVINGS** Based on 6 hours/day and \$0.11/kWh

MODEL #	LED WATTAGE	INCANDESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
LR20/6/8xx/D	6.5W	50W	43.5W	\$10.48	\$52.40
LBR30/9/xxx/D	9.5W	65W	55.5W	\$13.37	\$66.85
LBR40/16/8xx/D	16.5W	85W	68.5W	\$16.50	\$82.50

**DIMENSIONS | WEIGHT**

MODEL #	A (IN)	B (IN)	WEIGHT (LBS.)
LR20/6/8xx/D	3.9	2.5	.11
LBR30/9/8xx/D	5.2	3.7	.19
LBR40/16/8xx/D	6.5	5.0	.36

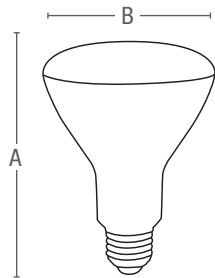

**NOTES**

\*Dimming- This product is designed to be compatible with most leading-edge type incandescent and LED style dimmers. (Dimming range 100% down to 5%). Product performance may vary depending on dimmer manufacturer and circuit loading. Visit [www.southwire.com](http://www.southwire.com) or contact your local Southwire representative for a list of compatible dimmers.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation. Specifications subject to change without notice.

FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC: For details visit: <https://southwire.com/resources/warranties>

Specifications subject to change without notice.

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

**800-666-2852 | SOUTHWIRE.COM**

©2025 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.