



# LED A19 LAMP

## OMNIDIRECTIONAL

### SUGGESTED APPLICATIONS

- Fan lights, decorative, recessed, task lighting
- Residential, hospitality, retail, restaurants, commercial

### FEATURES

- 85% energy savings compared to incandescent lamps
- Suitable for use in totally enclosed luminaires
- Long life – up to 10X longer than traditional incandescents
- RoHS compliant and mercury free
- Plastic lens material provides shatter protection



**INPUT VOLTAGE: 120V**

**FREQUENCY: 50/60Hz**

 
**THD%: <15%**

**DIMMABLE: DIMMABLE TO 5%**

**CRI: 80**

**BEAM ANGLE: 220°**

**LIFETIME (L70):  
UP TO 25,000 HOURS**



**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

**800-666-2852 | SOUTHWIRE.COM**

©2025 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.



# LED A19 LAMP

## OMNIDIRECTIONAL

### ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	LUMENS	WATTAGE	BASE	CCT	LPW	MOL
LA19/6W/27K/D-46	74370	751338024069	480	40W	E26	2700K	80	4.35"
LA19/6W/30K/D-46	74371	751338024106	480	40W	E26	3000K	80	4.35"
LA19/6W/40K/D-46	74372	751338024120	480	40W	E26	4000K	80	4.35"
LA19/6W/50K/D-46	74373	751338024137	480	40W	E26	5000K	80	4.35"
LA19/11W/27K/D-46	74378	751338024199	1,100	75W	E26	2700K	100	4.35"
LA19/11W/30K/D-46	74379	751338024229	1,100	75W	E26	3000K	100	4.35"
LA19/11W/40K/D-46	74380	751338024236	1,100	75W	E26	4000K	100	4.35"
LA19/11W/50K/D-46	74381	751338024243	1,100	75W	E26	5000K	100	4.35"
LA19/15W/27K/D-46	74382	751338024250	1,600	100W	E26	2700K	107	4.65"
LA19/15W/30K/D-46	74383	751338024274	1,600	100W	E26	3000K	107	4.65"
LA19/15W/40K/D-46	74384	751338024298	1,600	100W	E26	4000K	107	4.65"
LA19/15W/50K/D-46	74385	751338024304	1,600	100W	E26	5000K	107	4.65"
LA19/9W/27K/GU24D	74386	751338024311	800	60W	GU24	2700K	82	4.35"
LA19/9W/40K/GU24D	74388	751338024335	800	60W	GU24	4000K	82	4.35"

### ORDERING GUIDE

Example: LA19/6W/27K/D

PRODUCT	WATTAGE	CRI	
LA19 = LAMP A19	6W=6 WATTS 9W= 9 WATTS 11W= 11 WATTS 15W= 15 WATTS	27K = 2700K 30K = 3000K 40K = 4000K 50K = 5000K	D= DIMMABLE GU24D = GU24 BASE, DIMMABLE



800-666-2852 | SOUTHWIRE.COM

©2025 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.




**ENERGY SAVINGS** Based on 5 hours/day and \$0.11/kWh

MODEL #	LED WATTAGE	HALOGEN/INCANDESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
LA19/6W/xxK/D-46	6W	40W	34W	\$6.83	\$34.13
LA19/11W/xxK/D-46	11W	75W	64W	\$12.85	\$64.24
LA19/15W/xxK/D-46	15W	100W	85W	\$17.06	\$85.32
LA19/9W/xxK/GU24D	9.8W	60W	50W	\$10.04	\$50.19

**DIMENSIONS | WEIGHT**

MODEL #	A (IN)	B (IN)	WEIGHT (LBS.)
LA19/xW/xxK/D-46	4.35	2.36	0.1
LA19/15W/xxK/D-46	4.65	2.36	0.1
LA19/9W/xxK/GU24D	4.35	2.36	0.1

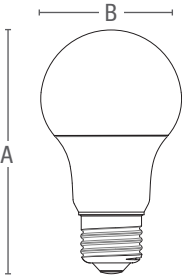

**NOTES**

Dimming- This product is designed to be compatible with most leading-edge type incandescent and LED style dimmers. (Dimming range 100% down to 5%). Product performance may vary depending on dimmer manufacturer and circuit loading. Visit [www.southwire.com](http://www.southwire.com) or contact your local Southwire representative for a list of compatible dimmers.

THREE (3) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC: For details visit: <https://southwire.com/resources/warranties>

\*This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

Specifications are subject to change without prior notice. Replacement wattage shown depends on application and fixture.



800-666-2852 | SOUTHWIRE.COM

©2025 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.