



Southwire™

RIGID RAIN TIGHT CONNECTORS

COMPRESSION TYPE WITH INSULATED THROAT - MALLEABLE IRON

FEATURES

- Raintight and concrete tight
- Compression type connector
- Insulated throat
- Threadless
- Suitable for use with UL 6 & UL6 A Rigid Conduit
- For use with steel or aluminum conduit
- EZ slip on labor saving design
- No disassembly required

APPLICATION

- Use to join unthreaded Rigid or IMC conduit to steel outlet box or metal enclosure

STANDARD MATERIAL

- Malleable iron

STANDARD FINISH


- Zinc plated



262MIRT



PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
261MIRT	1/2"	20	200	45	1.45"	1.74"
262MIRT	3/4"	10	100	28	1.68"	1.87"
263MIRT	1"	5	50	34	1.93"	2.13"
264MIRT	1-1/4"	5	50	34	2.34"	2.49"
265MIRT	1-1/2"	---	12	11	2.56"	2.52"
266MIRT	2"	---	12	15	3.14"	2.58"
267MIRT	2-1/2"	---	5	12	3.83"	3.49"
268MIRT	3"	---	3	10	4.46"	3.69"
269MIRT	3-1/2"	---	2	9	5.01"	3.73"
270MIRT	4"	---	2	10	5.53"	3.99"

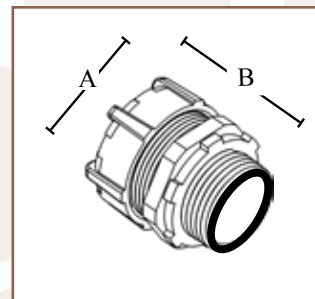

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.