


FMC-PCS Duo™

FIXTURE WHIP ASSEMBLY

Southwire's FMC-PCS Duo™ Fixture Whip Assembly combines power and control/signal conductors into one assembly for a cost-effective solution for wiring LED lighting with 0-10 V dimming control. This UL listed and NEC compliant 6 foot fixture whip assembly is constructed of ½ inch steel flexible metal conduit, THHN power conductors, and a 16/2 TFFN control/signal cable.

FEATURES //

- Meets the requirements of NEC 725.136 for combining class 1 circuits with class 2 or 3 circuits
- 6 foot steel flexible metal conduit with 6 inch exposed wire leads at each end and lock-nut or snap-in fittings for easy and hassle-free hookups.
- Convenient labor and material savings assembly.
- Available in drum or carton packaging for bulk delivery and easy handling.
- Available in low volt and high volt color constructions.

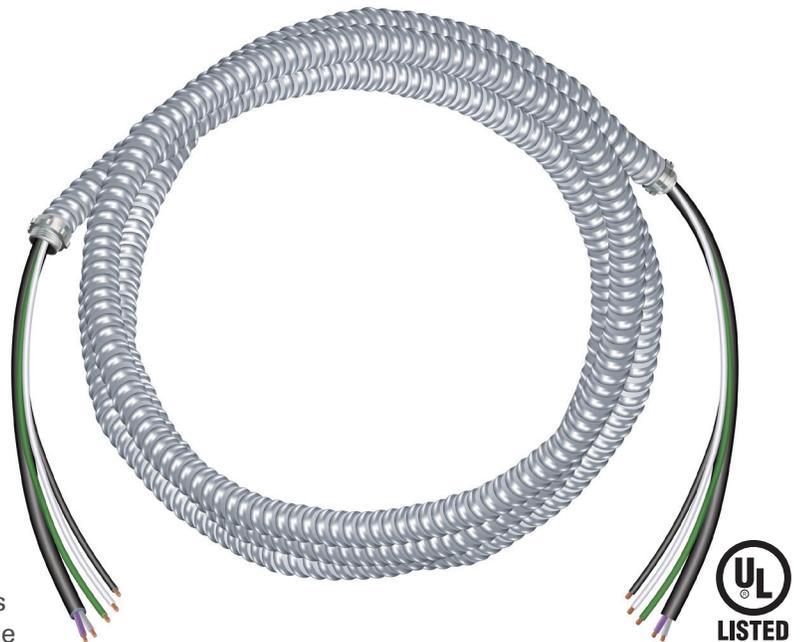

CONSTRUCTION //

- FMC-PCS Duo™ Fixture Whip Assembly is constructed with ½ inch steel flexible metal conduit with 10-14 AWG solid or stranded THHN/THWN power conductors and a 16/2 control/signal cable with purple and gray TFFN conductors.
- 6 foot fixture whip assembly with 6 inch leads on each end.
- Other constructions, configurations, and packaging options available upon request.

Lock Nut Fittings with Solid and Stranded Conductors					
Size	Description	Southwire Stock #	Conduit Length	Lead Length	Assemblies Per Drum
14/3c SOL LN WHIP	BK/WE/GN	64389202	6'	6"	50 pcs.
14/3c STR LN WHIP	BK/WE/GN	64406802	6'	6"	50 pcs.
12/3c STR LN WHIP	BK/WE/GN	64371702	6'	6"	50 pcs.
Snap In Fittings with Solid and Stranded Conductor					
12/3c STR SI WHIP	BK/WE/GN	64371902	6'	6"	50 pcs.

The Power of Connections™

Connect With Us | #SOUTHWIRE



Southwire®

©2017 Southwire Company, LLC. All Rights Reserved.
 ®Registered Trademark and ™Trademark of Southwire Company, LLC.