


Steady arm G1" curved with eye and insulation 3 kV, adjustable, L = 1500 mm, with thread 5/8", SST

Item number D2411-05

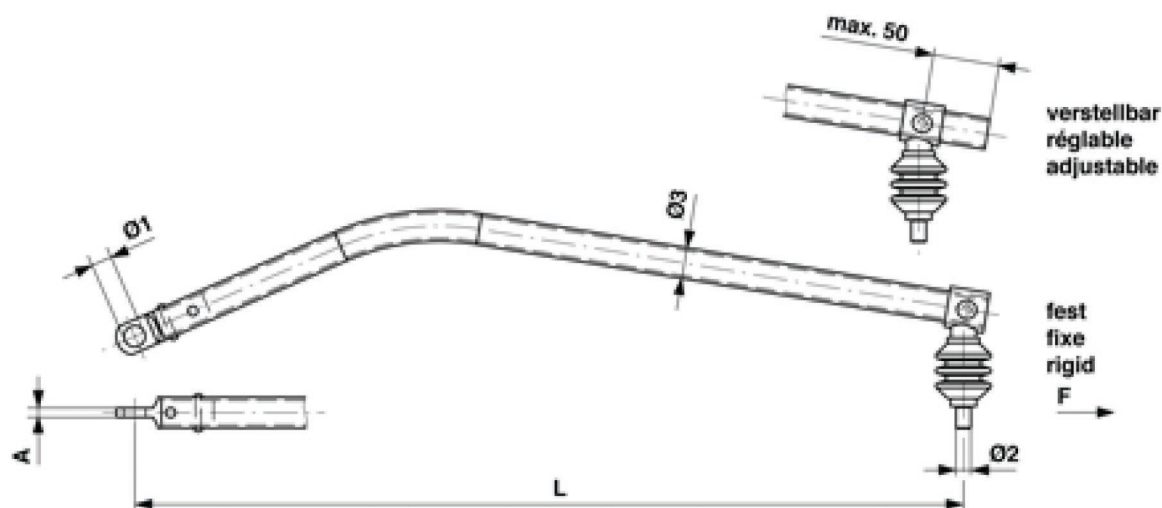

Dimensions

A: 10.000 mm

Ø1: 23 mm

Ø3: 33.7 mm

Ø2: 5/8"

L: 1500 mm

Material and weight

Material: SST

Weight: 4.130 kg

Loads

Breaking load F: 5.5 kN

Specification

Operating voltage: max. 3000 V

Minimum creeping distance: 85 mm for insulator

Comments

- Steady arm G1" are also available in aluminum (with reduced breaking load and low weight)
- Minimum order quantity on request



Southwire™



A COLAS RAIL COMPANY

Contact Us: Transit@southwire.com