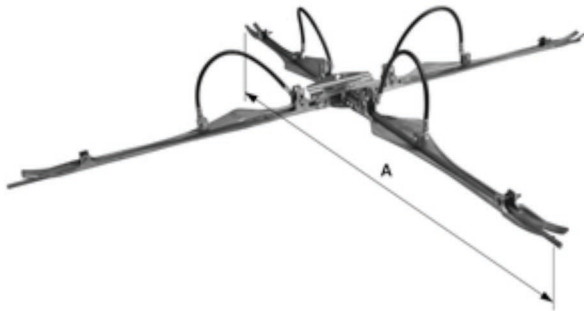

Crossing TW-TW, adjustable, KUMAX, 55°–90°, for contact wire 150 mm² - 178 mm²
Part no. B1180-02



Technical data

Dimensions

A: 1902 mm

Material and weight

Weight: 18.000 kg

Loads and tightening torque

-

Standards applied

-

Function

-

Specifications

-

Spare parts

-

Accessories

-

Comments

- For use with flat and bowed pantographs
- It is recommended to use the special installation tool part no. WD2725-01
- Contact wire reinforcing run-out side part no. C1996-01
- Jig to check the runner wear (check prism) part no. WE3513-01
- Special applications for double crossings on request
- Spare material
 - Mid piece for crossing TW part no. D2716-01 (for B1180-01 and B1180-02)
 - Glider for crossing TW-TW part no. D2715-01 (for B1180-01) and part no. D2715-02 (for B1180-02)



Southwire™



A COLAS RAIL COMPANY

Contact Us: Transit@southwire.com