


## LED Fire Rated Recessed Housing

### NEW CONSTRUCTION - SHALLOW

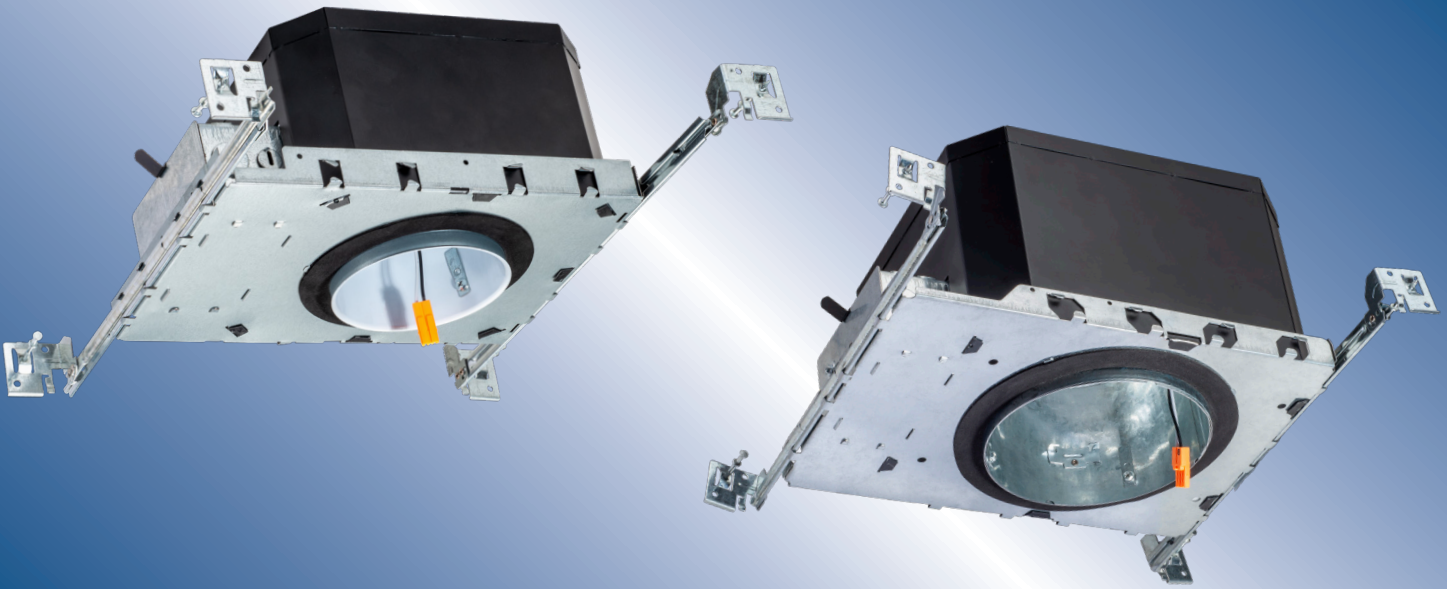

#### Designed to Meet Strict Fire Safety Codes

Topaz's fire rated recessed housings are sure to meet the demands of the toughest fire codes. Our shallow, new construction models are available in 4" or 6" sizes and offer a non-screw base quick connector for use with a variety of LED trims to match any décor. Featuring a double wall construction, these housings are filled with non-combustible fiber insulation, to prevent flames and gasses from passing through.

Adding to its extensive list of features are expandable, swivel hanger bars that can be repositioned 90° for various mounting applications. With pre-installed nails and 1-½ inches of adjustability to accommodate a variety of ceiling thicknesses, installation will be a breeze.

#### FEATURES

- 2 hour fire rated UL Listed (UL 1598/ UL 263)
- Air Tight (ASTM Standard E283-04)
- Relocatable and adjustable swivel hanger bar with pre-installed nails
- Adjustable housing to accommodate various ceiling thickness
- Low-profile design to fit in shallow locations
- Non-screw base quick connector for snap-in connection of LED downlights
- For use with 4" or 6" LED trim kits

#### SUGGESTED APPLICATIONS

- New construction
- Commercial and residential
- Condominiums, apartment buildings, multi-family



## LED Fire Rated Recessed Housing NEW CONSTRUCTION - SHALLOW


### GENERAL SPECIFICATIONS

**Frame:** Galvanized steel; housing can be removed from frame to provide access to junction box

**Housing:** Die-formed 22-gauge galvanized steel exterior; flexible non-combustible insulated interior

**Junction Box:** Listed for through branch circuit wiring; contains (1) 1-1/8", (1) 1/2", (3) 7/8" KOs and 4 pryouts with strain relief



**Installation:** Hanger bars with pre-installed nails; hangers are adjustable from 13-5/8" to 25" and swivel up to 90° for easy installation

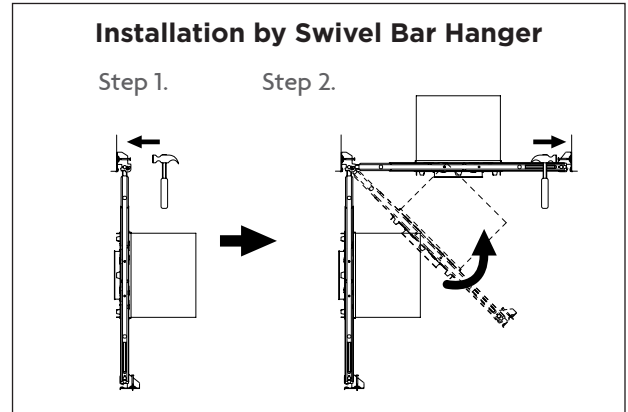



### ORDER INFO/ PRODUCT DIMENSIONS

Catalog Number	Order Code	UPC	(A)	(B)	(C)	(D)	(E)	Weight
RH4/NLED/IC/AT/F-28	70290	751338036291	7"	10.07"	4.81"	4.25"	3.50"	2.07 Lbs.
RH6/NLED/IC/AT/F-28	70291	751338036307	9"	12.50"	6.19"	6.13"	5.50"	3.03 Lbs.

RH4/NLED/IC/AT/F-28

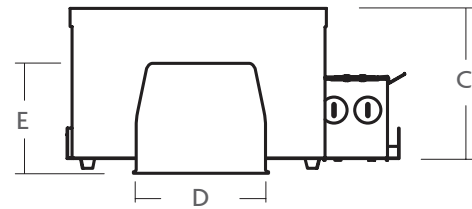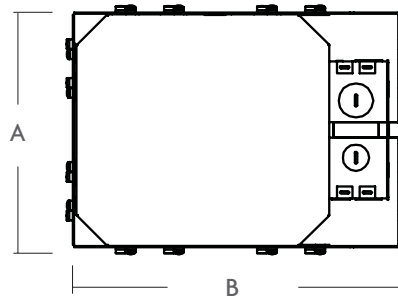

RH6/NLED/IC/AT/F-28

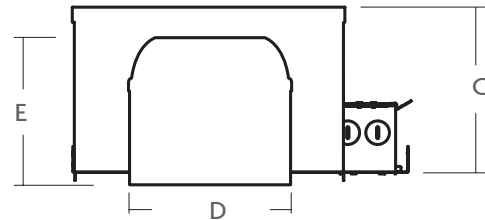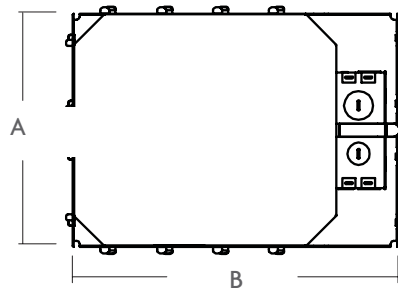

### NOMENCLATURE

Example: RH4/NLED/IC/AT/F-28

RH = Recessed Housing 4 = 4 inch / N = New Construction LED = For use with LED trims only / IC = Insulation Contact / AT = Air Tight / F = Fire Rated  
6 = 6 inch / R = Remodel

### NOTES:

Specifications subject to change without prior notice.

**WARNING:** Some products included in this specification sheet may be subject to the warning requirements of California's Proposition 65. Please refer to your product packaging for more information.