



BENDDOLLY™ BENDING PLATFORM


MECHANICAL BENDING PLATFORM

***LIGHT WEIGHT BENDING
PLATFORM***

***INTERCHANGEABLE SHOE
MOUNTING PLATE***

***LARGE DOLLY WHEELS FOR
EASY MANEUVERABILITY***

***STABLE BENDING
PLATFORM***

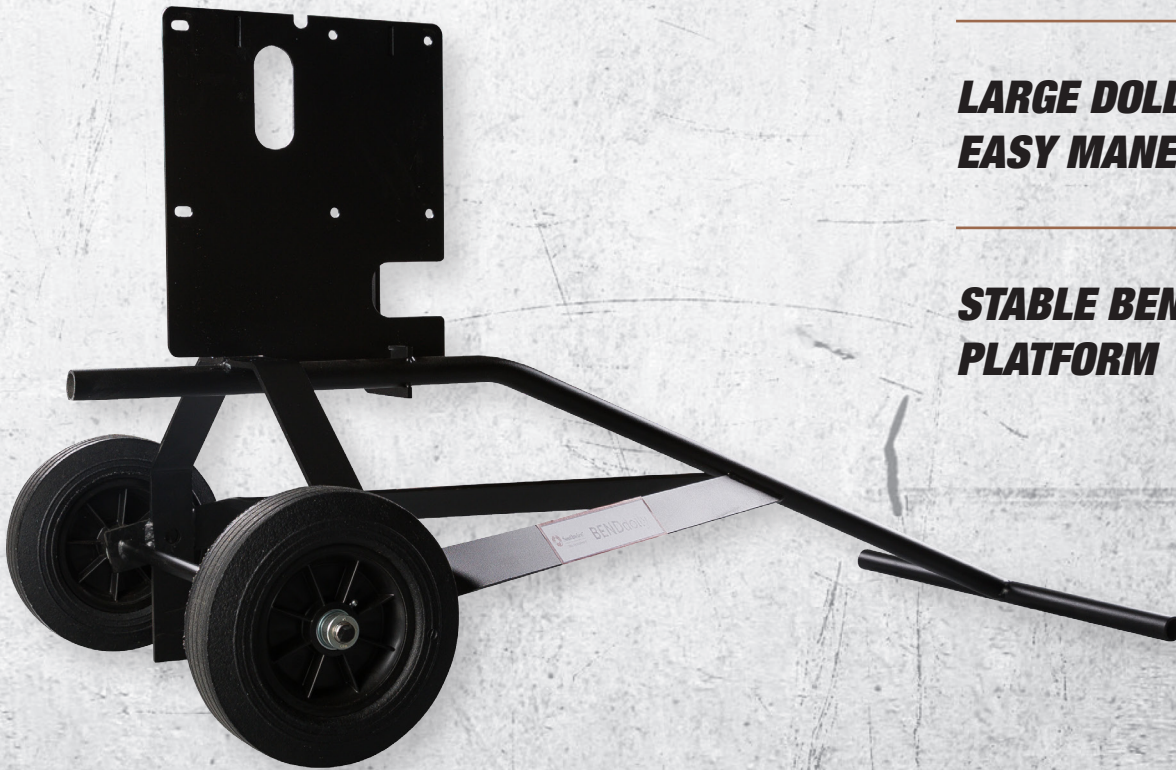



BENDDOLLY™ BENDING PLATFORM

FEATURES & BENEFITS

- Light Weight Bending Platform
- Interchangeable Shoe Mounting Plate
- Large Dolly Wheels for Easy Maneuverability
- Stable Bending Platform



SPECIFICATIONS

Model #	Stock #	Description	Capacity
BD-01	64601101	BENDdolly™ Bending Platform	Works with EMT, IMC/GRC Bending
Height	Width	Depth	Weight
28.75"	26"	55"	60lbs

Model #	Stock #	Description	Capacity
BD750E	64602301	BENDdolly™ 1/2"-3/4" EMT Bender	1/2"-3/4" EMT Conduit
Height	Width	Depth	Weight
28.75"	26"	55"	92lbs

Model #	Stock #	Description	Capacity
BD1000E	64602401	BENDdolly™ 3/4"-1" EMT Bender	3/4"-1" EMT Conduit
Height	Width	Depth	Weight
28.75"	26"	55"	110lbs

Model #	Stock #	Description	Capacity
BD1250E	64602401	BENDdolly™ 1"-1.25" EMT Bender	1"-1.25" EMT Conduit
Height	Width	Depth	Weight
28.75"	26"	55"	145lbs

Model #	Stock #	Description	Capacity
BD1000R	64602501	BENDdolly™ 3/4"-1" GRC/IMC Bender	3/4"-1" GRC/IMC Conduit
Height	Width	Depth	Weight
28.75"	26"	55"	140lbs