



Southwire™

RIGID CONDUIT BODIES

THREADED LB TYPE - MALLEABLE IRON

FEATURES

- NPT tapered hubs
- Suitable for use in concrete

APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

STANDARD MATERIAL

- Malleable iron

STANDARD FINISH


- Zinc plated, aluminum enameled

CERTIFICATIONS

- UL Standard: UL 514A
- Fed. Spec: W-C-586D
- NEMA: FB 1



LB1M

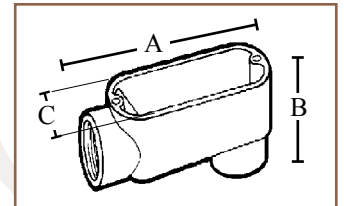

PART #	SIZE	WIRE SIZE		MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
		MAX. NUMBER	MAX. SIZE					
LB1M	1/2"	---	---	10	7	4.56"	2.06"	1.31"
LB2M	3/4"	3	6 AWG	10	9	5.31"	2.37"	1.48"
LB3M	1"	3	4 AWG	5	6	6.25"	2.63"	1.75"
LB4M	1-1/4"	3	2 AWG	5	23	8.22"	3.50"	2.40"
LB5M	1-1/2"	3	1/0 AWG	10	26	8.22"	3.75"	2.40"
LB6M	2"	3	4/0 AWG	5	26	10.48"	4.31"	3.05"
LB7M	2-1/2"	3	300 MCM	1	10	13.75"	4.45"	4.38"
LB8M	3"	3	350 MCM	1	13	13.75"	4.45"	4.38"
LB9M	3-1/2"	3	500 MCM	1	22	16.75"	5.80"	5.63"
LB10M	4"	3	500 MCM	1	24	16.75"	5.80"	5.63"

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.