



Southwire™

BX, FLEX CONNECTORS

90° - SQUEEZE TYPE WITH INSULATED THROAT - ZINC

FEATURES

- Squeeze type with insulated throat

APPLICATION

- Indoor use only
- In a dry location, use to connect flexible metallic conduit, AC and steel MC cable to a steel outlet box or other metal enclosure
- 3/8" size fits 1/2" knockout
- Suitable For: 3/8" - 3/4" steel and aluminum armored cable, steel and aluminum interlocked metal clad cable, flexible cord, and 1" - 2" flexible metallic conduit

STANDARD MATERIAL

- Zinc die cast


CERTIFICATIONS

- cULus



1001

PART #	CONDUIT SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B (MIN. - MAX.)	C	SCREWS
1001	3/8" 1/2" KO	50	500	45	1.74"	.43" - .72"	.37"	2
1011	1/2"	25	250	35	2.11"	.64" - 1.03"	.40"	2
1021	3/4"	10	100	20	2.40"	.76" - 1.15"	.40"	2
1031	1"	5	50	19	2.87"	1.09" - 1.73"	.54"	2
1041	1-1/4"	10	40	20	4"	1.34" - 1.97"	.64"	2
1051	1-1/2"	---	5	5	6"	1.65" - 2.61"	.75"	2
1061	2"	---	5	6	6"	1.54" - 2.54"	.74"	2

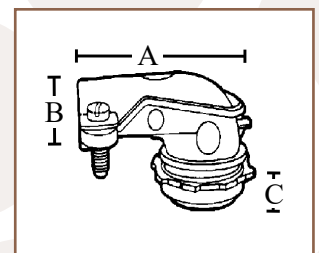

Rev. 0, 02/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.