



# Southwire™

## BX, FLEX CONNECTORS

### 90° - SQUEEZE TYPE WITH INSULATED THROAT - MALLEABLE IRON

#### FEATURES

- Squeeze type with insulated throat

#### APPLICATION

- Indoor use only
- In a dry location, use to connect flexible metallic conduit, AC and steel MC cable to a steel outlet box or other metal enclosure

#### STANDARD MATERIAL

- Malleable iron

#### STANDARD FINISH

- Zinc plated


#### CERTIFICATIONS

- cULus



100MI

PART #	CONDUIT SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B (MIN. – MAX.)	C	SCREWS
101MI	1/2"	25	250	16	1.75"	.78" – .95"	.44"	2
102MI	3/4"	10	100	30	1.81"	.91" – 1.02"	.44"	2
103MI	1"	5	50	60	2.06"	1.25" – 1.38"	.56"	2
104MI	1-1/4"	5	50	76	2.81"	1.41" – 1.63"	.56"	2
105MI	1-1/2"	---	5	100	3.81"	1.75" – 2"	.56"	2
106MI	2"	---	5	200	4.75"	2.19" – 2.44"	.69"	2
107MI	2-1/2"	---	5	320	6.25"	2.75" – 3"	.88"	4
108MI	3"	---	2	450	7.25"	3.25" – 3.50"	1"	4
109MI	3-1/2"	---	1	1400	10.25"	3.70" – 4.16"	1.25"	4
110MI	4"	---	1	2400	13"	4.11" – 4.56"	1.25"	4

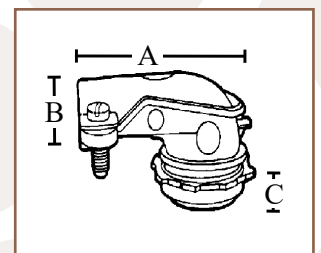

Rev. 0, 02/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.