



Southwire™

BX, FLEX CONNECTORS

90° - SQUEEZE TYPE - MALLEABLE IRON

FEATURES

- Squeeze type

APPLICATION

- Indoor use only
- In a dry location, use to connect flexible metallic conduit, AC and steel MC cable to a steel outlet box or other metal enclosure

STANDARD MATERIAL

- Malleable iron

STANDARD FINISH

- Zinc plated


CERTIFICATIONS

- cULus



100M

PART #	CONDUIT SIZE	INNER QTY.	MASTER QTY.	WEIGHT/CASE (LBS.)	A	B (MIN. – MAX.)	C	SCREWS
100M	3/8" 1/2" KO	25	250	40	1.75"	.78" – .95"	.44"	2
101M	1/2"	25	250	40	1.75"	.78" – .95"	.44"	2
102M	3/4"	10	100	30	1.81"	.91" – 1.02"	.44"	2
103M	1"	5	50	30	2.06"	1.25" – 1.38"	.56"	2
104M	1-1/4"	5	20	38	2.81"	1.41" – 1.63"	.56"	2
105M	1-1/2"	---	5	5	3.81"	1.75" – 2"	.56"	2
106M	2"	---	5	10	4.75"	2.19" – 2.44"	.69"	2
107M	2-1/2"	---	5	16	6.25"	2.75" – 3"	.88"	4
108M	3"	---	2	9	7.25"	3.25" – 3.50"	1"	4
109M	3-1/2"	---	1	14	10.25"	3.70" – 4.16"	1.25"	4
110M	4"	---	1	24	13"	4.11" – 4.56"	1.25"	4

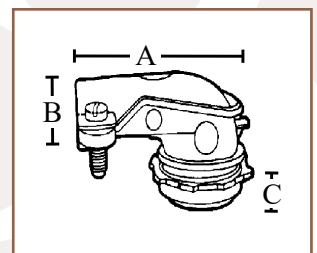

Rev. 0, 02/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.