




Southwire™

TOOLS & EQUIPMENT

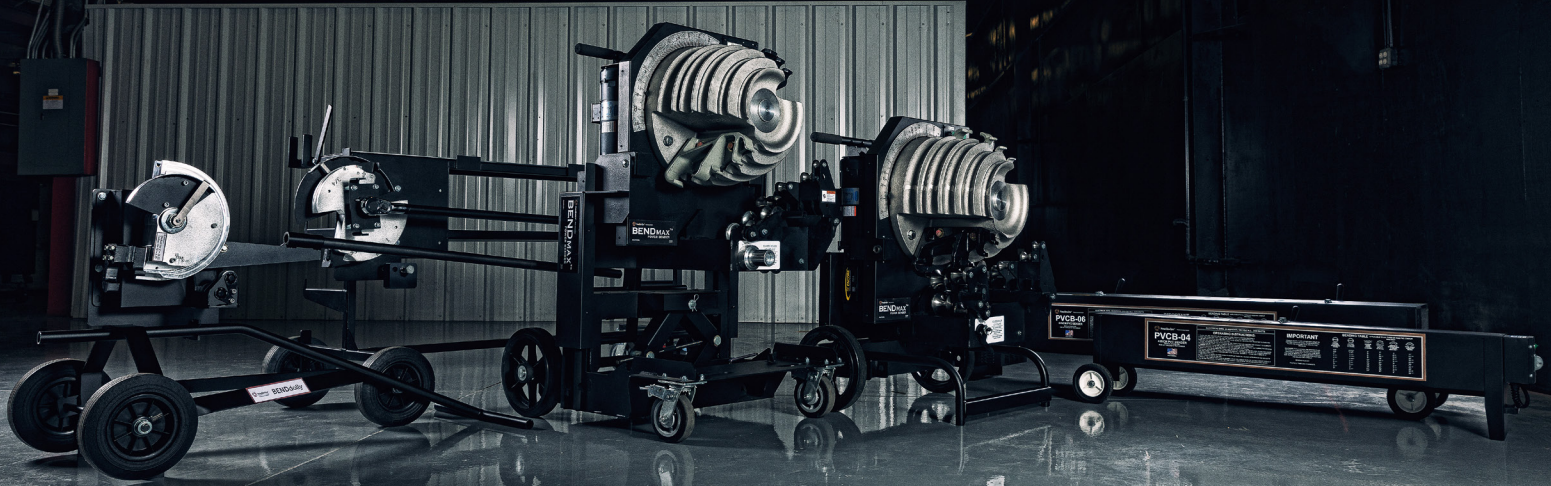

BENDING MADE EASY

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRETOOLS.COM

©2018 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



Southwire™ TOOLS & EQUIPMENT

BENDING MADE EASY


We don't just help you bend conduit—we change the way you do it. Southwire now carries a full line of traditional conduit bending tools, allowing you to bend 1/2"-2" EMT, IMC and GRC conduit more efficiently.

BENDMAX™ POWER BENDER

**POWER BENDER FOR 3/4" - 2" EMT, IMC,
GRC CONDUIT**

NEW NOW WITH AUTOSTOP

- Easily adjustable to ergonomic working height
- 3/4" - 2" EMT, IMC, GRC conduit bender
- 2 degree leveling adjustment
- Industrial grade DC drive and electrical components
- Push cart mounted platform
- Includes free standing conduit roller support
- Total lock casters
- Programmable spring back incorporated into digital readout
- Large analog protractor for accurate bends
- Backlit digital display
- Billet aluminum hand pendant
- Easily replaceable control cable

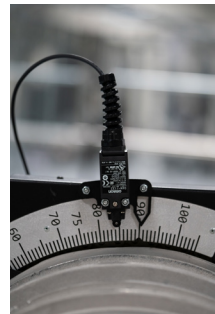

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

BENDMAX™

COMPACT POWER BENDER


**COMPACT POWER BENDER FOR 3/4" - 2"
EMT, IMC/GRC CONDUIT**

AUTOSTOP ACCESSORY NOW AVAILABLE

- Bends 3/4" - 2" EMT, IMC and GRC conduits
- Double sided shoe for EMT and IMC/GRC conduit
- Large analog protractor for accurate bends
- Push cart mounted platform
- Industrial-grade DC drive and electrical components
- Adjustable squeeze setting for wrinkle-free bends on EMT/IMC conduit
- Durable locking casters
- Fits through finished 30" door frames
- Durable two-position hand pendant
- Completely assembled, no gang boxes to deal with



*sold separately item

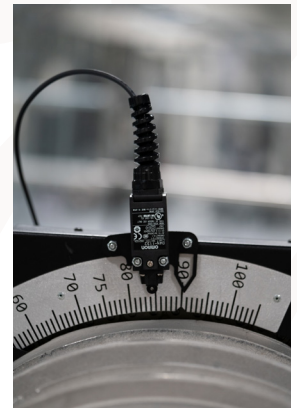

1-855-798-6657 | SOUTHWIRETOOLS.COM

©2018 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



Southwire™

TOOLS & EQUIPMENT

BENDSTATION™ COMMON CART WORK STATION

Southwire's BENDstation™ line includes an adaptable cart platform with four shoes for bending a wide variety of conduit. This purpose built tool can increase efficiency up to 30% over traditional hand benders.

COMPREHENSIVE CONDUIT BENDING WORKSTATION

- More accurate measurements, bends, and cuts
- Built-in protractor for quick and accurate bends
- Measure, bend, clamp, and cut at a comfortable 36" work table height for reduced labor fatigue
- Store up to 1000 feet of conduit or strut
- Extra shelf for storage of tools and materials
- Heavy duty casters for easy transportation and mobility
- Multiple Bending shoe design accepts bending heads 1/2"- 1 1/4" EMT, 3/4"-1" IMC and GRC
- Requires up to 40% less effort than other mechanical benders
- Multi-position Vise for cutting and threading operations
- Built-in 60" ruler for quick and accurate measuring



We've got it
MADE IN AMERICA™



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

SPECIFICATIONS

MODEL #	STOCK #	DESCRIPTION	LENGTH	WIDTH	HEIGHT	WEIGHT
BSCC01	647952	BENDSTATION™ Common Cart	69"	29"	38.5"	170 lb.
RB1000	598407	BENDSTATION™ for 3/4" and 1" GRC and IMC	69"	29"	38.5"	180 lb.
MB1250	647951	BENDSTATION™ for 1" and 1.25" EMT	69"	29"	38.5"	185 lb.
MB1000	643069	BENDSTATION™ for 3/4" and 1" EMT	69"	29"	38.5"	150 lb.
MB750	583152	BENDSTATION™ for 1/2" and 3/4" EMT	69"	29"	38.5"	132 lb.

BENDING SHOE HEAD KITS

MODEL #	STOCK #	DESCRIPTION	LENGTH	WIDTH	HEIGHT	WEIGHT
RBCCH-1000	643166	Head Kit for 3/4" - 1" GRC and IMC	9.20"	17.45"	20.80"	80 lb.
MBCCH-750	646010	Head Kit for 1/2" - 3/4" EMT	7.60"	16.13"	14.87"	32 lb.
MBCCH-1000	643167	Head Kit for 3/4" - 1" EMT	8.70"	16.63"	16.61"	49 lb.
MBCCH-1250	647953	Head Kit for 1" - 1.25" EMT	10"	12.75"	15.23"	86 lb.



1-855-798-6657 | SOUTHWIRETOOLS.COM

©2018 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



Southwire™

TOOLS & EQUIPMENT

BENDDOLLY™ BENDING PLATFORM

MECHANICAL BENDING PLATFORM

- Light weight bending platform
- Interchangeable shoe mounting plate
- Large dolly wheels for easy maneuverability
- Stable bending platform
- Interchangeable EMT shoes and IMC/GRC shoes
- Durable black powder coating for increased corrosion resistance
- Accepts four different Southwire bending shoes
- Upright storage position



We've got it
MADE IN AMERICA™



*Shown with RB1000
Rigid Shoe


**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

SPECIFICATIONS

MODEL #	STOCK #	DESCRIPTION		
BD-01	646011	BEND <i>dolly</i> ™ Bending Platform		
BD1000R	646025	BEND <i>dolly</i> ™ 3/4" - 1" GRC IMC Bender		
BD750E	646023	BEND <i>dolly</i> ™ 1/2" - 3/4" EMT Bender		
BD1000E	646024	BEND <i>dolly</i> ™ 3/4" - 1" EMT Bender		
BD1250E	646024	BEND <i>dolly</i> ™ 1" - 1.25" EMT Bender		
	LENGTH	WIDTH	HEIGHT	WEIGHT
BD-01	55"	26"	28.75"	60 lb.
BD1000R	55"	26"	28.75"	140 lb.
BD750E	55"	26"	28.75"	92 lb.
BD1000E	55"	26"	28.75"	110 lb.
BD1250E	55"	26"	28.75"	145 lb.

BENDING SHOE HEAD KITS

MODEL #	STOCK #	DESCRIPTION		
MBCCH-750	646010	Head Kit for 1/2"-3/4" EMT		
MBCCH-1000	643167	Head Kit for 3/4"-1" EMT		
MBCCH-1250	647953	Head Kit for 1"-1.25" EMT		
RBCCH-1000	643166	Head Kit for 3/4"-1" GRC/IMC		
	HEIGHT	WIDTH	DEPTH	WEIGHT
MBCCH-750	14.87"	16.13"	7.60"	32 lb.
MBCCH-1000	16.61"	16.63"	8.70"	49 lb.
MBCCH-1250	15.23"	12.75"	10"	85 lb.
RBCCH-1000	20.80"	17.45"	9.20"	80 lb.

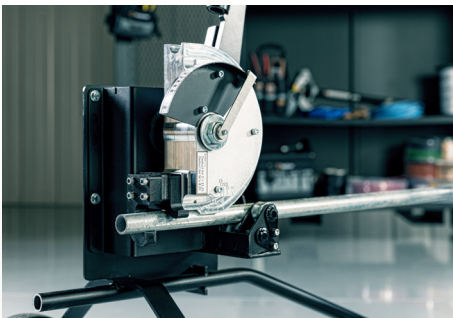



Southwire™

TOOLS & EQUIPMENT

PVCB-06M

1/2" TO 6" PVC MOTORIZED BENDER

- Durable black powder coating for increased corrosion resistance
- Solid 6" wheels for easy maneuverability
- Chrome plated reflectors for maximum reflection of infrared energy for a faster bend
- Label includes NEC bending tables
- Bright red indicator light to advise when unit is turned "ON"



PVCB-06

1/2" TO 6" PVC BENDER

- Durable black powder coating for increased corrosion resistance
- Solid 6" wheels for easy maneuverability
- Chrome plated reflectors for maximum reflection of infrared energy for a faster bend
- Label includes NEC bending tables
- Bright red indicator light to advise when unit is turned "ON"



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

PVCB-04

1/2" TO 4" PVC BENDER

- Durable black powder coating for increased corrosion resistance
- Solid 6" wheels for easy maneuverability
- Chrome plated reflectors for maximum reflection of infrared energy for a faster bend
- Label includes NEC bending tables
- Bright green indicator light to advise when unit is turned "ON"



PVCB-02

1/2" TO 2" PVC BENDER

- Durable black powder coating for increased corrosion resistance
- Chrome plated reflectors for maximum reflection of infrared energy for a faster bend
- Label includes NEC bending tables
- Bright green indicator light to advise when unit is turned "ON"



PLUG KIT PVCP

PVCP-01 & PVCP-02

- Rugged carrying case to store and transport plugs
- Durable long-lasting neoprene gaskets
- Twist lock design for easy installation and removal
- Provides air tight seal
- Prevents conduit from collapsing when heated



1-855-798-6657 | SOUTHWIRETOOLS.COM

©2018 Southwire Company, LLC. All rights reserved.
*Registered Trademark & TMTrademark of Southwire Company, LLC.



Southwire™

TOOLS & EQUIPMENT

CONDUIT BENDERS

- Durable cast metal heads
- Swaged steel handle permits insertion of conduit to correct overbends
- Raised and highly visible bender markings are cast on both sides of the bender head
- Large serrated step provides greater control and helps prevent slipping when applying force



SPECIFICATIONS

MODEL #	STOCK #	DESCRIPTION			
MCB1	582814	1" EMT Conduit Bender with Handle (Ductile Iron Head)			
MCB3/4	582812	3/4" EMT Conduit Bender with Handle (Aluminum Head)			
MCB1/2	582813	1/2" EMT Conduit Bender with Handle (Aluminum Head)			
	HEIGHT	WIDTH	DEPTH	WEIGHT	CONDUIT SIZE
MCB1	1.75"	12"	45"	13 lb.	1" EMT, 3/4" Rigid
MCB3/4	1.25"	9"	39"	9 lb.	3/4" EMT, 1/2" Rigid
MCB1/2	1.25"	8"	39"	7 lb.	1/2" EMT

12" & 14" HAND CABLE BENDER



- Black oxide finish for corrosion resistance
- Dipped grip handles
- Forged one-piece design
- High strength steel
- 12" 350 MCM cable capacity
- 14" 500 MCM cable capacity

12" SPECIFICATIONS

MODEL #	STOCK #	DESCRIPTION			
CB12-350	587391	CB12-350 12" 350 MCM Hand Cable Bender			
	HEIGHT	WIDTH	DEPTH	WEIGHT	
CB12-350	12"	1.86"	.85"	0.95 lb.	

14" SPECIFICATIONS

MODEL #	STOCK #	DESCRIPTION			
CB14-500	587392	CB14-500 14" 500 MCM Hand Cable Bender			
	HEIGHT	WIDTH	DEPTH	WEIGHT	
CB14-500	14.25"	2.22"	1.35"	1.6 lb.	

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**



SIMpull™ NON-CONDUCTIVE TIP FISH TAPE

- 75', 100', 125' non-conductive tip fish tape
- High impact, durable case for lasting durability and use
- Non-conductive leader reduces risk of damage to wire jackets
- Leader glows in the dark for easier tracking on low-light conditions
- Spiral extruded polymer allows for faster install time
- Spiral extruded polymer does not rust and will not break when folded
- Weighs less than steel
- 40% lower coefficient of friction than Southwire steel fish tape



SIMpull™ FLEXIBLE METAL LEADER FISH TAPE

- 75', 100', 125' flexible metal leader tip fish tape
- High impact, durable case for lasting durability and use
- 360° swiveling leader for ease of guidance through turns
- Spiral extruded polymer allows for faster install time
- Spiral extruded polymer does not rust and will not break when folded
- Weighs less than steel
- 40% lower coefficient of friction than Southwire steel fish tape




1-855-798-6657 | SOUTHWIRETOOLS.COM

©2018 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



Southwire™

TOOLS & EQUIPMENT

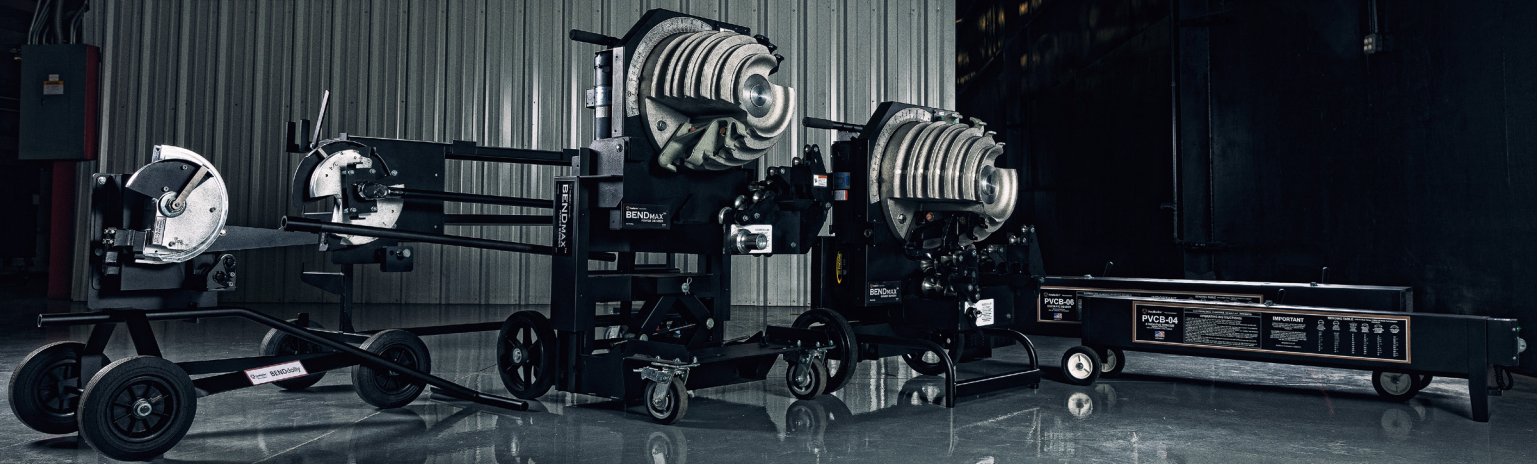

GET SOCIAL WITH US:



**/SOUTHWIRETOOLS
/SOUTHWIRETOOLSLATINO**



@SOUTHWIRETOOLS



@SOUTHWIRETOOLS



SOUTHWIRETOOLS

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRETOOLS.COM

©2018 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.