



Southwire™

RIGID CONDUIT NIPPLES

MALLEABLE IRON

FEATURES

- Threaded NPSM for Rigid conduit and IMC
- Use with locknuts
- Also available with insulated throat

APPLICATION

- Serves as a short raceway between enclosures

STANDARD MATERIAL


- Malleable iron



751M



PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
751M	1/2"	100	1000	47	.68"	1.02"
752M	3/4"	50	500	33	.75"	1.29"
753M	1"	25	250	29	.87"	1.53"
754M	1-1/4"	25	250	51	.94"	1.89"
755M	1-1/2"	10	100	27	.91"	2.30"
756M	2"	10	40	14	1.07"	2.88"
757M	2-1/2"	10	40	23	1.38"	3.39"
758M	3"	10	40	7	1.44"	4.06"
759M	3-1/2"	10	40	11	1.47"	4.61"
760M	4"	5	20	27	1.47"	5.15"
760A	5"	---	1	3	2.352"	6"
760B	6"	---	1	4	2.18"	7"

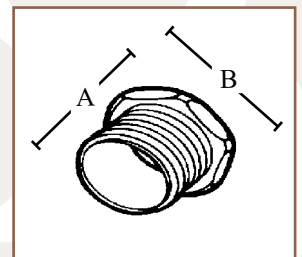

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.