



**Southwire™**

TOOLS & EQUIPMENT





# **BASKET GRIPS**

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

**1-855-798-6657 | SOUTHWIRETOOLS.COM**

©2018 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.

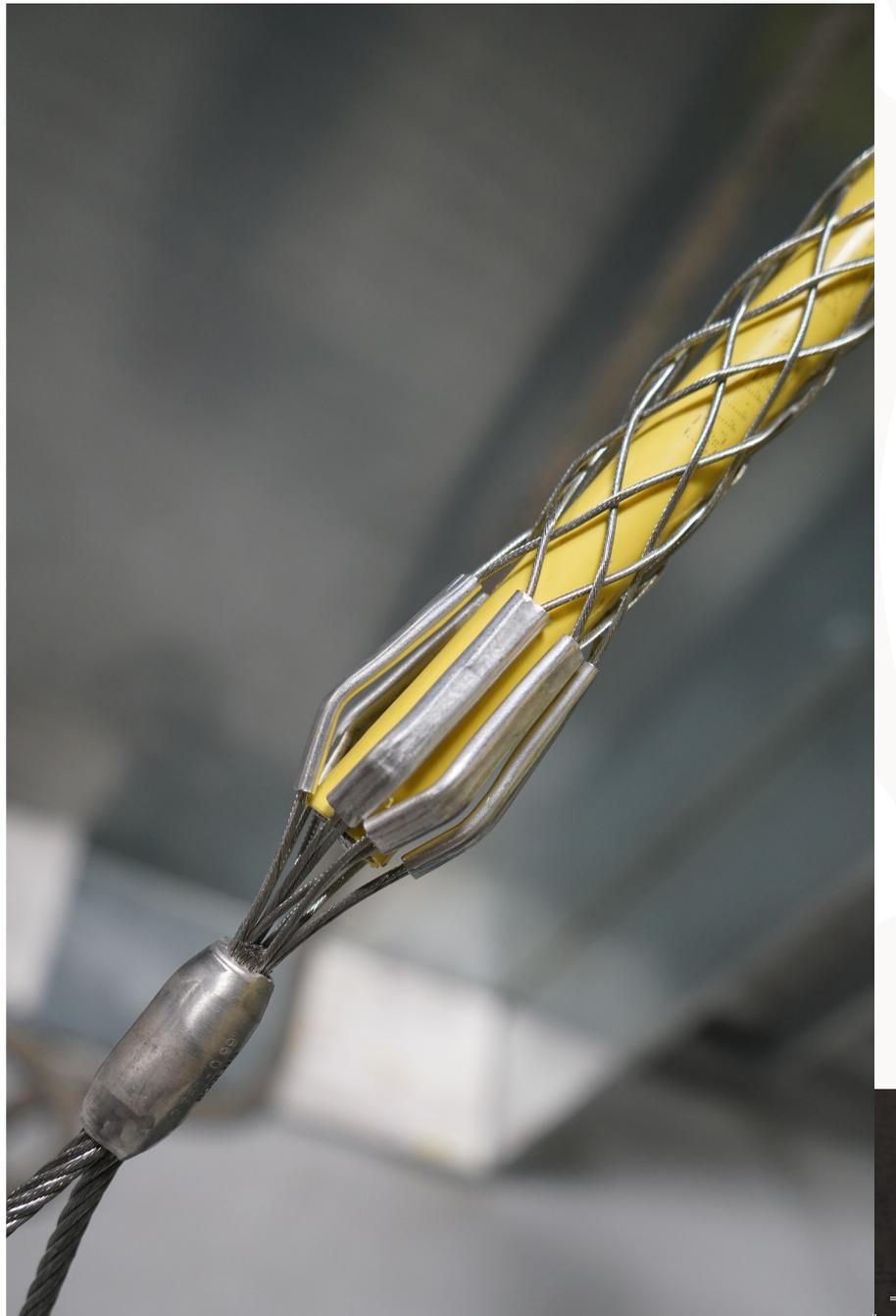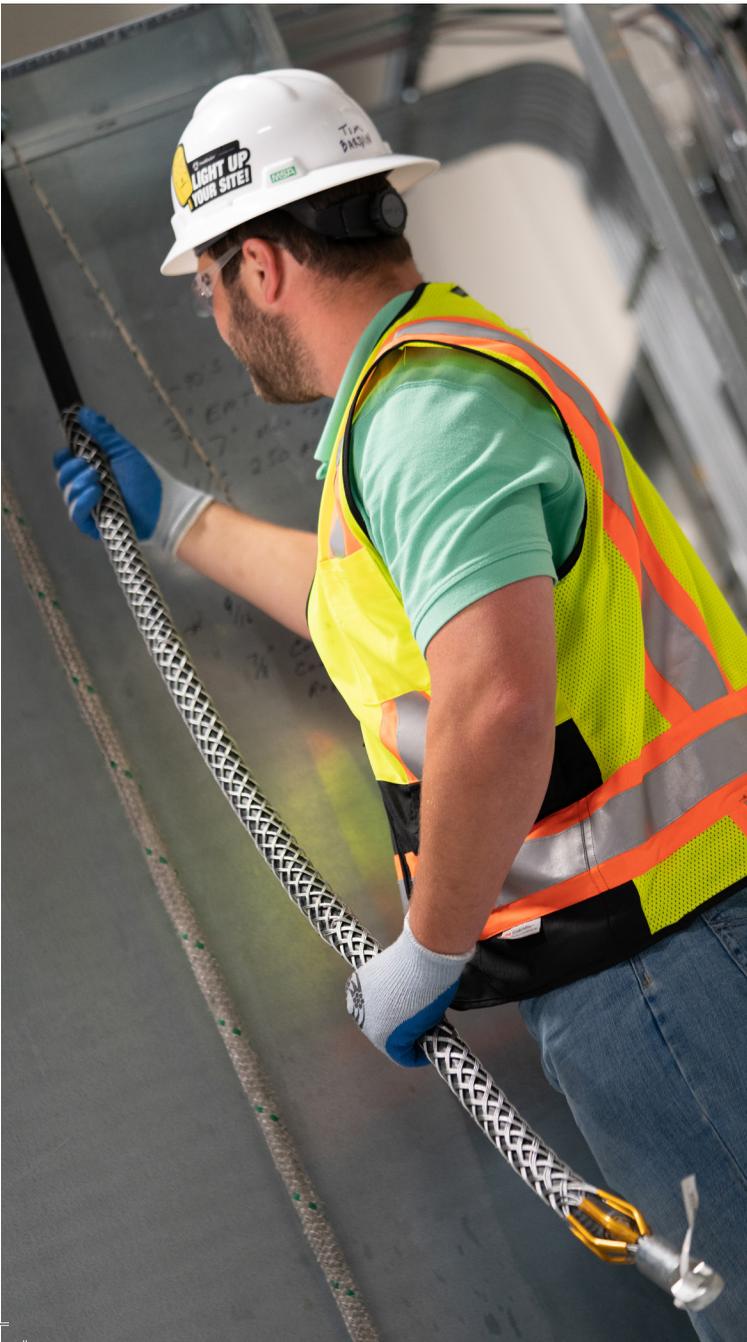


# JUNIOR BASKET GRIPS

The Junior Basket Grip will save you time by eliminating cutting, stripping or weaving to make your own pulling head. It features a durable galvanized weather-resistant steel, single weave mesh, that will not corrode. A flexible, low-profile eye that easily attaches to the pulling line, snake or fish tape and easily moves through conduit 90° bends. This basket grip is Ideal for pulling single cable or cable bundles over building wire.

Model Number	UPC	Stock Number	Description	Working Load Lbs.	Cable Diameter Range
JBG-024	0-32886-69795-1	650173	Junior Basket Grip 0.19" - 0.24"	Max Rated Capacity: 80 lbs.	0.19" - 0.24"
JBG-036	0-32886-69796-8	650174	Junior Basket Grip 0.25" - 0.36"	Max Rated Capacity: 90 lbs.	0.25" - 0.36"
JBG-049	0-32886-69797-5	650175	Junior Basket Grip 0.37" - 0.49"	Max Rated Capacity: 180 lbs.	0.37" - 0.49"
JBG-061	0-32886-69798-2	650177	Junior Basket Grip 0.50" - 0.61"	Max Rated Capacity: 260 lbs.	0.50" - 0.61"
JBG-074	0-32886-69799-9	650178	Junior Basket Grip 0.62" - 0.74"	Max Rated Capacity: 390 lbs.	0.62" - 0.74"
JBG-099	0-32886-69800-2	650179	Junior Basket Grip 0.75" - 0.99"	Max Rated Capacity: 560 lbs.	0.75" - 0.99"
JBG-124	0-32886-69801-9	650180	Junior Basket Grip 1.00" - 1.24"	Max Rated Capacity: 780 lbs.	1.00" - 1.24"

## Features & Benefits

- Single weave steel mesh
- Low profile head eliminates the problem of the head not fitting in the conduit or around a tight turn
- Easily moves through conduit and around 90° bends
- Reusable pulling head
- Galvanized finish for Corrosion and Weather Resistance
- No cutting, stripping or weaving of wire to make pulling head
- Saves time making pulling heads

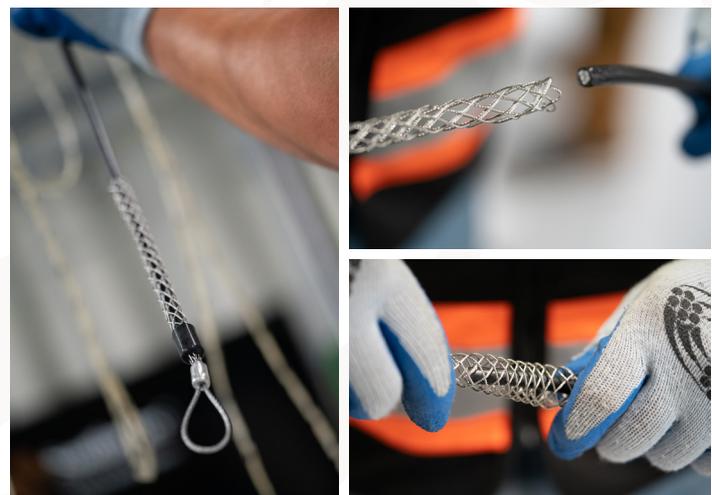

1-855-798-6657 | [SOUTHWIRETOOLS.COM](http://SOUTHWIRETOOLS.COM)

©2018 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & <sup>TM</sup>Trademark of Southwire Company, LLC.



Southwire  
**MAXIS XD**  
EXTREME DUTY

# LIGHT DUTY BASKET GRIPS

The Light Duty Basket Grip will save you time by eliminating cutting, stripping or weaving to make your own pulling head. It features a durable galvanized weather-resistant steel, single weave mesh, that will not corrode. A flexible, low-profile eye that easily attaches to the pulling line, snake or fish tape and easily moves through conduit 90° bends. This basket grip is ideal for general lighter pulling jobs.

Model Number	UPC	Stock Number	Description	Working Load Lbs.	Cable Diameter Range
LBG-061	0-32886-69802-6	650181	Light Duty Basket Grip 0.50" - 0.61"	Max Rated Capacity: 560 lbs.	0.50" - 0.61"
LBG-074	0-32886-69803-3	650182	Light Duty Basket Grip 0.62" - 0.74"	Max Rated Capacity: 560 lbs.	0.62" - 0.74"
LBG-099	0-32886-69804-0	650183	Light Duty Basket Grip 0.75" - 0.99"	Max Rated Capacity: 800 lbs.	0.75" - 0.99"
LBG-124	0-32886-69805-7	650185	Light Duty Basket Grip 1.00" - 1.24"	Max Rated Capacity: 1360 lbs.	1.00" - 1.24"
LBG-149	0-32886-69806-4	650186	Light Duty Basket Grip 1.25" - 1.49"	Max Rated Capacity: 1360 lbs.	1.25" - 1.49"
LBG-199	0-32886-69807-1	650187	Light Duty Basket Grip 1.50" - 1.99"	Max Rated Capacity: 1360 lbs.	1.50" - 1.99"
LBG-249	0-32886-69808-8	650188	Light Duty Basket Grip 2.00" - 2.49"	Max Rated Capacity: 1700 lbs.	2.00" - 2.49"
LBG-299	0-32886-69809-5	650189	Light Duty Basket Grip 2.50" - 2.99"	Max Rated Capacity: 2120 lbs.	2.50" - 2.99"
LBG-349	0-32886-69810-1	650190	Light Duty Basket Grip 3.00" - 3.49"	Max Rated Capacity: 2940 lbs.	3.00" - 3.49"
LBG-399	0-32886-69811-8	650191	Light Duty Basket Grip 3.5" - 3.99"	Max Rated Capacity: 2940 lbs.	3.5" - 3.99"

## Features & Benefits

- Single weave steel mesh
- Low profile head eliminates the problem of the head not fitting in the conduit or around a tight turn
- Easily moves through conduit and around 90° bends
- Reusable pulling head
- Galvanized finish for Corrosion and Weather Resistance
- No cutting, stripping or weaving of wire to make pulling head
- Saves time making pulling heads



**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**


# “T-TYPE” SHORT BASKET GRIPS

The “T-Type” Short Basket Grips will save you time by eliminating cutting, stripping or weaving to make your own pulling head. It features a durable galvanized weather-resistant steel, double weave mesh for extra pulling strength, which will not corrode. A flexible, low-profile eye that easily attaches to the pulling line, snake or fish tape and easily moves through conduit 90° bends. This basket grip is Ideal for medium pulls on construction sites and underground electrical projects.

Model Number	UPC	Stock Number	Description	Working Load Lbs.	Cable Diameter Range
SHBG-061	0-32886-69812-5	650193	Short Basket Grip 0.50" - 0.61"	Max Rated Capacity: 900 lbs.	0.50" - 0.61"
SHBG-074	0-32886-69813-2	650194	Short Basket Grip 0.62" - 0.74"	Max Rated Capacity: 1120 lbs.	0.62" - 0.74"
SHBG-099	0-32886-69814-9	650195	Short Basket Grip 0.75" - 0.99"	Max Rated Capacity: 1360 lbs.	0.75" - 0.99"
SHBG-149	0-32886-69815-6	650196	Short Basket Grip 1.00" - 1.49"	Max Rated Capacity: 1920 lbs.	1.00" - 1.49"
SHBG-199	0-32886-69816-3	650197	Short Basket Grip 1.50" - 1.99"	Max Rated Capacity: 3280 lbs.	1.50" - 1.99"
SHBG-249	0-32886-69817-0	650198	Short Basket Grip 2.00" - 2.49"	Max Rated Capacity: 3700 lbs.	2.00" - 2.49"
SHBG-299	0-32886-69818-7	650199	Short Basket Grip 2.50" - 2.99"	Max Rated Capacity: 4900 lbs.	2.50" - 2.99"
SHBG-349	0-32886-69819-4	650201	Short Basket Grip 3.00" - 3.49"	Max Rated Capacity: 4900 lbs.	3.00" - 3.49"
SHBG-399	0-32886-69820-0	650202	Short Basket Grip 3.50" - 3.99"	Max Rated Capacity: 6200 lbs.	3.50" - 3.99"

## Features & Benefits

- Double weave steel mesh
- Low profile head eliminates the problem of the head not fitting in the conduit or around a tight turn
- Easily moves through conduit and around 90° bends
- Reusable pulling head
- Galvanized finish for Corrosion and Weather Resistance
- No cutting, stripping or weaving of wire to make pulling head
- Saves time making pulling heads

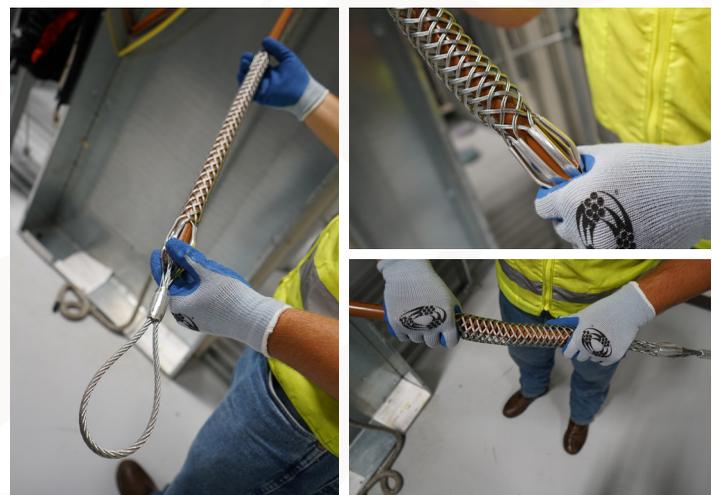

1-855-798-6657 | [SOUTHWIRETOOLS.COM](http://SOUTHWIRETOOLS.COM)

©2018 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & <sup>TM</sup>Trademark of Southwire Company, LLC.




# “T-TYPE” STANDARD BASKET GRIPS

The Standard “T-Type” Basket Grip will save you time by eliminating cutting, stripping or weaving to make your own pulling head. It features a durable galvanized weather-resistant steel, double weave mesh for extra pulling strength, which will not corrode. A flexible, low-profile eye that easily attaches to the pulling line, snake or fish tape and easily moves through conduit 90° bends. This basket grip is Ideal for general pulls on construction sites and underground electrical projects.

Model Number	UPC	Stock Number	Description	Working Load Lbs.	Cable Diameter Range
STBG-099	0-32886-69821-7	650203	Standard Basket Grip 0.75" - 0.99"	Max Rated Capacity: 1360 lbs.	0.75" - 0.99"
STBG-149	0-32886-69822-4	650204	Standard Basket Grip 1.00" - 1.49"	Max Rated Capacity: 1920 lbs.	1.00" - 1.49"
STBG-199	0-32886-69823-1	650205	Standard Basket Grip 1.50" - 1.99"	Max Rated Capacity: 3280 lbs.	1.50" - 1.99"
STBG-249	0-32886-69824-8	650206	Standard Basket Grip 2.00" - 2.49"	Max Rated Capacity: 3700 lbs.	2.00" - 2.49"
STBG-299	0-32886-69825-5	650207	Standard Basket Grip 2.50" - 2.99"	Max Rated Capacity: 4900 lbs.	2.50" - 2.99"
STBG-349	0-32886-69826-2	650208	Standard Basket Grip 3.00" - 3.49"	Max Rated Capacity: 4900 lbs.	3.00" - 3.49"
STBG-399	0-32886-69827-9	650209	Standard Basket Grip 3.50" - 3.99"	Max Rated Capacity: 6200 lbs.	3.50" - 3.99"

### Features & Benefits

- Double weave steel mesh
- Low profile head eliminates the problem of the head not fitting in the conduit or around a tight turn
- Easily moves through conduit and around 90° bends
- Reusable pulling head
- Galvanized finish for Corrosion and Weather Resistance
- No cutting, stripping or weaving of wire to make pulling head
- Saves time making pulling heads

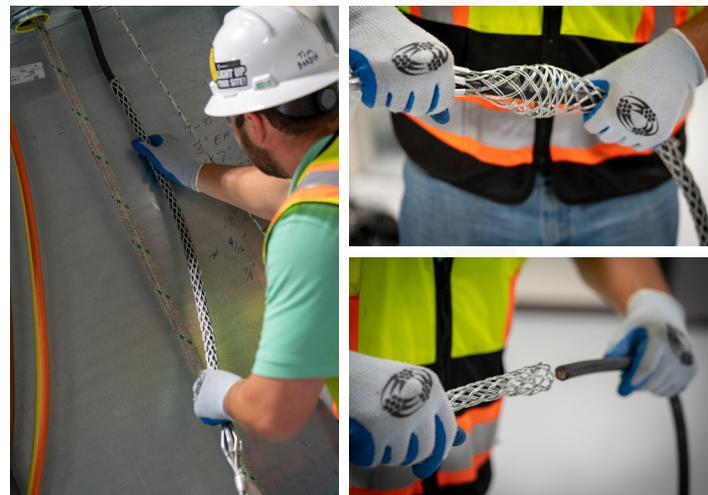

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

# K-BASKET GRIP

The K-Basket Grip will save you time by eliminating cutting, stripping or weaving to make your own pulling head. It features a durable galvanized weather-resistant steel, double weave mesh for extra pulling strength, which will not corrode. A flexible, low-profile swiveling eye that easily attaches to the pulling line, snake or fish tape and easily moves through conduit 90° bends. The swiveling head reduces the likelihood of tangles during the pull. The double woven mesh makes this basket grip Ideal for longer heavier pulling jobs.

Model Number	UPC	Stock Number	Description	Working Load Lbs.	Cable Diameter Range
KBG-061	0-32886-69828-6	650210	K- Basket Grip 0.50" - 0.61"	Max Rated Capacity: 1120 lbs.	0.50" - 0.61"
KBG-074	0-32886-69829-3	650211	K- Basket Grip 0.62" - 0.74"	Max Rated Capacity: 1360 lbs.	0.62" - 0.74"
KBG-099	0-32886-69830-9	650212	K- Basket Grip 0.75" - 0.99"	Max Rated Capacity: 1920 lbs.	0.75" - 0.99"
KBG-149	0-32886-69831-6	650213	K- Basket Grip 1.00" - 1.49"	Max Rated Capacity: 3280 lbs.	1.00" - 1.49"
KBG-199	0-32886-69832-3	650214	K- Basket Grip 1.50" - 1.99"	Max Rated Capacity: 3280 lbs.	1.50" - 1.99"
KBG-249	0-32886-69833-0	650215	K- Basket Grip 2.00" - 2.49"	Max Rated Capacity: 5440 lbs.	2.00" - 2.49"
KBG-299	0-32886-69834-7	650216	K- Basket Grip 2.50" - 2.99"	Max Rated Capacity: 6600 lbs.	2.50" - 2.99"
KBG-349	0-32886-69835-4	650217	K- Basket Grip 3.00" - 3.49"	Max Rated Capacity: 8200 lbs.	3.00" - 3.49"
KBG-399	0-32886-69836-1	650219	K- Basket Grip 3.50" - 3.99"	Max Rated Capacity: 9600 lbs.	3.50" - 3.99"
KBG-449	0-32886-69837-8	650220	K- Basket Grip 4.00" - 4.49"	Max Rated Capacity: 9600 lbs.	4.00" - 4.49"
KBG-499	0-32886-69838-5	650221	K- Basket Grip 4.50" - 4.99"	Max Rated Capacity: 9600 lbs.	4.50" - 4.99"
KBG-599	0-32886-69839-2	650222	K- Basket Grip 5.00" - 5.99"	Max Rated Capacity: 9600 lbs.	5.00" - 5.99"

## Features & Benefits

- Double weave steel mesh
- Low profile head eliminates the problem of the head not fitting in the conduit or around a tight turn
- Easily moves through conduit and around 90° bends
- Reusable pulling head
- Galvanized finish for Corrosion and Weather Resistance
- No cutting, stripping or weaving of wire to make pulling head
- Saves time making pulling heads



1-855-798-6657 | [SOUTHWIRETOOLS.COM](http://SOUTHWIRETOOLS.COM)

©2018 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & <sup>TM</sup>Trademark of Southwire Company, LLC.




# SPLIT MESH BASKET GRIP

The Split Mesh Basket Grip will save you time by eliminating cutting, stripping or weaving to make your own pulling head. It features a durable galvanized weather-resistant steel, double weave mesh for extra pulling strength, that will not corrode and an offset eye for easy attachment to pulling lines. This basket grip is ideal for pulling when the cable end is not accessible.

Model Number	UPC	Stock Number	Description	Working Load Lbs.	Cable Diameter Range
SMBG-061	0-32886-69851-4	650236	Split Mesh Basket Grip 0.50" - 0.61"	Max Rated Capacity: 300 lbs.	0.50" - 0.61"
SMBG-074	0-32886-69852-1	650237	Split Mesh Basket Grip 0.62" - 0.74"	Max Rated Capacity: 360 lbs.	0.62" - 0.74"
SMBG-099	0-32886-69853-8	650238	Split Mesh Basket Grip 0.75" - 0.99"	Max Rated Capacity: 440 lbs.	0.75" - 0.99"
SMBG-124	0-32886-69854-5	650239	Split Mesh Basket Grip 1.00" - 1.24"	Max Rated Capacity: 680 lbs.	1.00" - 1.24"
SMBG-149	0-32886-69855-2	650240	Split Mesh Basket Grip 1.25" - 1.49"	Max Rated Capacity: 900 lbs.	1.25" - 1.49"
SMBG-174	0-32886-69856-9	650241	Split Mesh Basket Grip 1.50" - 1.74"	Max Rated Capacity: 1160 lbs.	1.50" - 1.74"
SMBG-199	0-32886-69857-6	650243	Split Mesh Basket Grip 1.75" - 1.99"	Max Rated Capacity: 1520 lbs.	1.75" - 1.99"
SMBG-249	0-32886-69858-3	650244	Split Mesh Basket Grip 2.00" - 2.49"	Max Rated Capacity: 1800 lbs.	2.00" - 2.49"
SMBG-299	0-32886-69859-0	650245	Split Mesh Basket Grip 2.50" - 2.99"	Max Rated Capacity: 2200 lbs.	2.50" - 2.99"
SMBG-349	0-32886-69860-6	650246	Split Mesh Basket Grip 3.00" - 3.49"	Max Rated Capacity: 2400 lbs.	3.00" - 3.49"
SMBG-399	0-32886-69861-3	650247	Split Mesh Basket Grip 3.50" - 3.99"	Max Rated Capacity: 2400 lbs.	3.50" - 3.99"

## Features & Benefits

- Double weave steel mesh
- Reusable pulling head
- Galvanized finish for Corrosion and Weather Resistance
- No cutting, stripping or weaving of wire to make pulling head
- Saves time making pulling heads

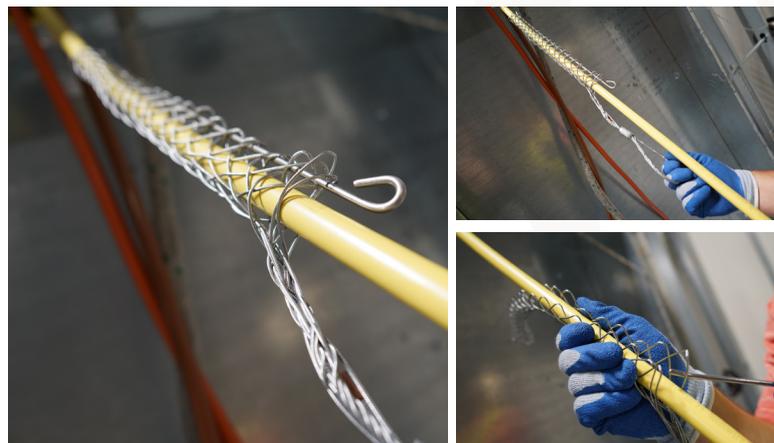

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**


# MULTI-STRENGTH BASKET GRIP

The Multi-Strength Basket Grip will save you time by eliminating cutting, stripping or weaving to make your own pulling head. It features a durable galvanized weather resistant steel that will not corrode, single to double to triple weaved mesh for extra pulling strength and a flexible and low-profile swiveling eye that easily attaches to the pulling line, snake or fish tape and easily moves through conduit 90° bends. The swiveling head reduces the likelihood of tangles during the pull. The triple woven mesh makes this basket grip ideal for longer heavier pulling jobs.

Model Number	UPC	Stock Number	Description	Working Load Lbs.	Cable Diameter Range
MBG-049	0-32886-69840-8	650223	Multi-Strength Basket Grip 0.25" - 0.49"	Max Rated Capacity: 1360 lbs.	0.25" - 0.49"
MBG-074	0-32886-69841-5	650224	Multi-Strength Basket Grip 0.50" - 0.74"	Max Rated Capacity: 2000 lbs.	0.50" - 0.74"
MBG-099	0-32886-69842-2	650225	Multi-Strength Basket Grip 0.75" - 0.99"	Max Rated Capacity: 2880 lbs.	0.75" - 0.99"
MBG-124	0-32886-69843-9	650227	Multi-Strength Basket Grip 1.00" - 1.24"	Max Rated Capacity: 4920 lbs.	1.00" - 1.24"
MBG-149	0-32886-69844-6	650228	Multi-Strength Basket Grip 1.25" - 1.49"	Max Rated Capacity: 6120 lbs.	1.25" - 1.49"
MBG-174	0-32886-69845-3	650229	Multi-Strength Basket Grip 1.50" - 1.74"	Max Rated Capacity: 6120 lbs.	1.50" - 1.74"
MBG-199	0-32886-69846-0	650230	Multi-Strength Basket Grip 1.75" - 1.99"	Max Rated Capacity: 9600 lbs.	1.75" - 1.99"
MBG-249	0-32886-69847-7	650231	Multi-Strength Basket Grip 2.00" - 2.49"	Max Rated Capacity: 9600 lbs.	2.00" - 2.49"
MBG-299	0-32886-69848-4	650232	Multi-Strength Basket Grip 2.50" - 2.99"	Max Rated Capacity: 9600 lbs.	2.50" - 2.99"
MBG-349	0-32886-69849-1	650233	Multi-Strength Basket Grip 3.00" - 3.49"	Max Rated Capacity: 9600 lbs.	3.00" - 3.49"
MBG-399	0-32886-69850-7	650235	Multi-Strength Basket Grip 3.50" - 3.99"	Max Rated Capacity: 9600 lbs.	3.50" - 3.99"


## Features & Benefits



- Triple to Double to Single weave steel mesh
- Low profile head eliminates the problem of the head not fitting in the conduit or around a tight turn
- Easily moves through conduit and around 90° bends
- Reusable pulling head
- Galvanized finish for Corrosion and Weather Resistance
- No cutting, stripping or weaving of wire to make pulling head
- Saves time making pulling heads

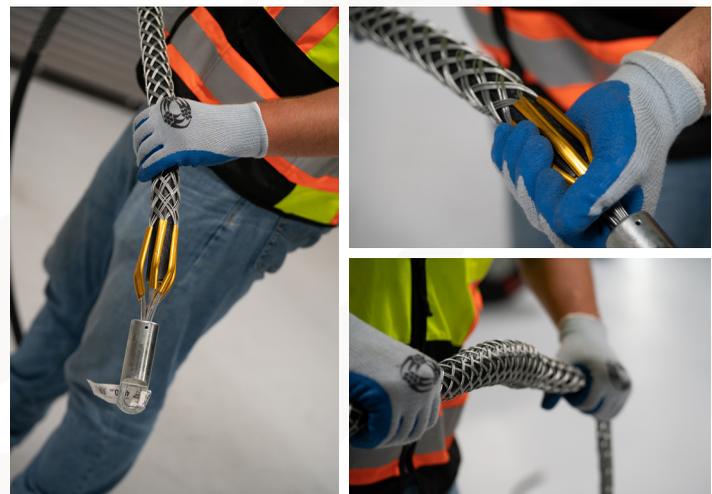

1-855-798-6657 | [SOUTHWIRETOOLS.COM](http://SOUTHWIRETOOLS.COM)

©2018 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & <sup>TM</sup>Trademark of Southwire Company, LLC.

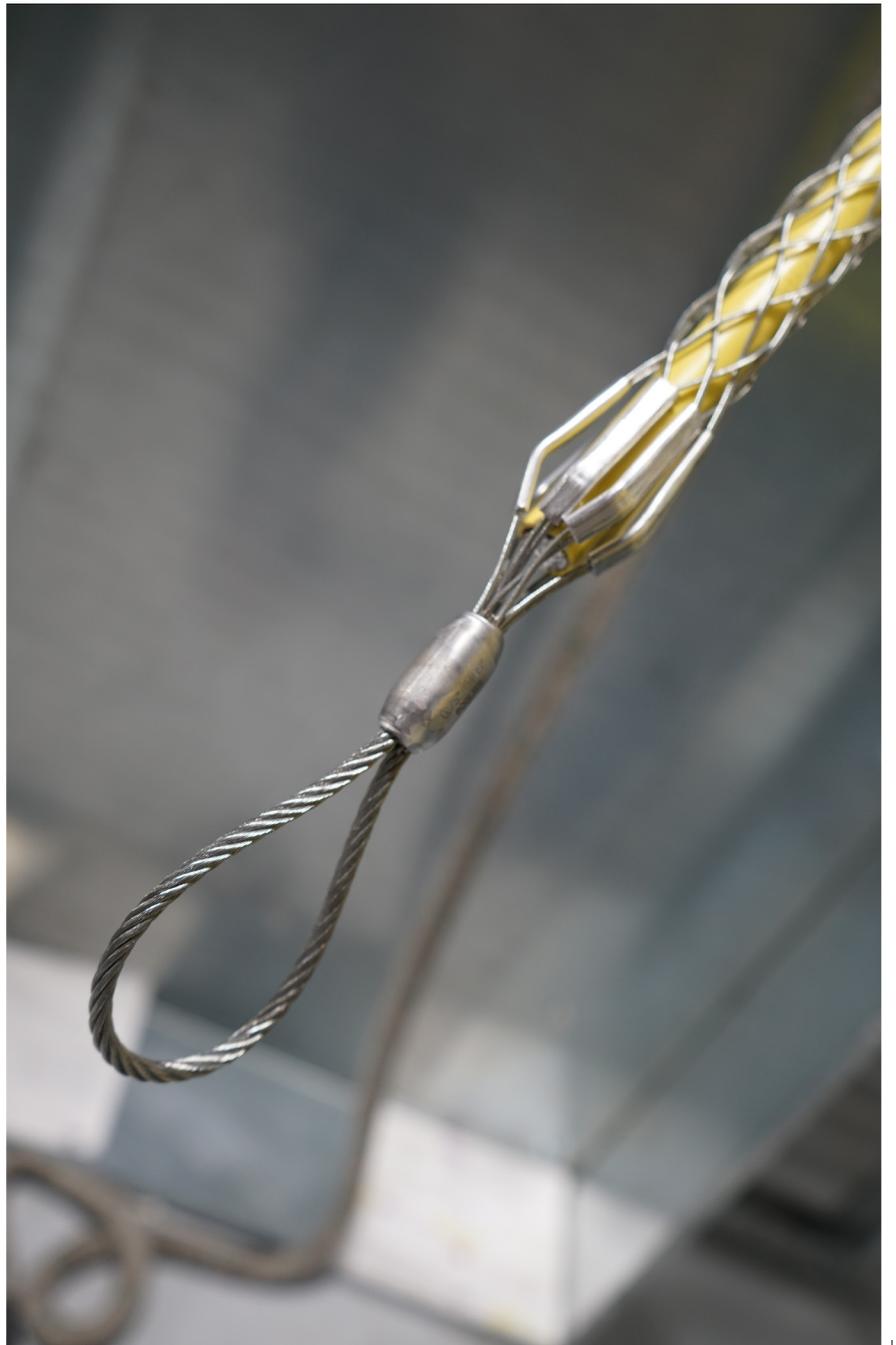


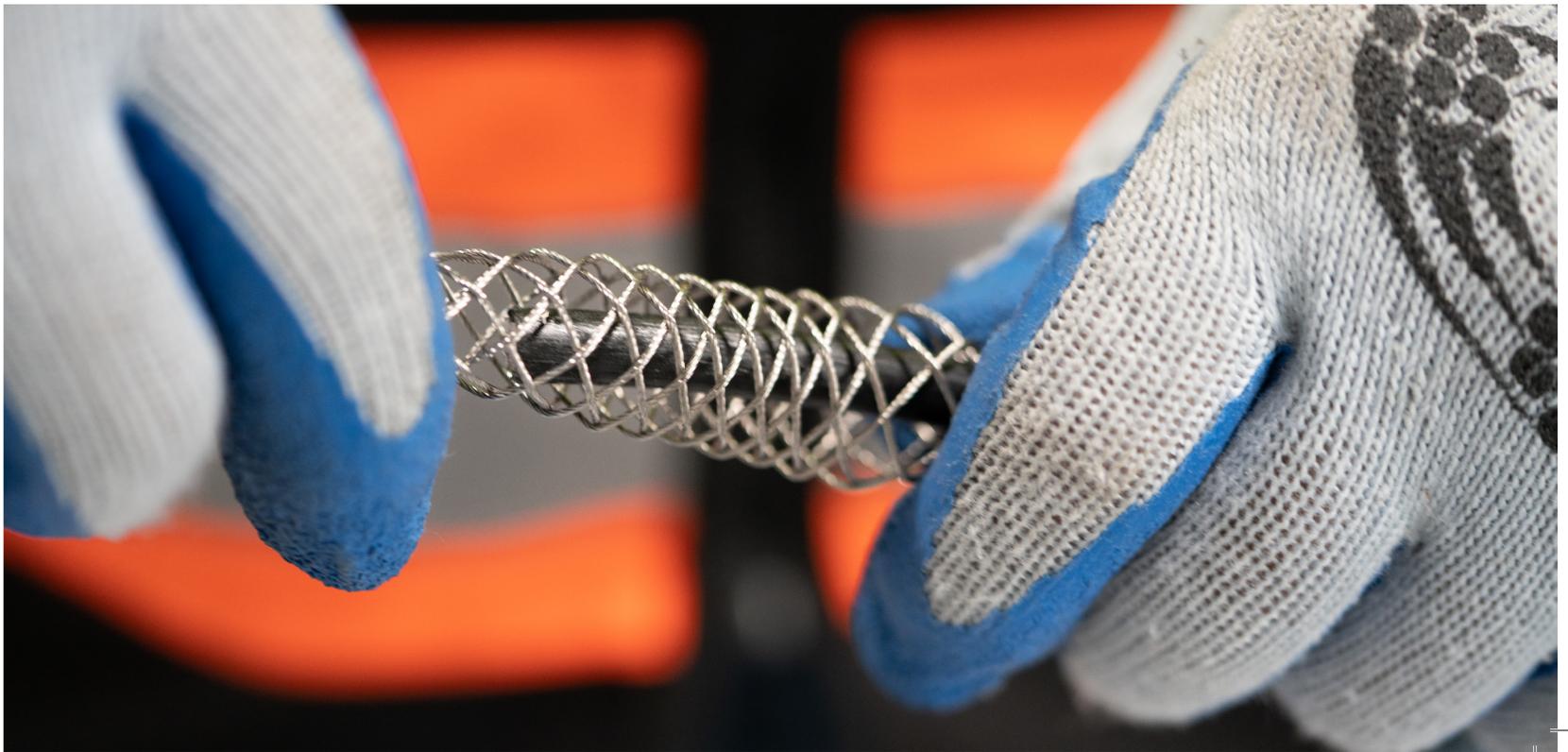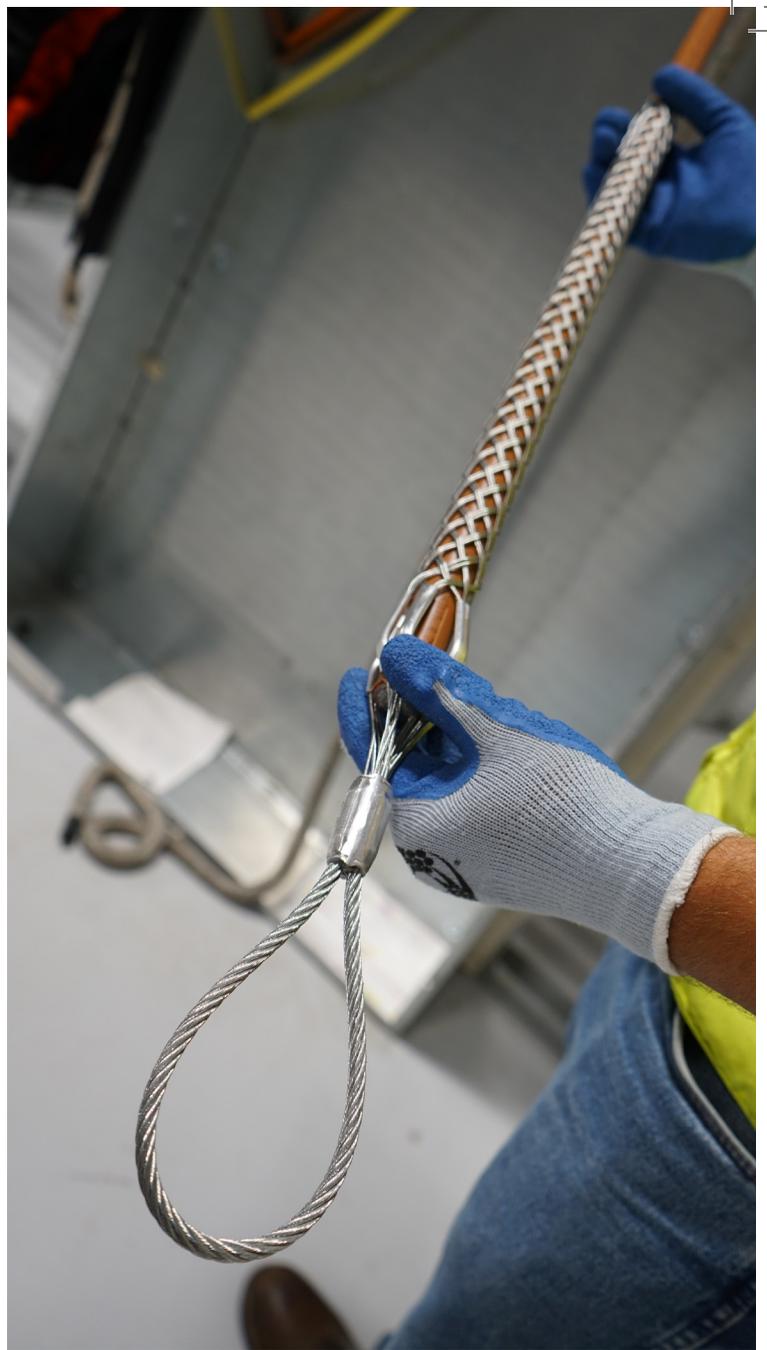



**Southwire™**

TOOLS & EQUIPMENT

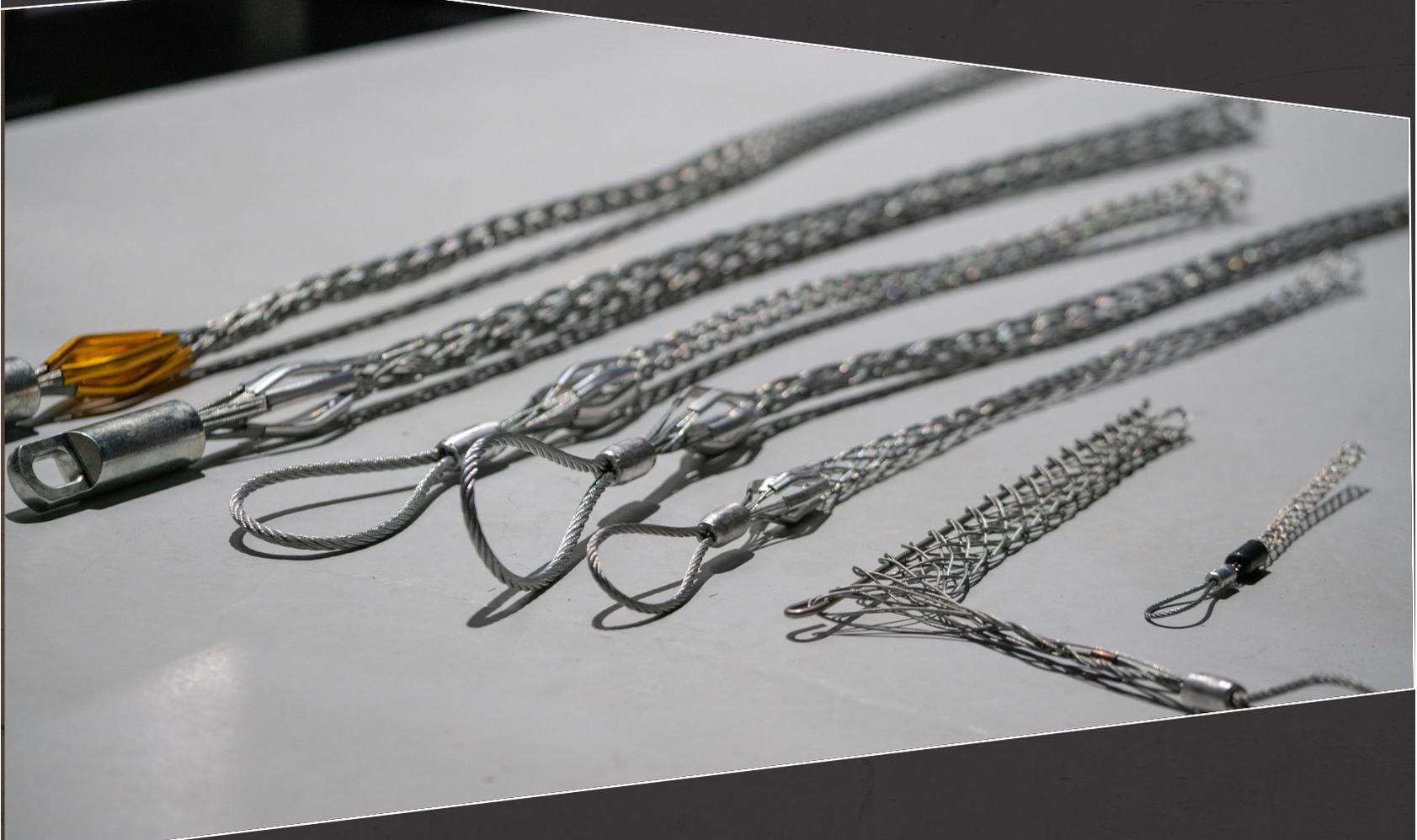

**GET SOCIAL WITH US:**



**/SOUTHWIRETOOLS  
/SOUTHWIRETOOLSLATINO**



**@SOUTHWIRETOOLS**



**@SOUTHWIRETOOLS**



**SOUTHWIRETOOLS**

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

**1-855-798-6657 | SOUTHWIRETOOLS.COM**

©2018 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.