


Pipe-end insulator with tongue complete, composite, to pipe 2.5" Schedule 40
Part no. D2372-08

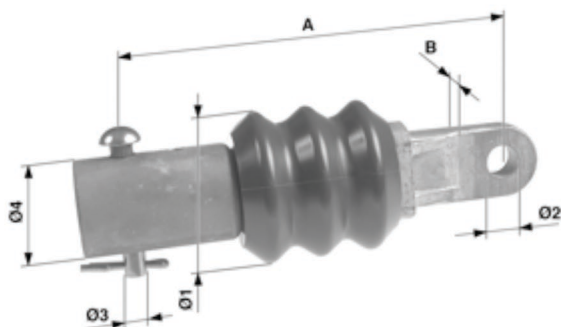

Technical data

Dimensions

A: 195 mm
B: 18 mm
Ø1: 80 mm
Ø2: 17 mm
Ø3: 12 mm
Ø4: 61.5 mm

Material and weight

-

Loads and tightening torque

Breaking load: 30 kN

Standards applied

-

Function

-

Specifications

Operating voltage: max. 3.000 kV
Minimum creeping distance: 92 mm for insulator

Spare parts

Tongue, with thread M16, Part no. D2357-01
Pin, 12 x 90, Part no. E3232-04
Cotter pin, 4.0 x 30, Part no. E3234-01
Support insulator with 2 inner threads M16, Ø = 80 mm, Part no. D2650-01

Accessories

-

Comments

- Connection parts in Al
- Pin and cotter pin SST
- Other insulators on request



Southwire™



A COLAS RAIL COMPANY

Contact Us: Transit@southwire.com