


Audacious Sound Cable®

Direct Burial

-GENESIS-

Genesis Audacious Sound Cables deliver better quality and bolder sound. Oxygen-free copper conductors and high strand count deliver minimal distortion for optimal performance.

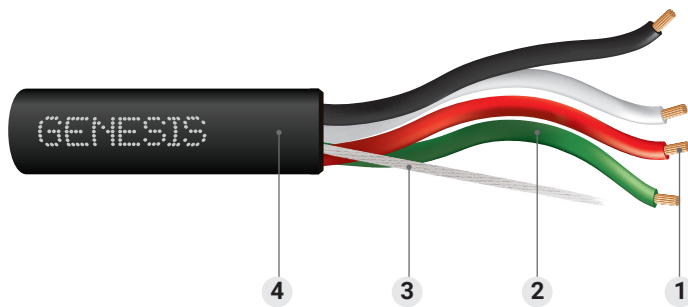

Construction

- 1. Conductor:** Oxygen-Free Bare Copper conductors for excellent sound transmission and low voltage drop
- 2. Insulation:** SRPVC
- 3. Rip Cord:** Durable rip cord for efficient jacket stripping and removal
- 4. Jacket:** PVC
Countdown® Length Markings for easy tracking of usage and remaining cable





Applications

- In burial applications with or without conduit
- In outdoor locations, exposed to sunlight and moisture

Specifications

- UL 1685 – General Purpose Rated
- UL 444 – Communication Cables, Type CM
- UL 13 – Power-Limited Circuit Cables, Type CL3
- Direct Burial Rated
- Sunlight Resistant Rated
- REACH/RoHS Compliant
- Rated for 300 Volts
- Rated for -20°C to 75°C

Conductor Color Codes: Audacious Sound Cable

Conductor Number	Color
1	Black 
2	Red 
3	White 
4	Green 

Sample Print Legend

GENESIS AUDACIOUS OXYGEN FREE P/N 528X XC XAWG (ETL) CL3 OR CM C(ETL)US SUN RES DIR BUR 75C
 "FOR USE IN AUDIO APPLICATIONS ONLY" (RoHS) W/O #XXXXXX-XXXXXX XXXX FT RM# A B C D E F 1 2 3 4 5 6 7 8 9

Audacious Sound Cable, Direct Burial

Part Number	Conductor Size (AWG)	Number of Conductors	Stranding	Insulation Thickness (in.)	Jacket Thickness (in.)	Nominal Diameter (in.)	DC Resistance (Ohms/1000 ft. at 20 °C)	Capacitance (pF/ft.)	Weight (lbs./1000ft.)
5283	16	2	65-strand	0.018	0.045	0.287	4.19	35.2	43.2
5284	16	4	65-strand	0.018	0.045	0.328	4.19	35.2	68.8
5285	14	2	105-strand	0.018	0.045	0.319	2.62	40.0	56.9
5286	14	4	105-strand	0.018	0.045	0.366	2.62	40.0	93.8

Genesis Cable

7701 95th Street
 Pleasant Prairie, WI 53158
 Office: 800.222.0060
www.genescable.com



-GENESIS-