

LED A19 Lamp CCT SELECTABLE



SUGGESTED APPLICATIONS

- High efficiency replacement for incandescent lamps
- Ideal for residential, commercial, hospitality, general lighting, recessed downlighting and task lighting
- Suitable for both open and enclosed fixtures

FEATURES

- 5 CCT Selectable: 2700K, 3000K, 3500K, 4000K and 5000K
- Simple selector switch on lamp body
- Up to 85% energy savings
- Dimmable down to 10%
- Durable plastic construction, frosted lens



LED A19 LAMP CCT SELECTABLE

GENERAL SPECIFICATIONS

Input Voltage/Frequency: 120, 60Hz
Power Factor, THD %: 0.7, <20%
Input Current: 105mA
Minimum CRI: 80
Beam Angle: 230°

Functional Life (L70): 15,000 hours
Ambient Operating Temperature: -4°F to 104°F
CBCP (cd): 104
Construction: White, polycarbonate construction with frosted lens
Dimmable

ITEM SPECIFICATIONS / ORDER INFO

Catalog Number	Order Code	Base	Max Lumens	Wattage	Efficacy (LPW)	CCT
LA19-9W-CTS-D	73664	E26	800	9W	89	2700K 3000K 3500K 4000K 5000K

NOMENCLATURE


LA19 = Lamp A19 Shape 9W = 9 Watt CTS = Color Temperature Selectable 2700K|3000K|3500K|4000K|5000K D = Dimmable

ENERGY SAVINGS Based on 12 hours/day and \$0.11/kWh

Catalog Number	LED Wattage	Incandescent Replacement Wattage	Wattage Saved	Yearly Savings	5 Year Savings
LA19-9W-CTS-D	9W	60W	51W	\$25	\$123

DIMENSIONS/WEIGHTS

Catalog Number	(A)	(B)	Weight
LA19-9W-CTS-D	4.4"	2.36"	0.08 Lbs.

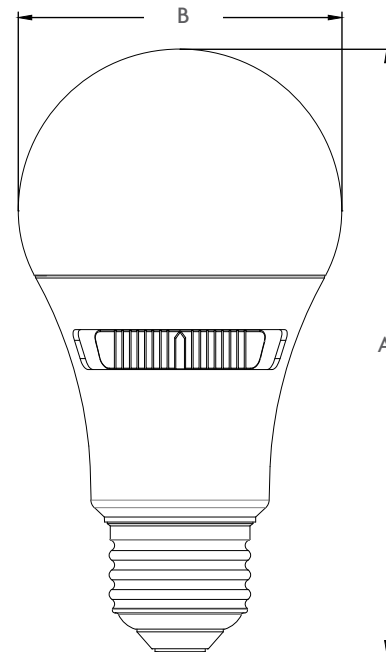

NOTES

Not for sale in California

Dimming - This product is designed to be compatible with most leading-edge type incandescent and LED style dimmers. (Dimming range 100% down to 10%). Product performance may vary depending on dimmer manufacturer and circuit loading. Visit www.topaz-usa.com/led-dimmer-compatibility for up-to-date dimmer compatibility information.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

THREE (3) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC: For details visit: www.topaz-usa.com/warranty

Specifications subject to change without notice.

Rev. 0, 01/22