



ARCHITECTURAL LINEAR WRAPS

POWER & CCT SELECTABLE

SUGGESTED APPLICATIONS

- High end residential
- Educational and library
- Hospitality
- Restaurants
- Conference rooms
- Office

FEATURES

- Crescent shape lens, wide light distribution with no hot spots
- 2 & 4 FT models with knock out for end to end wiring and connection
- Power and CCT select standard
- Surface mount, or optional chain and hook accessory or aircraft cable
- Lighting controls: optional occupancy sensor end cap assembly with Bluetooth connectivity
- Integrated emergency battery backup models available

INPUT VOLTAGE: 120-277V

FREQUENCY: 50/60HZ

POWER FACTOR, THD %:
>0.9; <20%

DIMMABLE: 0-10V,
DOWN TO 10%

CRI: 80

 
LIFETIME (L70): 54,000 HOURS

**MOUNTING OPTIONS: SURFACE
MOUNT READY, PENDANT
(SUSPENSION) MOUNT KITS
SOLD SEPERATELY**

MOUNTING HEIGHT: UP TO 12FT



**POWER
SELECT**



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



TOPAZ[®]

A Southwire Company

ARCHITECTURAL LINEAR WRAPS POWER & CCT SELECTABLE

ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	INPUT VOLTAGE MAX. INPUT CURRENT	POWER SELECTABLE WATTAGE	LUMENS @ 3000K	LUMENS @ 3500K	LUMENS @ 4000K	LUMENS @5000K	LUMENS @6500K	FLUORESCENT REPLACEMENT
LWRAPA2-25PCS	77117	032886167485	120-277V 0.099A/0.229A	15W	2,175	2,265	2,295	2,325	2,265	2X 17W T8
				20W	2,820	2,920	2,960	3,000	2,920	2X 17W T8
				25W	3,425	3,550	3,600	3,650	3,550	2X 17W T8 HBF
LWRAPA2-25PCS-EM	77118	32886167492	120-277V 0.099A/0.229A	15W	2,175	2,265	2,295	2,325	2,265	2X 17W T8
				20W	2,820	2,920	2,960	3,000	2,920	2X 17W T8
				25W	3,425	3,550	3,600	3,650	3,550	2X 17W T8 HBF
LWRAPA4-50PCS	77119	032886167508	120-277V 0.199A/0.458A	30W	4,350	4,530	4,590	4,650	4,530	2X 32W T8 LBF
				40W	5,640	5,840	5,920	6,000	5,840	2X 32W T8
				50W	6,850	7,100	7,200	7,300	7,100	2X 32W T8 HBF
LWRAPA4-50PCS-EM	77120	32886167515	120-277V 0.199A/0.458A	30W	4,350	4,530	4,590	4,650	4,530	2X 32W T8 LBF
				40W	5,640	5,840	5,920	6,000	5,840	2X 32W T8
				50W	6,850	7,100	7,200	7,300	7,100	2X 32W T8 HBF

DLC INFORMATION

MODEL #	DLC CLASSIFICATION	DLC I.D.	DLC PRIMARY USE	DLC CLASSIFICATION	DLC I.D.	DLC PRIMARY USE
LWRAPA2-25PCS	STANDARD	S-02LZLH	DIRECT LINEAR AMBIENT LUMINAIRES	PREMIUM	S-K03H9P	STAIRWELL AND PASSAGEWAY LUMINAIRES
LWRAPA2-25PCS-EM	STANDARD	S-02LZLH	DIRECT LINEAR AMBIENT LUMINAIRES	PREMIUM	S-K03H9P	STAIRWELL AND PASSAGEWAY LUMINAIRES
LWRAPA4-50PCS	STANDARD	S-7MNWPD	DIRECT LINEAR AMBIENT LUMINAIRES	PREMIUM	S-MD9MGH	STAIRWELL AND PASSAGEWAY LUMINAIRES
LWRAPA4-50PCS-EM	STANDARD	S-7MNWPD	DIRECT LINEAR AMBIENT LUMINAIRES	PREMIUM	S-MD9MGH	STAIRWELL AND PASSAGEWAY LUMINAIRES

ORDERING GUIDE

Example: LWRAPA2-25PCS

PRODUCT FAMILY	TRADE SIZE	POWER SELECTABLE	LUMEN PACKAGES	CCT SELECTABLE	OPTIONS	FINISH
LWRAP= LINEAR WRAPAROUND A = ARCHITECTURAL	2FT 4FT	25PCS = 15/20/25W 50PCS = 30/40/50W	2,295/2,960/3,600 4,590/5,920/7,200	3000K/3500K/4000K/5000K/6500K	EM = EMERGENCY BATTERY BACKUP	WH = WHITE BL = BLACK

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.




ARCHITECTURAL LINEAR WRAPS

POWER & CCT SELECTABLE

DIMENSIONS | WEIGHT


MODEL #	LENGTH	WIDTH	HEIGHT	WEIGHT (LBS)	PALLET QUANTITY (PCS)* 48"X 40"X 60"
LWRAPA2-25PCS	24.57	9.64	3.61	4.96	60
LWRAPA2-25PCS-EM				5.45	
LWRAPA4-50PCS	47	9.64	3.61	9.81	32
LWRAPA4-50PCS-EM				10	

*pallet qtys may vary

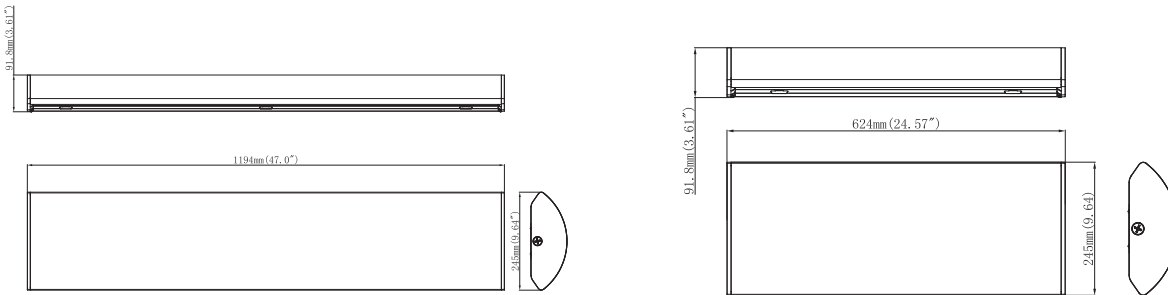

ACCESSORIES (SOLD SEPARATELY)

MODEL #	ORDER CODE	UPC	DESCRIPTION
LWRAPA-OS-PIR-BT	77121	032886167522	BLUETOOTH PIR OCCUPANCY SENSOR
LWRAPA-VHK-CHAIN	77122	032886167539	V-HOOK AND CHAIN

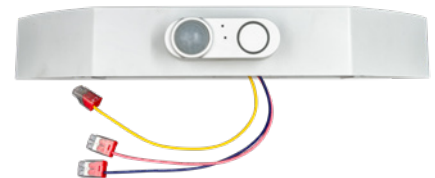

NOTES

Dimming with standard 0-10V control system or wall dimmers. Dimming complies with IEC60929 Annex E. Fixture may not be compatible with all dimmers. Dimming performance may vary based on selected dimmer. Visit southwire.com/led-dimmer-compatibility for up-to-date dimmer compatibility information.

FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC. For details visit: <https://southwire.com/resources/warranties>

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

CAN-ICES-003B/NMB-003B

Specifications are subject to change without prior notice. Replacement wattage shown depends on application and fixture.

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.