



Southwire™

RIGID COUPLINGS

THREE PIECE TYPE - MALLEABLE IRON

FEATURES

- For threaded Rigid or IMC conduit

APPLICATION

- Use as a threaded coupling between lengths of threaded Rigid or IMC conduit

STANDARD MATERIAL

- Malleable iron

STANDARD FINISH

- Zinc plated

CERTIFICATIONS


- UL Standard: UL 514B
- RoHS
- Fed. Spec: A-A-50553
- NEMA: FB 1



852



PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
851	1/2"	20	200	48	1.43"	1.36"
852	3/4"	10	100	38	1.63"	1.58"
853	1"	5	50	28	1.81"	1.89"
854	1-1/4"	5	50	44	2.19"	2.38"
855	1-1/2"	3	30	38	2.31"	2.83"
856	2"	---	20	37	2.44"	3.29"
857	2-1/2"	---	10	31	2.52"	4.03"
858	3"	---	5	20	2.58"	4.62"
859TZ	3-1/2"	---	5	26	2.65"	5.35"
860	4"	---	2	13	3.42"	5.87"
860A	5"	---	1	8	4.38"	7"
860B	6"	---	1	11	4.38"	8.25"

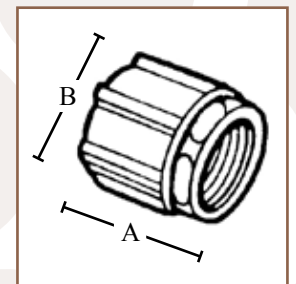

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.