



LED SLIM FIT RECESSED DOWNLIGHTS

DEEP REGRESSED - CCT SELECTABLE

SUGGESTED APPLICATIONS

- Retrofit and new construction
- Commercial, residential and multi-family buildings
- Low clearance areas, closets, stairwells, soffits, bathroom, and living areas

FEATURES

- 5 CCT selectable switch: 2700K, 3000K, 3500K, 4000K and 5000K
- Deep regress reflector provides low glare and comfortable uniform optical distribution
- Strong low profile design with white aluminum trim and polycarbonate lens
- Easy to install with spring clips and quick-connects without the need of housings
- Spacious remote J-box provides flexibility in mounting
- IC Rated, approved for use in insulated ceiling and non-insulated ceiling
- Airtight certified per ASTM-E283
- T24 JA8: Can be used to comply with California Energy Commission's High Efficacy LED light source requirements

INPUT VOLTAGE: 120V, 60Hz

**FUNCTIONAL LIFE (L70):
50,000 HOURS**

**POWER FACTOR,
THD %: >0.94, <18%**

**DIMMABLE: PHASE CUT,
DOWN TO 5%**

EFFICACY: UP TO 83 LPW

MINIMUM CRI: 90

**AMBIENT OPERATING
TEMPERATURE: -4°F TO 113°F**

**LOCATION RATING:
WET LOCATION**

**SUITABLE FOR BATHROOM
APPLICATIONS**



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | TOPAZ-USA.COM

©2022 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



LED SLIM FIT RECESSED DOWNLIGHTS

DEEP REGRESSED - CCT SELECTABLE

ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	LUMENS	WATTAGE	INPUT CURRENT	CCT	BEAM ANGLE	CA T24 JA8
SMOOTH								
DLD3S-7CS	73706	032886303227	500	7W	90mA	2700K/3000K/3500K/4000K/5000K	105°	Y
DLD4S-7CS	73287	032886300196	580	7W	70mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD6S-10CS	73289	032886300202	770	10W	90mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD6S-13CS	73291	032886300219	1,000	13W	125mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD6S-16CS	73293	032886300226	1,200	16W	145mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD8S-21CS	73752	032886303234	1,700	21W	200mA	2700K/3000K/3500K/4000K/5000K	110°	Y
BAFFLE								
DLD3B-7CS	73769	032886303241	500	7W	90mA	2700K/3000K/3500K/4000K/5000K	105°	Y
DLD4B-7CS	73299	032886300233	580	7W	70mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD6B-10CS	73301	032886300240	770	10W	90mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD6B-13CS	73303	032886300257	1,000	13W	125mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD6B-16CS	73305	032886300264	1,200	16W	145mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD8B-21CS	73778	032886303258	1,700	21W	200mA	2700K/3000K/3500K/4000K/5000K	110°	Y

NOMENCLATURE

EXAMPLE: DLD3S-7CS

PRODUCT	SIZE	TRIM STYLE	WATTAGE	CCT
DLD = Downlight LED Deep Regress	3 = 3"	S = Smooth	7 = 7 Watts	CS = 5 Color Temperature Selectable
	4 = 4"	B = Baffle	10 = 10 Watts	
	6 = 6"		13 = 13 Watts	
	8 = 8"		16 = 16 Watts	
			21 = 21 Watts	

NOTES

Dimming - This product is designed to be compatible with most leading-edge type incandescent and LED style dimmers. (Dimming range 100% down to 5%).
 Product performance may vary depending on dimmer manufacturer and circuit loading. Visit www.topaz-usa.com/fed-dimmer-compatibility for up-to-date dimmer compatibility information.
 This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.
 FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC. For details visit: <https://southwire.com/resources/warranties>
 Specifications subject to change without notice.



800-666-2852 | TOPAZ-USA.COM

©2022 Southwire Company, LLC. All rights reserved.
 *Registered Trademark & ™ Trademark of Southwire Company, LLC.



LED SLIM FIT RECESSED DOWNLIGHTS


DEEP REGRESSED - CCT SELECTABLE

ENERGY SAVINGS Based on 12 hours/day and \$0.11/kWh

MODEL #	LED WATTAGE	INCANDESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
DLD3X-7CS	7W	50W	43W	\$21	\$104
DLD4X-7CS	7W	50W	43W	\$21	\$104
DLD6X-10CS	10W	65W	55W	\$26	\$132
DLD6X-13CS	13W	75W	62W	\$30	\$149
DLD6X-16CS	15.5W	85W	69.5W	\$33	\$167
DLD8X-21CS	21W	150W	129W	\$62	\$311

DIMENSIONS | WEIGHT

MODEL #	A	B	C	D	E	F	WEIGHT (LBS.)
DLD3X-7CS	4.13"	1.73"	3"	4.50"	5.45"	1.36"	0.71
DLD4X-XCS	5.28"	1.73"	3"	4.50"	5.45"	1.36"	0.75
DLD6X-XCS	7.09"	1.78"	3"	4.50"	5.45"	1.36"	0.86
DLD8X-21CS	9.52"	2.36"	3"	4.50"	5.45"	1.36"	1.21

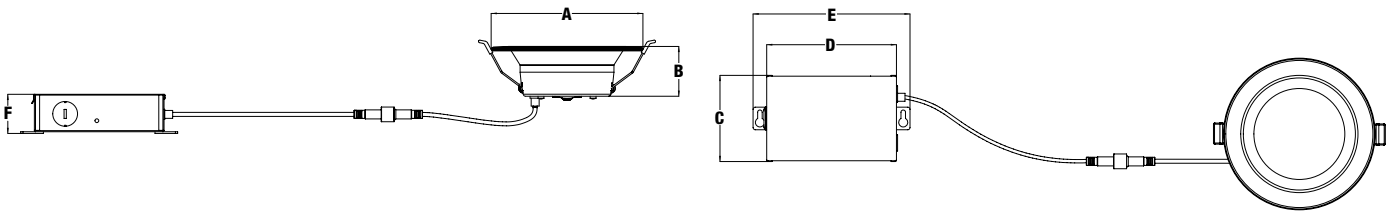

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | TOPAZ-USA.COM

©2022 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



LED SLIM FIT RECESSED DOWNLIGHTS

DEEP REGRESSED - CCT SELECTABLE

ACCESSORIES (SOLD SEPERATELY)

MODEL #	ORDER CODE	UPC	DESCRIPTION	COMPATIBLE DOWNLIGHT		
DLD-UNV-FRAMEKIT	73642	032886304231	Universal Frame Kit	3", 4", 6", 8" Deep Regress Downlights		
DLD3S-TRIM-BL	73440	032886303999	3" Smooth Black	DLD3S-7CS	---	---
DLD3S-TRIM-BZ	73442	032886304002	3" Smooth Bronze	DLD3S-7CS	---	---
DLD3S-TRIM-BN	73444	032886304019	3" Smooth Brushed Nickel	DLD3S-7CS	---	---
DLD3B-TRIM-BL	73446	032886304026	3" Baffle Black	DLD3B-7CS	---	---
DLD3B-TRIM-BZ	73448	032886304033	3" Baffle Bronze	DLD3B-7CS	---	---
DLD3B-TRIM-BN	73460	032886304040	3" Baffle Brushed Nickel	DLD3B-7CS	---	---
DLD4S-TRIM-BL	73469	032886304057	4" Smooth Black	DLD4S-7CS	---	---
DLD4S-TRIM-BZ	73474	032886304064	4" Smooth Bronze	DLD4S-7CS	---	---
DLD4S-TRIM-BN	73644	032886304071	4" Smooth Brushed Nickel	DLD4S-7CS	---	---
DLD4B-TRIM-BL	73969	032886304088	4" Baffle Black	DLD4B-7CS	---	---
DLD4B-TRIM-BZ	73700	032886304095	4" Baffle Bronze	DLD4B-7CS	---	---
DLD4B-TRIM-BN	73551	032886304101	4" Baffle Brushed Nickel	DLD4B-7CS	---	---
DLD6S-TRIM-BL	73552	032886304118	6" Smooth Black	DLD6S-10CS	DLD6S-13CS	DLD6S-16CS
DLD6S-TRIM-BZ	73789	032886304125	6" Smooth Bronze	DLD6S-10CS	DLD6S-13CS	DLD6S-16CS
DLD6S-TRIM-BN	73841	032886304132	6" Smooth Brushed Nickel	DLD6S-10CS	DLD6S-13CS	DLD6S-16CS
DLD6B-TRIM-BL	73842	032886304149	6" Baffle Black	DLD6B-10CS	DLD6B-13CS	DLD6B-16CS
DLD6B-TRIM-BZ	73632	032886304156	6" Baffle Bronze	DLD6B-10CS	DLD6B-13CS	DLD6B-16CS
DLD6B-TRIM-BN	73633	032886304163	6" Baffle Brushed Nickel	DLD6B-10CS	DLD6B-13CS	DLD6B-16CS
DLD8S-TRIM-BL	73634	032886304170	8" Smooth Black	DLD8S-21CS	---	---
DLD8S-TRIM-BZ	73635	032886304187	8" Smooth Bronze	DLD8S-21CS	---	---
DLD8S-TRIM-BN	73636	032886304194	8" Smooth Brushed Nickel	DLD8S-21CS	---	---
DLD8B-TRIM-BL	73637	032886304200	8" Baffle Black	DLD8B-21CS	---	---
DLD8B-TRIM-BZ	73638	032886304217	8" Baffle Bronze	DLD8B-21CS	---	---
DLD8B-TRIM-BN	73640	032886304224	8" Baffle Brushed Nickel	DLD8B-21CS	---	---
RDL/CBL/5CTS/6FT-46	71090	751338038684	6' Low Voltage Extension Cable	3", 4", 6", 8" Deep Regress Downlights		

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | TOPAZ-USA.COM


©2022 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.




LED SLIM FIT RECESSED DOWNLIGHTS

DEEP REGRESSED - CCT SELECTABLE


POLAR PLOTS

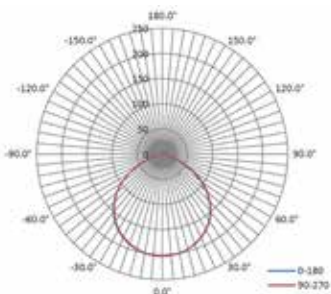


DLD3B-7CS

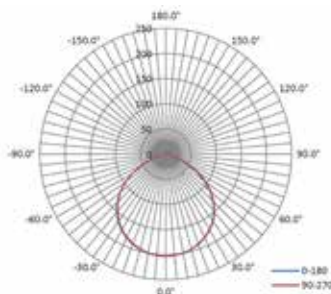


DLD3S-7CS

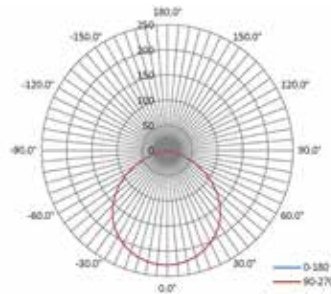


DLD4B-7CS

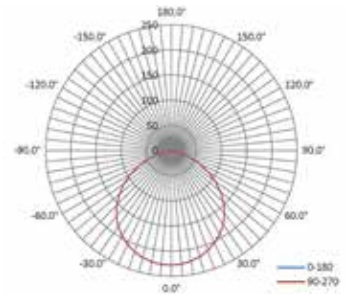


DLD4S-7CS

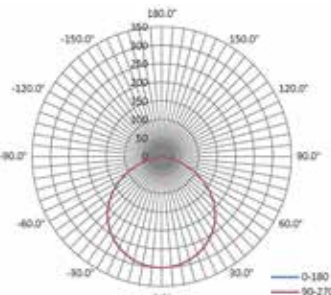


DLD6B-10CS

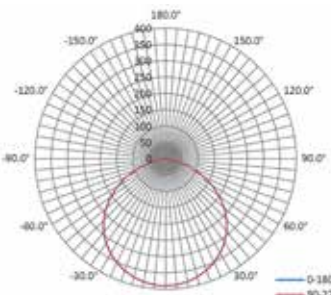


DLD6B-13CS

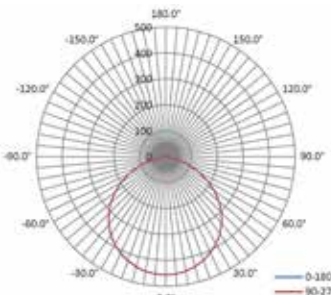


DLD6B-16CS

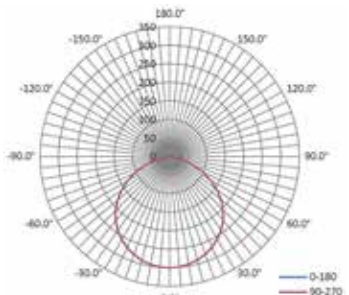


DLD6S-10CS

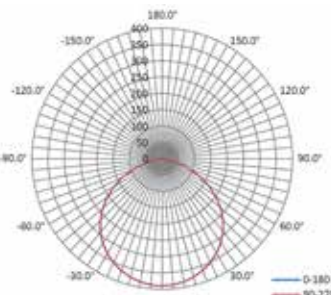


DLD6S-13CS

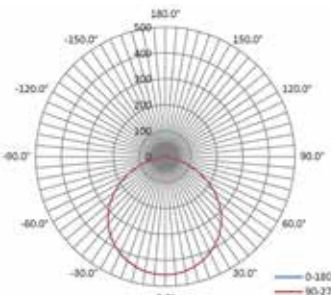

DLD6S-16CS

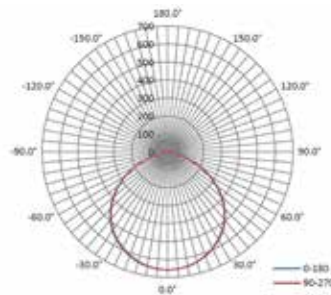

DLD8B-21CS

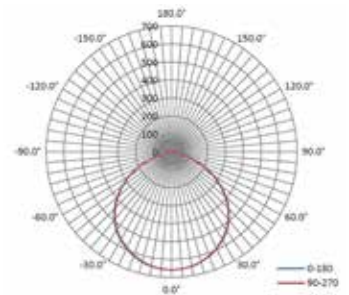

DLD8S-21CS

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**