

LED A-Shape Lamp

A15



Versatility of Form and Function

Topaz A15 lamps offer a compact and versatile alternative to the 60W incandescent for a wide range of lighting applications. Available in warm and cool color temperatures with a wide beam output, the A15s are suitable for enclosed fixtures. Designed with a durable, shatterproof lens these low-maintenance LED lamps bring excellent illumination, dimming capabilities and energy savings to residential, commercial and hospitality applications.

FEATURES

- Up to 85% energy savings
- Lasts up to 10X longer than traditional lighting
- Suitable for use in enclosed fixtures
- Dimmable down to 10% of total light output
- Plastic lens provides shatter protection

SUGGESTED APPLICATIONS

- Residential, commercial, and hospitality
- Fan lights
- Decorative
- Recessed downlighting
- Task lighting





Job Name/Title: _____ Catalog Number _____

Contractor: _____ Notes: _____

LED A-Shape Lamp A15

GENERAL SPECIFICATIONS

Input Voltage, Frequency: 120V, 60Hz
Power Factor, THD %: >0.7, <20%
Dimmable: Line voltage down to 10%¹
Efficacy: 92 LPW
Minimum CRI: 80
Functional Life (L70): 15,000 hours

Location Rating: Damp
Ambient Operating Temperature: -4°F to 104°F
Suitable for Enclosed Fixtures
Housing: White plastic with frosted lens
Base: E26

ITEM SPECIFICATIONS / ORDER INFO

| Catalog Number | Order Code | UPC | Lumens | Wattage | Input Current | CCT | Beam Angle |
|----------------|------------|--------------|--------|---------|---------------|-------|------------|
| LA15-7W-830-D | 73487 | 751338039599 | 600 | 6.5W | 85mA | 3000K | 150° |
| LA15-7W-850-D | 73488 | 751338039605 | 600 | 6.5W | 85mA | 5000K | 150° |

Not for sale in California.

NOMENCLATURE


LA15 = LED A15 Shape - 7W = 6.5 Watts - 830 = 3000K, 80 CRI - D = Dimmable
 850 = 5000K, 80 CRI

ENERGY SAVINGS

| Catalog Number | LED Wattage | Halogen Replacement Wattage | Watts Saved | Yearly Savings | 5 Year Savings |
|---|-------------|-----------------------------|-------------|----------------|----------------|
| Based on 12 hours/day and \$0.11/kWh | | | | | |
| LA15-7W-830-D | 6.5W | 50W | 43.5W | \$21 | \$105 |
| LA15-7W-850-D | 6.5W | 50W | 43.5W | \$21 | \$105 |

DIMENSIONS / WEIGHTS

| Catalog Number | MOL (A) | MOD (B) | Weight |
|----------------|---------|---------|----------|
| LA15-7W-8XX-D | 3.44" | 1.96" | 0.1 Lbs. |

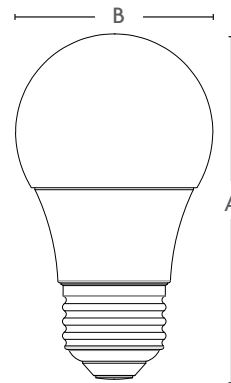

NOTES:

¹Dimming - This product is designed to be compatible with most leading-edge type incandescent and LED style dimmers. (Dimming range 100% down to 10%). Product performance may vary depending on dimmer manufacturer and circuit loading. Visit www.topaz-usa.com/led-dimmer-compatibility for up-to-date dimmer compatibility information.

Replacement wattage shown depends on application and fixture.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

Specifications subject to change without prior notice.

WARNING: Some products included in this specification sheet may be subject to the warning requirements of California's Proposition 65. Please refer to your product packaging for more information.

August 2021