



# Southwire™

## RIGID COUPLINGS

### COMPRESSION TYPE - MALLEABLE IRON

#### FEATURES

- Compression type coupling
- Threadless
- Concrete tight
- Suitable for use with UL 6 Rigid Conduit

#### APPLICATION

- Dry location only
- Use to join two lengths unthreaded Rigid or IMC conduit

#### STANDARD MATERIAL

- Malleable iron

#### STANDARD FINISH

- Zinc plated

#### CERTIFICATIONS


- UL Standard: UL 514B
- Fed. Spec: W-F-406E, W-F-406D
- NEMA: FB 1-2014



251M



PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/CASE (LBS.)	A	B
251M	1/2"	10	100	16	1.81"	1.50"
252M	3/4"	10	100	24	1.87"	1.62"
253M	1"	5	50	48	2.18"	2"
254M	1-1/4"	5	50	86	2.62"	2.37"
255M	1-1/2"	---	12	125	2.68"	2.62"
256M	2"	---	5	160	3"	3.31"
257TZ	2-1/2"	---	5	260	5.75"	3.93"
258TZ	3"	---	3	300	5.72"	4.66"
259	3-1/2"	---	2	350	6"	5.20"
260TZ	4"	---	2	400	6.81"	5.75"
260A	5"	---	1	9	6.86"	6.10"
260B	6"	---	1	12	8.14"	6.81"

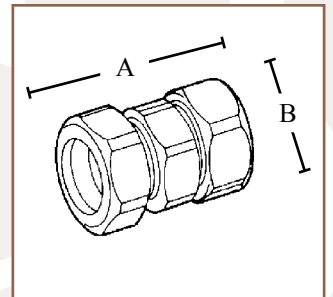

Rev. 0, 03/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.