



Southwire™

COMBINATION COUPLINGS

COMPRESSION TYPE EMT TO RIGID - STEEL

FEATURES

- Internally threaded for Rigid/IMC conduit
- Compression type EMT
- Raintight

APPLICATION

- Suitable for indoor and outdoor use
- Use to join Rigid/IMC conduit to EMT between 2 different raceways
- Coupling internally threaded for Rigid/IMC
- Compression type for EMT, concrete tight

STANDARD MATERIAL

- Steel

STANDARD FINISH

- Zinc plated


CERTIFICATIONS

- UL standard 514B
- Fed. Spec. A-A-50553
- NEMA FB 1



391C

PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/CASE (LBS.)	A	B
391C	1/2"	20	200	31	1.10"	1.57"
392C	3/4"	10	100	21	1.33"	1.62"
393C	1"	10	100	30	1.63"	1.82"
RTE125	1-1/4"	---	25	26	2.062"	1.75"

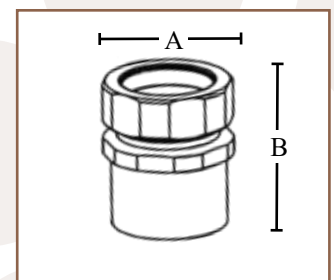

Rev. 0, 01/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.