



Southwire™

RIGID CONDUIT BODIES

LR TYPE - FORM 7

FEATURES

- NPT tapered hubs
- NEMA FB 1/NEMA 3R raintight when installed with cover and gasket
- Suitable for Class 1 Div.2 hazardous locations when installed according to NEC 2014 501.10(B)(4)

APPLICATION

- Serves as pull outlet for conductors being installed

STANDARD MATERIAL

- Gray iron

STANDARD FINISH


- Zinc plated
- Eco-friendly finish with superior corrosion resistant coating
- ASTM B117 (200+ HR NaCL spray test)
- Highly resistant to solvents, fuels and acids

CERTIFICATIONS

- UL Standard: UL 514A and UL 514D
- Fed. Spec: A-A-50563
- NEMA: FB 1



LR1G7

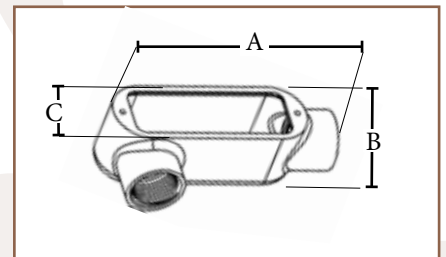

PART #	SIZE	WIRE SIZE MAX. NUMBER	WIRE SIZE MAX. SIZE	INTERNAL VOLUME (IN ³)	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
LR1G7	1/2"	---	---	3.8	10	8	4.50"	2.30"	1.40"
LR2G7	3/4"	3	6 AWG	5.8	10	12	5.20"	2.50"	1.70"
LR3G7	1"	3	4 AWG	9	5	9	6.20"	2.80"	1.90"
LR4G7	1-1/4"	3	2 AWG	17.8	10	25	6.50"	3.10"	2.30"
LR5G7	1-1/2"	3	2 AWG	24	10	30	7.10"	3.40"	2.60"
LR6G7	2"	3	1/0 AWG	45	5	24	8.10"	4"	3.10"
LR7G7	2-1/2"	3	250 MCM	95.8	1	8	10.70"	5.80"	3.70"
LR8G7	3"	3	250 MCM	119	1	10	10.70"	5.80"	4.40"
LR10G7	4"	3	350 MCM	231	1	17	12.80"	7"	5.40"

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.