



# Southwire™

## RIGID BUSHINGS

### INSULATED - 105°C THERMOPLASTIC LINER - MALLEABLE IRON

#### FEATURES

- Liner is rated flame retardant to 105°C

#### APPLICATION

- Indoor or outdoor use
- Use with locknut to terminate Rigid or IMC conduit to an outlet box
- Plastic liner prevents damage to wire insulation

#### STANDARD MATERIAL

- Malleable iron

#### STANDARD FINISH


- Zinc plated
- Plastic insulator



311M



PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
311M	1/2"	100	1000	20	1.223"	.506"
312M	3/4"	50	500	20	1.498"	.547"
313M	1"	50	500	40	1.818"	.662"
314M	1-1/4"	25	250	43	2.423"	.735"
315M	1-1/2"	25	100	29	2.512"	.808"
316M	2"	10	100	30	3.053"	.808"
317M	2-1/2"	---	50	20	3.624"	.958"
318M	3"	---	25	13	4.172"	1.052"
319M	3-1/2"	---	25	18	4.767"	1.169"
320M	4"	---	10	10	5.321"	1.178"
320AM	5"	---	10	25	6.15"	1.30"
320BM	6"	---	10	35	7.19"	1.30"

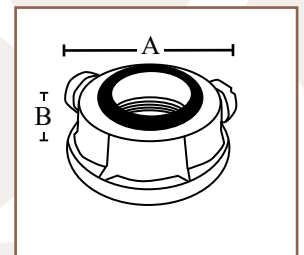

Rev. 0, 05/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.