




Friendly Service... Powerful Solutions



LINEAR FLUORESCENT LAMP

F032/830

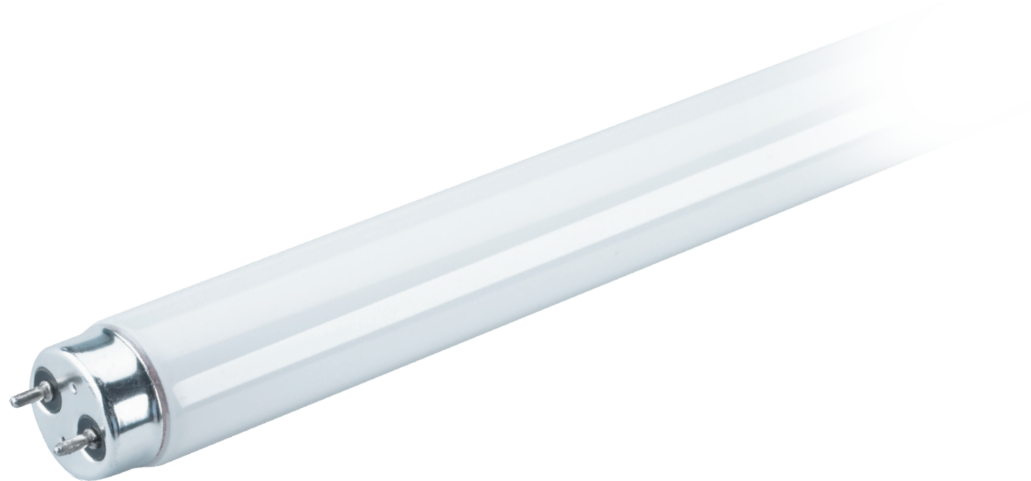

Features

T8 Linear Fluorescent Tube, Low Mercury Content, 3000K, 85 CRI; TCLP Compliant, ROHS Compliant, Made in China

Specifications

Item #	Watts	CCT (K)	CRI	Initial Lumens	Bulb Shape	Rated Life (HRS)	MOL (IN)	Diameter (IN)	Base
F032/830-39	32	3000	85	3050	T8 Linear Tube	20,000	48	1	G14 Medium Bi-Pin

TOPAZ LIGHTING™
A TOPAZ® COMPANY

www.topaz-usa.com

NY Office: 925 Waverly Ave • Holtsville, NY 11742 • 800-666-2852 • Fax: 631-758-8026
CA Office: 225 Parkside Drive, San Fernando, CA 91340 • 888-551-2852 or 818-838-3123 • Fax: 888-690-2852 or 818-838-3102
FL Office: 2020 West 26th Street, Jacksonville, FL 32209 • 800-338-2852 • Fax: 772-778-5386