



LED SPORTS LIGHT

POWER SELECTABLE

SUGGESTED APPLICATIONS

- High output pole mount applications
- Sport fields
- Municipal fields
- Arenas
- Parking lots
- Golf ranges

FEATURES

- Power Selectable: three performance levels
- Black heavy-duty die-cast aluminum housing with IK08 impact rated lens
- Shorting cap and 7-pin receptacle included (Photocell accessories available)
- Optimum light spread with 20° and 30° beam angles available
- Detachable driver allows fixture control from pole base
- Yoke Mount (pre-installed) with Slip Fitter Mount accessory available
- Glare Shield accessories available to prevent light pollution
- 35-ft and 65-ft Extension Cord accessories available
- Fixture mountable laser accessory available for fixture aiming



INPUT VOLTAGE:
120-277V AND 200-480V
OPTIONS AVAILABLE

5000K CCT, >70 CRI

DIMMING: 0-10V, DOWN TO 1%

EFFICACY: UP TO 160 LPW


**WEATHERPROOF: IP65 AND
20KV SURGE PROTECTION**

**LIFETIME (L70): UP TO
60,000 HOURS**

**MOUNTING HEIGHT: UP TO
115 FEET**

BUG RATING:
B5-U0-G2 (500W)
B5-U0-G5 (750W & 1200W)

POWER CORD: SJOW/10FT

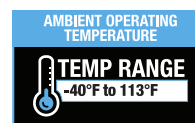

**POWER
SELECT**

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



LED SPORTS LIGHT

POWER SELECTABLE

ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	INPUT VOLTAGE MAX. INPUT CURRENT	POWER SELECTABLE WATTAGE	LUMEN	CCT	EFFICACY (LPW)	TYPICAL MOUNTING HEIGHT	HID REPLACEMENT WATTAGE
SP-500PS-50K	74446	032886312144	120-277V 4.2/1.9A	300W	48,000	5000K	160	32-85 FT	1,200W
				400W	62,000		155		1,600W
				500W	75,000		150		2,000W
SP-500PS-50K-HV	74447	032886312151	200-480V 2.5/1.1	300W	48,000	5000K	160	32-85 FT	1,200W
				400W	62,000		155		1,600W
				500W	75,000		150		2,000W
SP-750PS-50K	74448	032886312168	120-277V 6.3/2.9A	450W	72,000	5000K	160	49-98 FT	1,800W
				500W	77,500		155		2,000W
				750W	112,500		150		3,000W
SP-750PS-50K-HV	74449	032886312175	200-480V 3.8/1.7A	450W	72,000	5000K	160	49-98 FT	1,800W
				500W	77,500		155		2,000W
				750W	112,500		150		3,000W
SP-1200PS-50K	74450	032886312182	120-277V 10.1/4.6A	800W	128,000	5000K	160	66-115 FT	3,200W
				1,000W	155,000		155		4,000W
				1,200W	180,000		150		4,800W
SP-1200PS-50K-HV	74451	032886312199	200-480V 6.1/2.7A	800W	128,000	5000K	160	66-115 FT	3,200W
				1,000W	155,000		155		4,000W
				1,200W	180,000		150		4,800W

NOTE: 500W and 750W fixtures have a 30° Beam Angle. 1200W fixtures have a 20° Beam Angle.

ORDERING GUIDE

Example: **SP-750PS-50K**

PRODUCT	POWER SELECTABLE LUMEN OPTIONS	CCT	INPUT VOLTAGE	
SP = SPORTS LIGHT	500PS =	50K = 5000K	BLANK = 120-277V HV = 200-480V	
				(300W) 48,000LM
				(400W) 62,000LM
	750PS =			(500W) 75,000LM
				(450W) 72,000LM
				(500W) 77,500LM
	1200PS =			(750W) 112,500LM
				(800W) 128,000LM
				(1000W) 155,000LM
	(1200W) 180,000LM			

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.

Job Name/Title: _____

Model #: _____

Fixture Type: _____




LED SPORTS LIGHT


POWER SELECTABLE

DIMENSIONS | WEIGHT

MODEL #	A (IN)	B (IN)	C (IN)	WEIGHT (LBS.)	PALLET QUANTITY (PCS)* 48" x 40" x 60"
SP-500PS-50K	17.3	17.6	16.5	32.8	12PCS
SP-500PS-50K-HV	17.3	17.6	16.5	32.8	12PCS
SP-750PS-50K	21.8	21.3	19.5	48.1	6PCS
SP-750PS-50K-HV	21.8	21.3	19.5	48.1	6PCS
SP-1200PS-50K	24.6	22.5	21.3	47.6	3PCS
SP-1200PS-50K-HV	24.6	22.5	21.3	47.6	3PCS

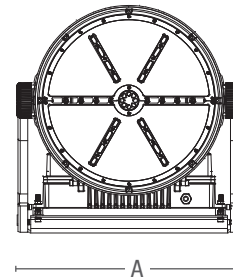

B

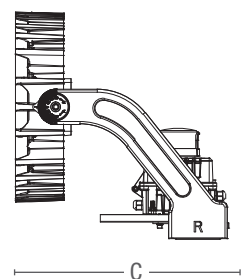

*pallet qty's may vary



SP-SFMOUNT-500
SP-SFMOUNT-750
SP-SFMOUNT-1200



SP-SHIELD-500
SP-SHIELD-750
SP-SHIELD-1200



SP-EXTCORD-35FT
SP-EXTCORD-65FT



SP-LASERPOINTER



120-277V TWIST-LOCK
PHOTOCELL



480V TWIST-LOCK
PHOTOCELL

ACCESSORIES (SOLD SEPARATELY)

MODEL #	ORDER CODE	UPC	DESCRIPTION
SP-SFMOUNT-500	74452	032886313103	SLIPFITTER MOUNT FOR 500W SPORT LIGHT
SP-SFMOUNT-750	74453	032886312601	SLIPFITTER MOUNT FOR 750W SPORT LIGHT
SP-SFMOUNT-1200	74454	032886312618	SLIPFITTER MOUNT FOR 1200W SPORT LIGHT
SP-SHIELD-500	74455	032886312625	SHIELD GUARD FOR 500W SPORT LIGHT
SP-SHIELD-750	74482	032886312632	SHIELD GUARD FOR 750W SPORT LIGHT
SP-SHIELD-1200	74484	032886312649	SHIELD GUARD FOR 1200W SPORT LIGHT
SP-EXTCORD-35FT	74486	032886312656	35-FT EXTENSION CORD
SP-EXTCORD-65FT	74490	032886312663	65-FT EXTENSION CORD
SP-LASERPOINTER	74500	032886312670	GREEN LASER POINTER
WD-PC/TL/120-277	72711	751338033771	120-277V TWIST-LOCK PHOTOCELL
WD-PC/TL/480	72722	751338033788	480V TWIST-LOCK PHOTOCELL

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**


800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



LED SPORTS LIGHT

POWER SELECTABLE

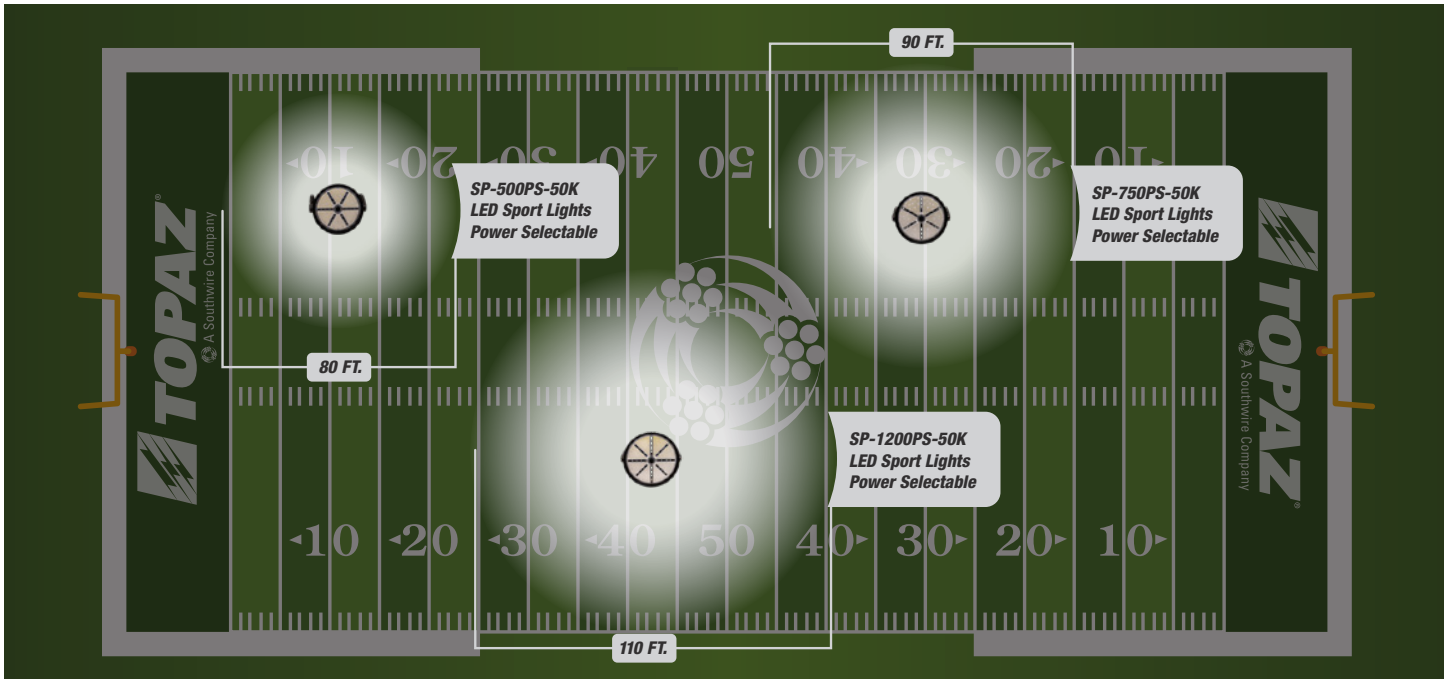

ENERGY SAVINGS Based on 12 hours/day and \$0.11/kWh

MODEL #	LED WATTAGE	REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
SP-500PS-50K SP-500PS-50K-HV	500W	2000W	3,285,000	\$985.50	\$4,927.50
SP-750PS-50K SP-750PS-50K-HV	750W	3000W	4,927,500	\$1,478.25	\$7,391.25
SP-1200PS-50K SP-1200PS-50K-HV	1200W	4800W	7,884,000	\$2,365.20	\$11,826.00

* based on 6 hours daily usage at max wattage output

DLC INFORMATION

MODEL #	DLC I.D.	DLC CLASSIFICATION	DLC PRIMARY USE
SP-500PS-50K	S-QB7P0D		ARCHITECTURAL FLOOD AND SPOT LUMINAIRES
SP-500PS-50K-HV	S-XH19UK	PREMIUM	ARCHITECTURAL FLOOD AND SPOT LUMINAIRES
SP-750PS-50K	S-4FPH9D		ARCHITECTURAL FLOOD AND SPOT LUMINAIRES

MODEL #	DLC I.D.	DLC CLASSIFICATION	DLC PRIMARY USE
SP-750PS-50K-HV	S-8PI0MN		ARCHITECTURAL FLOOD AND SPOT LUMINAIRES
SP-1200PS-50K	S-RPY4LC	PREMIUM	ARCHITECTURAL FLOOD AND SPOT LUMINAIRES
SP-1200PS-50K-HV	S-W4P01Z		ARCHITECTURAL FLOOD AND SPOT LUMINAIRES

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.