



Southwire™

RIGID COUPLINGS

TUBULAR THREADED TYPE - STEEL

FEATURES

- NPSM thread type

APPLICATIONS

- Indoor or outdoor use
- Use to join and ensure proper alignment of threaded Rigid or IMC conduit

STANDARD MATERIAL

- Steel

STANDARD FINISH

- Zinc plated

CERTIFICATIONS


- UL Standard: UL 6A
- Fed. Spec: WW-C-563
- NEMA: ANSI C80.1-2015



51



PART #	SIZE	THREADS PER INCH	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
51	1/2"	14	150	20	1.63"	1.563"
52	3/4"	14	50	9	1.64"	1.625"
53	1"	11-1/2	30	10	1.97"	2"
54	1-1/4"	11-1/2	25	10	2.03"	2.063"
55	1-1/2"	11-1/2	25	14	2.06"	2.063"
56	2"	11-1/2	20	15	2.13"	2.125"
57	2-1/2"	8	12	22	2.19"	3.125"
58	3"	8	8	18	3.31"	3.25"
59	3-1/2"	8	4	14	3.41"	3.375"
60	4"	8	4	12	3.52"	3.50"
60A	5"	8	2	11	3.95"	3.75"
60B	6"	8	3	12	4.25"	4"

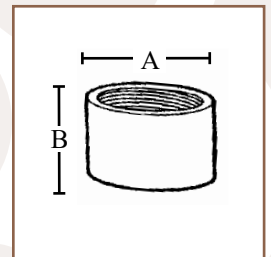

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.