



# Southwire™

## RIGID CONDUIT BODIES

### T TYPE - FORM 7

#### FEATURES

- NPT tapered hubs
- NEMA FB 1/NEMA 3R raintight when installed with cover and gasket
- Suitable for Class 1 Div.2 hazardous locations when installed according to NEC 2014 501.10(B)(4)

#### APPLICATION

- Serves as pull outlet for conductors being installed

#### STANDARD MATERIAL

- Gray iron

#### STANDARD FINISH


- Zinc plated
- Eco-friendly finish with superior corrosion resistant coating
- ASTM B117 (200+ HR NaCL spray test)
- Highly resistant to solvents, fuels and acids

#### CERTIFICATIONS

- UL Standard: UL 514A and UL 514B
- Fed. Spec: A-A-50563
- NEMA: FB 1



T1G7

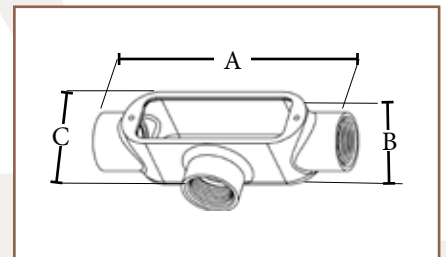

PART #	SIZE	WIRE SIZE MAX. NUMBER	WIRE SIZE MAX. SIZE	INTERNAL VOLUME (IN <sup>3</sup> )	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
T1G7	1/2"	---	---	3.8	10	8	5.30"	2.50"	1.80"
T2G7	3/4"	3	6 AWG	5.8	10	13	6.20"	2.70"	2"
T3G7	1"	3	4 AWG	9	5	9	7.30"	3"	2.30"
T4G7	1-1/4"	3	2 AWG	17.8	10	26	7.40"	3.10"	2.30"
T5G7	1-1/2"	3	2 AWG	24	10	32	8.20"	3.40"	2.60"
T6G7	2"	3	1/0 AWG	45	5	25	9.10"	4"	3.10"
T7G7	2-1/2"	3	2/0 AWG	95.8	1	8	12.40"	5.80"	3.70"
T8G7	3"	3	2/0 AWG	119	1	11	12.40"	5.80"	4.40"
T10G7	4"	3	250 MCM	231	1	18	14.50"	7"	5.40"

Rev. 0, 03/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.