



# Southwire™

## EMT CONDUIT BODIES

### SET SCREW T TYPE

#### FEATURES

- Set screw T type
- Suitable for use in concrete

#### APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

#### STANDARD MATERIAL

- Copper free aluminum die cast
- Steel screws

#### STANDARD FINISH

- Powder coat


#### CERTIFICATIONS

- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



ET1

PART #	SIZE	WIRE SIZE		INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
		MAX. NUMBER	MAX. SIZE						
ET1	1/2"	1	6 AWG	10	100	32	4.72"	1.37"	2.03"
ET2	3/4"	2	6 AWG	10	50	30	5.57"	1.625"	2.335"
ET3	1"	3	6 AWG	5	25	15	6.46"	1.90"	2.705"
ET4	1-1/4"	3	2 AWG	2	10	17	8.528"	2.77"	3.63"
ET5	1-1/2"	3	2 AWG	2	10	19	8.528"	2.77"	3.63"
ET6	2"	3	2/0 AWG	---	2	5	10.831"	3.335"	3.98"
ET7	2-1/2"	3	4/0 AWG	---	1	7	13.50"	4.06"	5.825"
ET8	3"	3	250 MCM	---	1	7	13.50"	4.685"	5.825"
ET9	3-1/2"	3	350 MCM	---	1	9	15.937"	5.45"	7.06"
ET10	4"	4	350 MCM	---	1	9	15.937"	5.45"	7.06"

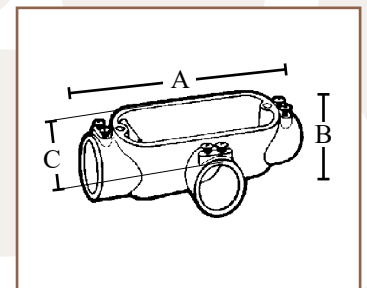

Rev. 0, 02/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.