

LED Lamps

ANTIQUE FILAMENT CANDELABRAS



Antique Style, Modern Energy Savings

With the lighting industry placing a relentless focus on LED efficacy and energy savings, Topaz has not forgotten the importance of lamps that are aesthetically appealing. Topaz's LED Antique Filament Candelabras offer the look and feel of traditional lighting to provide a warm ambiance in intimate settings. Suitable for open and enclosed fixtures, these lamps are ideal for decorative applications such as sconces and chandeliers in residential, commercial and hospitality settings. For additional atmosphere enhancement, these lamps are also dimmable down to 10% of their total light output.

FEATURES

- T20: Can be used to comply with California Energy Commission's Lighting Appliance Efficiency Regulations
- 90 CRI provides exceptional color rendering
- Dimmable down to 10% total light output
- Decorative candelabra with E12 screw base
- Suitable for open and enclosed fixtures

SUGGESTED APPLICATIONS

- Residential, commercial, and hospitality
- Decorative lighting, wall sconces, chandelier





Job Name/Title: _____ Catalog Number _____
 Contractor: _____ Notes: _____

LED Lamps ANTIQUE FILAMENT CANDELABRAS

GENERAL SPECIFICATIONS

Input Voltage, Frequency: 120V, 60Hz
Dimmable: Down to 10%
Efficacy: 90 LPW
CRI: 90
Beam Angle: 300°

Functional Life (L70): 15,000 hours
Location Rating: Damp
Ambient Operating Temperature: -4°F to 104°F
Enclosed Fixture Rating: Suitable
Housing Construction: Aluminum base

Base: E12
Finish / Color: Clear
Lens Type: Glass
Adapter Included: No

ITEM SPECIFICATIONS / ORDER INFO

Catalog Number	Order Code	UPC	Lumens	Wattage	Input Current	CCT	Shape
LCTC/5/927/ANTQ-61	71139	751338037977	500	5.5W	50mA	2700K	B11
LCTC/5/930/ANTQ-61	71140	751338037984	500	5.5W	50mA	3000K	B11
LCFC/5/927/ANTQ-61	71141	751338037991	500	5.5W	50mA	2700K	CA10
LCFC/5/930/ANTQ-61	71142	751338038004	500	5.5W	50mA	3000K	CA10

Not for sale in residential new construction in California.

NOMENCLATURE

Example: LCTC/5/927/ANTQ-61


LC = LED Candelabra / T = Blunt Torpedo Tip / C = Clear Lens / 5 = 5.5 Wattage / 9 = 90 CRI / 27 = 2700K CCT / ANTQ = Antique Filament
 / F = Flame Tip / 30 = 3000K CCT /

ENERGY SAVINGS

Catalog Number	LED Wattage	Incandescent Replacement Wattage	Watts Saved	Yearly Savings	5 Year Savings
Based on 12 hours/day and \$0.11/kWh					
LCxx/5/9xx/ANTQ-61	5.5W	60W	54.5W	\$26	\$131

PRODUCT DIMENSIONS / LINE DRAWING

Catalog Number	(A)	(B)	Weight
LCTC/5/9xx/ANTQ-61	3.8"	1.4"	0.191 Lbs.
LCFC/5/9xx/ANTQ-61	3.9"	1.3"	0.076 Lbs.

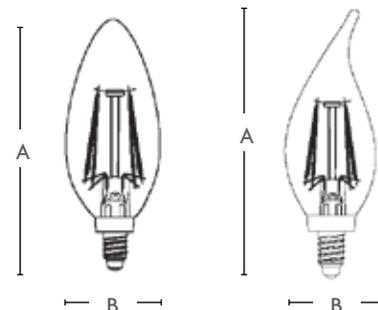

NOTES:

Dimming- This product is designed to be compatible with most leading-edge type incandescent and LED style dimmers. (Dimming range 100% down to 10%). Product performance may vary depending on dimmer manufacturer and circuit loading. Visit www.topaz-usa.com/led-dimmer-compatibility for up-to-date dimmer compatibility information.

Specifications subject to change without prior notice. Replacement wattage shown depends on application and fixture.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

WARNING: Some products included in this specification sheet may be subject to the warning requirements of California's Proposition 65. Please refer to your product packaging for more information.