



Southwire™

BX, FLEX CONNECTORS

90° - SQUEEZE TYPE - ZINC

FEATURES

- Squeeze type

APPLICATION

- Indoor use only
- In a dry location, use to connect flexible metallic conduit, AC and steel MC cable to a steel outlet box or other metal enclosure
- 3/8" size fits 1/2" knockout
- Suitable For: 3/8" – 3/4" steel and aluminum armored cable, steel and aluminum interlocked metal clad cable, flexible cord, and 1" – 4" flexible metallic conduit

STANDARD MATERIAL

- Zinc die cast
- Zinc plated steel strap


CERTIFICATIONS

- UL Standard: UL 514B
- Fed. Spec: W-F-406E, W-F-406D
- NEMA: FB 1-2014



100

PART #	CONDUIT SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B (MIN. – MAX.)	C	SCREWS
100	3/8" 1/2" KO	50	500	45	1.74"	.43" – .72"	.37"	2
101	1/2"	25	250	35	2.11"	.64" – 1.03"	.40"	2
102TZ	3/4"	10	100	20	2.40"	.76" – 1.15"	.40"	2
103	1"	5	50	19	2.87"	1.09" – 1.73"	.54"	2
104TZ	1-1/4"	10	40	20	4"	1.34" – 1.97"	.64"	2
105	1-1/2"	---	5	5	6"	1.65" – 2.61"	.75"	2
106	2"	---	5	6	6"	1.54" – 2.54"	.74"	2
107	2-1/2"	---	5	18	7.187"	2.45" – 2.98"	.875"	4
108	3"	---	2	9	7.875"	2.93" – 3.45"	1.031"	4
109	3-1/2"	---	1	9	9.40"	3.28" – 3.95"	1.031"	4
110TZ	4"	---	1	10	10.20"	3.68" – 4.43"	1.031"	4

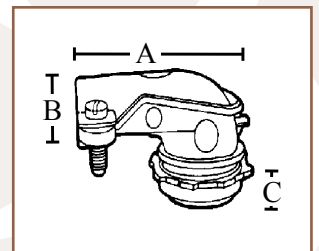

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.