


**Pipe-end insulator with tongue complete, composite, to pipe 1.25" Schedule 40**  
Part no. D2776-01

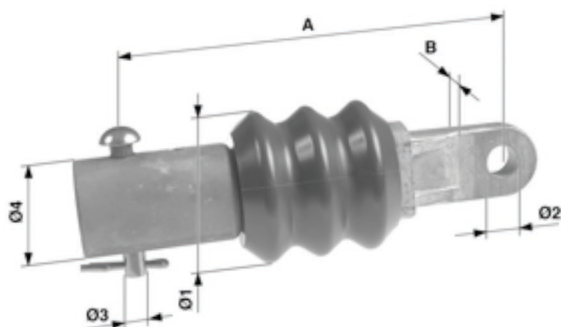

**Technical data**

Dimensions

A: 195 mm  
B: 18 mm  
Ø1: 80 mm  
Ø2: 17 mm  
Ø3: 12 mm  
Ø4: 34.0 mm

Material and weight

-

Loads and tightening torque

Breaking load: 30 kN

Standards applied

-

Function

-

Specifications

Operating voltage: max. 3.000 kV  
Minimum creeping distance: 92 mm for insulator

Spare parts

Pin, 12 x 60, Part no. E3232-01  
Cotter pin, 4.0 x 30, Part no. E3234-01

Accessories

-

Comments

- Connection parts in Al  
- Pin and cotter pin SST  
- Other insulators on request



**Southwire™**



A COLAS RAIL COMPANY

Contact Us: [Transit@southwire.com](mailto:Transit@southwire.com)