



Southwire™

EMT CONDUIT BODIES WITH COVER AND GASKET SET SCREW LR TYPE

FEATURES

- Set screw LR type with cover and gasket
- Suitable for use in concrete

APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

STANDARD MATERIAL

- Copper free aluminum die cast
- Steel screws
- Cover - Stamped steel
- Gasket - Neoprene rubber

STANDARD FINISH

- Powder coat


CERTIFICATIONS

- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



ELR1CG

PART #	SIZE	WIRE SIZE		INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
		MAX. NUMBER	MAX. SIZE						
ELR1CG	1/2"	1	6 AWG	10	100	36	4.295"	1.37"	2.03"
ELR2CG	3/4"	2	6 AWG	10	50	28	5.09"	1.625"	2.33"
ELR3CG	1"	3	6 AWG	5	25	17	5.915"	1.90"	2.65"
ELR4CG	1-1/4"	3	2 AWG	2	10	15	7.894"	2.77"	3.385"
ELR5CG	1-1/2"	3	2 AWG	2	10	18	7.894"	2.77"	3.385"
ELR6CG	2"	3	2/0 AWG	1	5	14	10.134"	3.335"	3.81"
ELR7CG	2-1/2"	3	4/0 AWG	---	1	7	12.50"	5.437"	4.45"
ELR8CG	3"	3	250 MCM	---	1	7	12.50"	5.657"	4.45"
ELR9CG	3-1/2"	3	350 MCM	---	1	10	15.50"	6.922"	5.50"
ELR10CG	4"	4	350 MCM	---	1	10	15.50"	6.922"	5.50"

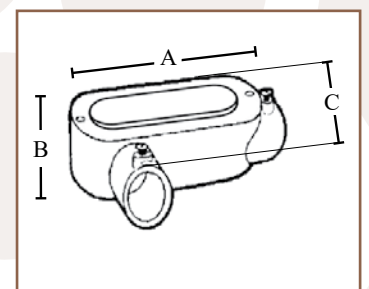

Rev. 0, 02/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.