



Caddy Mac #1
Part# 783398
Patented



Sumner's Caddy Mac #1 transports spools on spindles and works as a dolly!

Wire is dispensed while laying flat.




1/2" solid spindles are attached to cart... no loose pieces. Spindles lock in place, even during transportation.



Spindles swing out to set position for convenient loading of wire spools.



Inner spindles store in special loops which can hold four pieces and will not fall out during transportation.

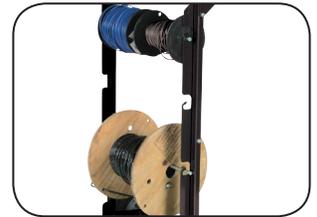

Spindles can be easily removed for the occasional use of larger spools.



Caddy Mac[®]

Caddy Mac #2
Part# 783395
Patented



Caddy Mac #2 holds 16 spools of #10 awg or 24 spools of #12 awg.

Hinge design allows easy access to all spools for wire dispensing and folds for compact storage.



Handi Mac[™]

- The Handi Mac dolly provides extra pool storage for Caddy Mac #1.
- Holds up to 8 additional spools.
- Spindles are made of sturdy 3/8" solid steel bar.



Handi Mac
Part# 783490



Caddy Mac #3

Part# 783400
Patent Pending



A Versatile Cart with SPECIAL Features

- Uses 5 spindles with 5/8" diameter
- Unique spindle locking system — no loose clips
- Storage loops retain up to 5 spindles
- 7 mounting positions
- Dual wire guides
- Large spool capacity

Spool Quantity	Maximum Spool Size			
	Diameter (inches)	Width (inches)	Diameter (mm)	Width (mm)
1	24	17-3/4	610	451
2	18	17-3/4	457	451
3	14	17-3/4	356	451
8	10	8-1/2	255	216
10	7	8-1/2	178	216
15	7	5-3/4	178	146
Maximum Platform Load		250 lb	115 kg	



Spindles slide into place from either side of cart.

Patented



Once in position, spindles lock without clips or snaps.

**ALL CADDY MAC CARTS
WILL ALSO HANDLE
CANADIAN SIZE SPOOLS**

Part #	Description	Dimensions			Weight	
		H	W	D	lb	kg
783400	Caddy Mac #3	47.25" 120 cm	26.5" 67 cm	21.5 55 cm	78	35.4

SPECIFICATIONS

Part #	Description	Dimensions		Dolly Capacity		Number of Spools	Maximum Spool Diameter		Weight	
		inches	cm	lb	kg		Inches	cm	lb	kg
783398	Caddy Mac #1	26.0 W 20.0 L 49.5 H	66.0 W 51.0 L 125.0 H	250.0	115.0	8 #10 awg or 12 #12 awg	7.5"	19.0	50.0	23.0
783395	Caddy Mac #2	26.0 W 14.0 L 49.5 H	66.0 W 35.6 L 125.0 H	N/A	N/A	16 #10 awg or 24 #12 awg	7.5"	19.0	63.0	28.6

Part #	Description	Dimensions		Number of Spools	Maximum Spool Diameter		Weight	
		inches	cm		Inches	cm	lb	kg
78349001	Handi Mac	12.5 W 22.5 L 10.0 H	31.8 W 57.2 L 25.4 H	4 7" x 10" or 8 7" x 5"	7.0"	17.8	7.5	3.4