



# Southwire™

## CABLE SUPPORT SYSTEMS

# J-HOOKS, BEAM/EDGE MOUNT HAMMER-ON CLIP

### APPLICATION

J-Hook cable supports with hammer-on beam edge clip can be attached to a wide variety of flange edges or beams. Southwire J-Hooks are an inexpensive alternative to cable trays. J-Hooks provide support to sensitive voice and data cables without causing stress.

### FEATURES

J-Hooks eliminate the problem of point loads that can cause band width damage to sensitive cables such as fiber optic, CAT 5E, 6, 7 or many others  
 Continuous wide base radius design supports the natural bends and curves of cable  
 Built-in cable retainer bar  
 360° rotation of J-Hook

### MATERIAL/FINISH

Clamp: Spring Steel/ GEOSEAL™

J-Hook: Steel/Galvanized

### CERTIFICATIONS

UL Standard: UL 2239




CAT3224TZ

JHK-12-H0



PART #	BEAM FLANGE THICKNESS	HOOK DIAMETER	CAT5E CABLE CAPACITY	A	B	C	D	E	BOX QTY.
JHK-12-H0**	1/8" TO 1/4"	3/4"	20	.748"	1.65"	1.06"	.866"	4.29"	50
JHK-12-H0516**	5/16" TO 1/2"	3/4"	20	.748"	1.65"	1.34"	.866"	4.57"	50
JHK-12-H0916**	9/16" TO 3/4"	3/4"	20	.748"	1.65"	1.63"	.866"	4.86"	50
JHK-21-H0**	1/8" TO 1/4"	1-5/16"	40	1.24"	1.79"	1.06"	1.64"	4.68"	50
JHK-21-H0516**	5/16" TO 1/2"	1-5/16"	40	1.24"	1.79"	1.34"	1.64"	4.96"	50
JHK-21-H0916**	9/16" TO 3/4"	1-5/16"	40	1.24"	1.79"	1.63"	1.64"	5.25"	50
CAT3224TZ*	1/8" TO 1/4"	2"	80	1.99"	2.5"	1.06"	1.64"	5.43"	50
JHK-32-H0516**	5/16" TO 1/2"	2"	80	1.99"	2.5"	1.34"	1.64"	5.71"	50
JHK-32-H0916**	9/16" TO 3/4"	2"	80	1.99"	2.5"	1.63"	1.64"	6"	50
JHK-64-H0**	1/8" TO 1/4"	4"	300	4.0"	4.69"	1.06"	1.91"	7.99"	25
JHK-64-H0516**	5/16" TO 1/2"	4"	300	4.0"	4.69"	1.34"	1.91"	8.27"	25
JHK-64-H0916**	9/16" TO 3/4"	4"	300	4.0"	4.69"	1.63"	1.91"	8.56"	25

\*cULus Listed, \*\*UL listed

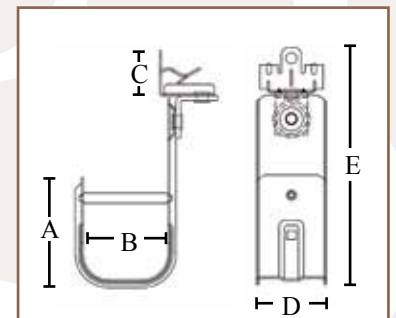

Rev. 1, 03/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.