



LED SURFACE MOUNT DISK LIGHTS

CCT SELECTABLE

SUGGESTED APPLICATIONS

- Ceiling or surface mount, designed to install with most 4" junction boxes
- Suitable for use in clothes closets when installed in accordance with NFPA 70, NEC section 410.16 (A)(3) and 410.16 (C)(5)

FEATURES

- 5 CCT Selectable Switch: 2700K/3000K/3500K/4000K/5000K
- ENERGY STAR® Certified, highly energy efficient with efficacy up to 82 LPW
- T24 JA8: Can be used to comply with California Energy Commission's High Efficacy LED light source requirements
- Exceptional light quality with Color Rendering Index of 90
- High performance, long functional life of 50,000 hrs (L70)
- Smooth dimming down to 5%

INPUT VOLTAGE: 120V

FREQUENCY: 60Hz

POWER FACTOR: ≥ 0.96 , $\leq 13\%$

DIMMABLE: DOWN TO 5%

EFFICACY: 82 LPW

CRI: 90


BEAM ANGLE: 113°

LIFETIME (L70): 50,000 HOURS

LOCATION RATING: WET

AMBIENT OPERATING TEMPERATURE: -4°F TO 113°F

CONSTRUCTION: ALUMINUM HOUSING WITH WHITE, BRONZE OR BRUSHED NICKEL FINISH, SMOOTH FRAME AND POLYCARBONATE LENS

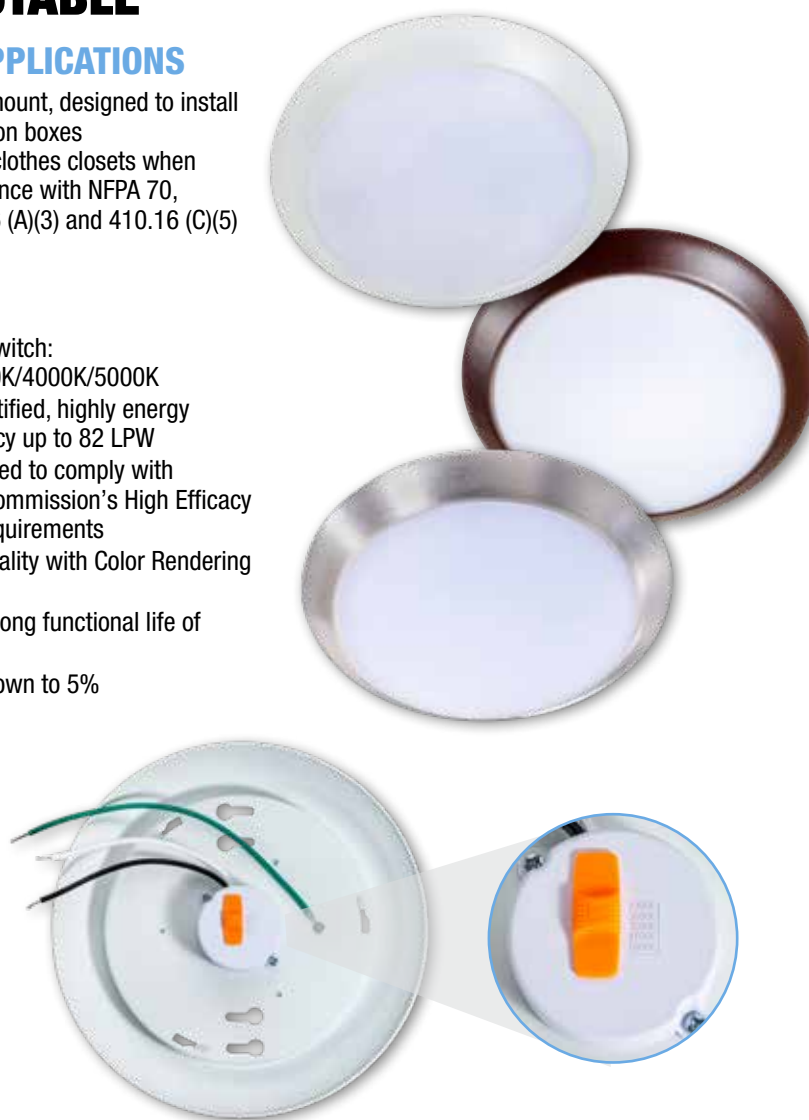

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



LED SURFACE MOUNT DISK LIGHTS

CCT SELECTABLE

ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	SIZE	LUMENS	WATTAGE	INPUT CURRENT	CCT	ENERGY STAR
WHITE								
SDL4/8W/WH/D/CTS	70722	751338037069	4"	660	8W	0.09A	2700K 3000K 3500K 4000K 5000K	Y
SDL6/11W/WH/D/CTS	70723	751338037076	6"	905	11W	0.125A		Y
SDL6/15W/WH/D/CTS	70724	751338037083	6"	1,230	15W	0.16A		Y
BRONZE								
SDL4/8W/BZ/D/CTS	70768	751338038011	4"	660	8W	0.09A	2700K 3000K 3500K 4000K 5000K	Y
SDL6/11W/BZ/D/CTS	70769	751338038028	6"	905	11W	0.125A		Y
SDL6/15W/BZ/D/CTS	70770	751338038035	6"	1,230	15W	0.16A		Y
BRUSHED NICKEL								
SDL4-8W-BN-D-CTS	73737	032886304842	4"	660	8W	0.09A	2700K 3000K 3500K 4000K 5000K	Y
SDL6-11W-BN-D-CTS	73738	032886304859	6"	905	11W	0.125A		Y
SDL6-15W-BN-D-CTS	73739	032886304866	6"	1,230	15W	0.16A		Y

ORDERING GUIDE

Example: **SDL4/8W/WH/D/CTS**

PRODUCT	SIZE	WATTAGE	COLOR	DIMMABLE	CCT
SDL = SURFACE MOUNT DISK LIGHT	4 = 4" 6 = 6"	8W = 8 WATTS 11W = 11 WATTS 15W = 15 WATTS	WH = WHITE BZ = BRONZE BN = BRUSHED NICKEL	D=DIMMABLE	CTS = COLOR TEMPERATURE SELECTABLE

ENERGY SAVINGS Based on 12 hours/day and \$0.11/kWh

MODEL #	LED WATTAGE	INCANDESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
SDL4/8W/xx/D/CTS	8W	65W	42W	\$20.24	\$101.18
SDL4-8W-BN-D-CTS	8W	65W	42W	\$20.24	\$101.18
SDL6/11W/xx/D/CTS	11W	75W	54W	\$26.02	\$130.09
SDL6-11W-BN-D-CTS	11W	75W	54W	\$26.02	\$130.09
SDL6/15W/xx/D/CTS	15W	85W	60W	\$28.91	\$144.54
SDL6-15W-BN-D-CTS	15W	85W	60W	\$28.91	\$144.54




800-666-2852 | [SOUTHWIRE.COM](https://www.southwire.com)

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.




DIMENSIONS | WEIGHT


MODEL #	A (IN)	B (IN)	WEIGHT (LBS.)
SDL4/8W/xx/D/CTS	5.43	1.77	0.30
SDL4-8W-BN-D-CTS	5.43	1.77	0.30
SDL6/11W/xx/D/CTS	7.48	1.89	0.46
SDL6-11W-BN-D-CTS	7.48	1.89	0.46
SDL6/15W/xx/D/CTS	7.48	1.89	0.46
SDL6-15W-BN-D-CTS	7.48	1.89	0.46

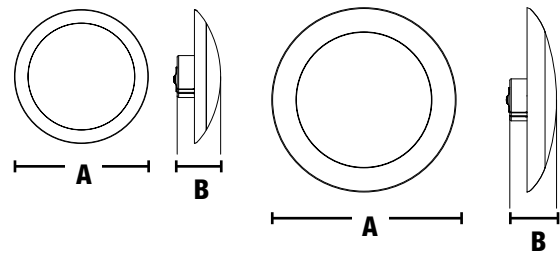


POLAR PLOTS

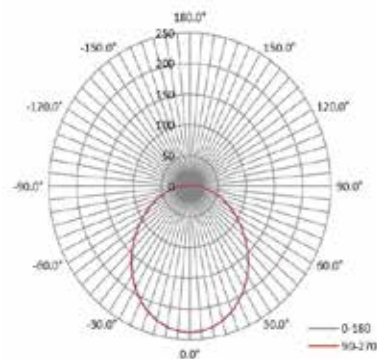

4" 8W

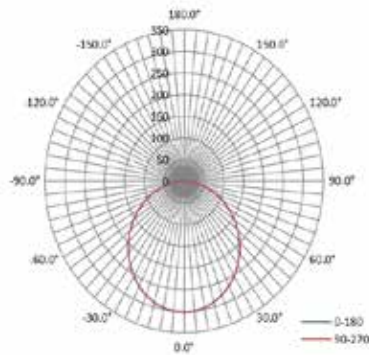

6" 11W

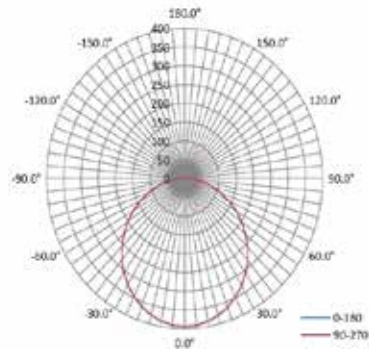

6" 15W

NOTES

Dimming- This unit is designed to be compatible with most leading-edge type incandescent or LED style dimmers. (Dimming range 100% - 5%). Fixture performance may vary depending on dimmer manufacturer and circuit loading. Contact your local Southwire representative for a list of compatible dimmers.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC. For details visit: <https://southwire.com/resources/warranties>. This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

Specifications are subject to change without prior notice. Replacement wattage shown depends on application and fixture.



800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.