



# Southwire™

## RIGID COUPLINGS

### COMPRESSION TYPE - STEEL

#### FEATURES

- Compression type coupling
- Threadless
- Concrete tight

#### APPLICATION

- Dry location only
- Use to join two lengths unthreaded Rigid or IMC conduit

#### STANDARD MATERIAL

- Steel

#### STANDARD FINISH

- Zinc plated

#### CERTIFICATIONS


- UL Standard: UL 514B
- Fed. Spec: W-F-406E, W-F-406D
- NEMA: FB 1-2014



251



PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/CASE (LBS.)	A	B
251TZ	1/2"	10	100	16	1.74"	1.17"
252TZ	3/4"	10	100	24	1.82"	1.43"
253	1"	5	50	24	1.95"	1.75"
254	1-1/4"	5	50	43	2.65"	2.15"
255	1-1/2"	---	12	15	2.70"	2.37"
256	2"	---	5	8	2.93"	3.38"

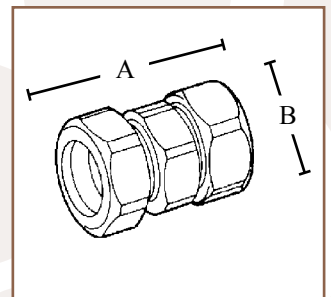

Rev. 0, 03/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.