



# Hang-A-Light® 400W Metal Halide

This Hang-A-Light® 400 watt Metal Halide temporary lighting fixture produces 360° of light. The integrated 6 foot power cord and spring loaded, steel safety hook make for fast installation. The heavy gauge steel safety case has an added bottom guard for protection and durability.



Spring Loaded Hanging Hook


6' Integrated Power Cord

cUL Listed

Welded Wire Safety Cage

400 Watts

42,000 Lumens

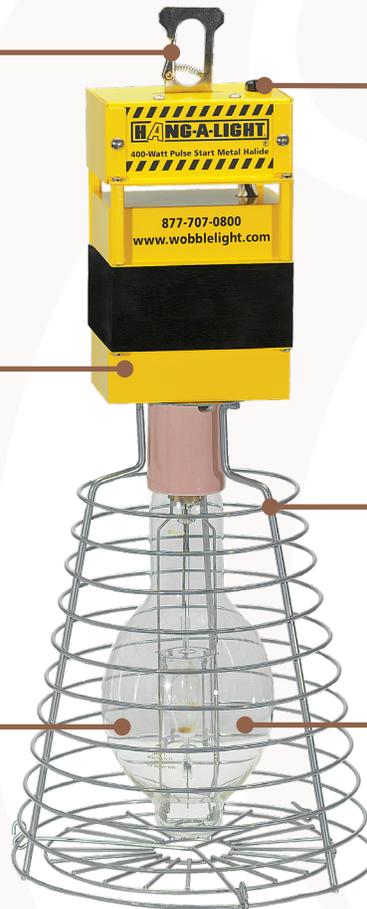

Model No.	Lumens	Lighting Range	Bulb Type	Lamp Life	Kelvins	Watts	Amp Draw	Linking Units	Voltage	Temp Rated	Tested	Cord Type	Weight
111400PS	42,000	100 ft	Metal Halide	20,000 hrs	4,100	400	4	Modifiable	120V*	-22°-120°F	cUL	14/3 SJTW	20 lbs

\*Modifiable to 277V

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRETOOLS.COM

©2019 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.